



Insulators (Porcelain)

STRAIN, SUSPENSION, SPOOL, PIN TYPE

Wet Insulators


Cat. No. Hydel	K.V.L.F CdnPorc	COB	L (")	W (")	Flashover (Dry)	Flashover (Wet)	Nominal KV	Pin Diameter	Minimum Pin Height	Std.Pkg.	Wt.-Lbs. / C	ANSI Class No.
Spool Insulator (WSPG):												
1606WSPG	2011	----	2-1/8	2-1/4	20	8/10	8 (vert) 10 (hor)	1/2	120	50	51	53-1
355WSPG	2012	----	3	3-1/8	25	12/15	12 (vert) 15 (hor)	5/8	50	50	126	53-2
Guy Strain Insulator (WGS):												
502WGS	502	3-1/2	2-1/2	25	12	5/8		5/8	50	50	100	54-1
504WGS	504	31504	4-1/4	2-7/8	30	15	4.4	1/2	40	50	170	54-2
506WGS	506	32506	5-1/2	3-3/8	35	18	6.6	5/8	20	25	240	54-3
451WGS	451	31352	6-3/4	3-1/2	40	23	6.6	5/8	20	25	455	54-4
Pin Type Insulator (WPT):												
505WPT	28085	100231	3-1/4	3-3/4	50	25	7.2	1	3-3/4	32	164	----
555WPT	555	12847	3-1/4	3-3/4	50	25	7.2	1	3-3/4	32	154	55-2
5916WPT	5916.Q	38148	3-3/4	4-3/4	65	35	13.2	1	4-3/4	24	238	55-3
2783WPT	2783.Q	38149	4-1/2	5-1/2	70	40	13.2	1	4-3/4	18	350	55-4
2785WPT	2785.Q	38151	4-5/8	7	85	45	15	1	6	8	600	55-5
3930WPT	3930.Q	38222	6-1/4	9	110	70	23	1-3/8	7	3	1200	56-2
4575WPT	4575.Q	38223	7-1/2	10 1/2	125	80	36	1-3/8	8	3	1900	56-3
4830WPT	4830.Q	38255		12	140	95	36	1-3/8	10	3	2935	56-4
Suspension Insulator (WSU):												
26434WSU	28674	42399	6-1/4	4-1/4	50	30	6	5/8		6	630	----
8080WSU	28676	32433	5-1/2	6	60	30	6	5/8		6	680	52-1
6500WSU	6500	32439	5-3/4	10	80	50	16	5/8		6	1200	52-4



504WGS



506WGS

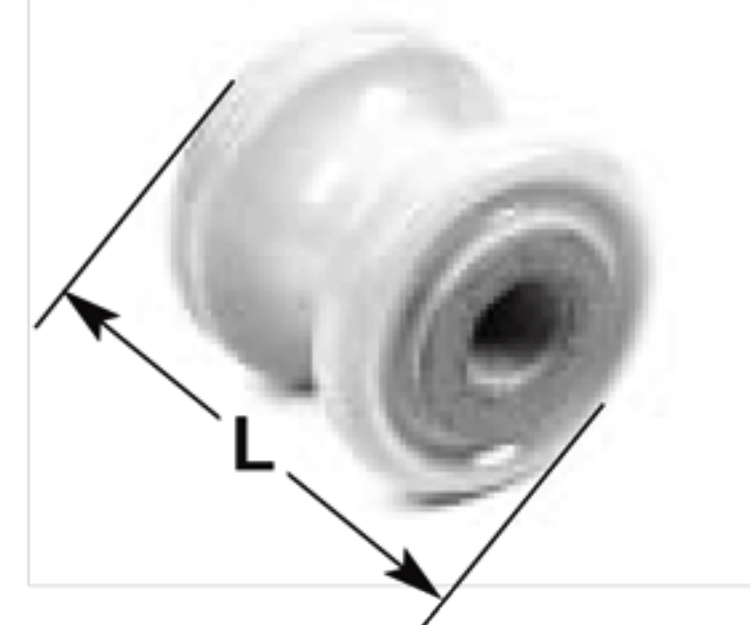

355WSPG



2783WPT



3930WPT



8080WSU

INSULATORS (PORCELAIN)