




# Guying

## GUY WIRE

### Guy Wire

C.S.A. standard guy strand formed from 7 individual strands and hot dip galvanized (4 immersion).

Cat. No.	Diameter	Grade and breaking strength lbs.				Wt.-lbs./ C ft.	Wt.-lbs./ C mtrs.
		50	110	160	180		
14GW	1/4"	1,800	3,950	5,750	6,450	12.9	42.31
516GW	5/16"	3,100	6,800	9,900	11,150	22.2	72.82
38GW	3/8"	3,750	8,250	12,000	13,500	27.0	88.56
716GW	7/16"	5,410	11,900	17,300	19,500	38.8	127.26
12GW	1/2"	7,100	15,600	22,700	25,500	51.0	167.28

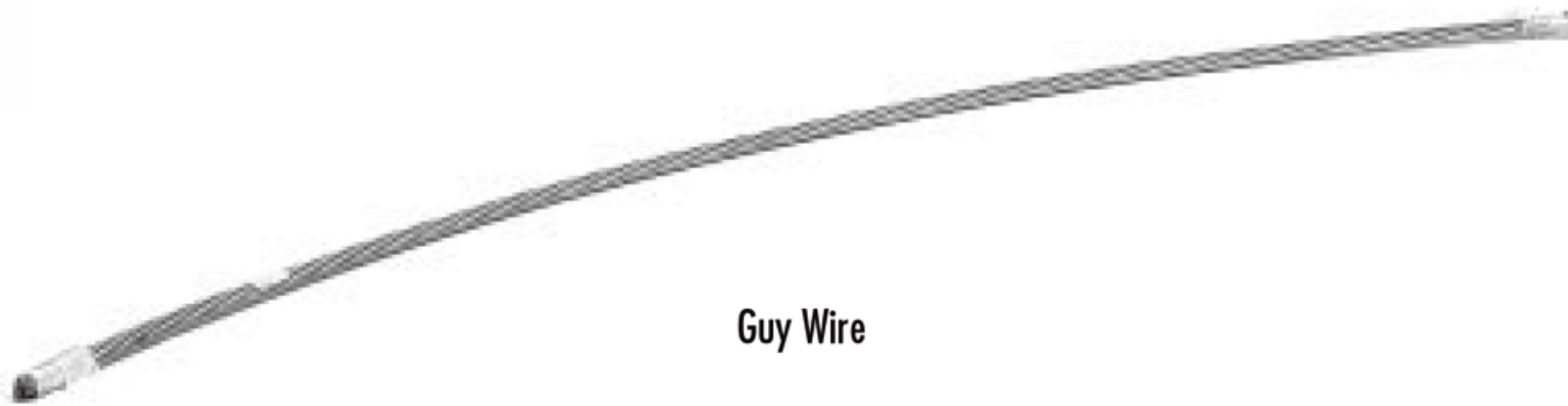

Guy Wire

### Standard coil and spool sizes carried in stock

Spools:	5,000 feet (1525 meters)	2,500 feet (762.5 meters)
Coils:	500 feet (152.5 meters)	250 feet (76.25 meters)

When ordering, order by Catalogue number length and grade. Please also specify spool or coil.  
 Prices vary only with diameter and grade, not with the size of spool or coil.  
 A cutting charge applies to all special size spools and coils.  
 A deposit charge applies to all spools with less than 2,500 feet of wire.

### Aluminum Tie Wire

Cat.No.	Description	Wt./1000 feet
4TWA	# 4 gauge	34 lbs.



4TWA