



Anchors

ANCHOR RODS

Screw Anchors (Wrenchless)

Hot dip Galvanized.

Rod and plate are one unit.

Installed by inserting a 1" rod into eye and turning the anchor manually.

Cat. No.	Diameter plate	Holding Strength	Diameter Rod	Holding Strength Dry Clay – lbs.	Std. Pkg.	Wt.-lbs./C
634SA	6"	6500 #	3/4	5500	2	1050
810SA	8"	8000 #	1	8000	1	1900



634SA

Anchor Rods

Threaded anchor rods for all types of anchors.

Single thimble (AST); Double thimble (ADT);

C.S.A. Specification No. C-83 No. R1, R2, R3 and R14.


Cat.No.		Length	Diameter	Std.Pkg.	Wt. lbs./ C
Single	Double				
658AST	658ADT	6'	5/8	5	750
758AST	758ADT	7'	5/8	5	830
	858ADT	8'	5/8	5	930
	634ADT	6'	3/4	5	1010
	734ADT	7'	3/4	5	1160
	834ADT	8'	3/4	5	1320

Minimum breaking strength at thread root:

5/8" diameter - 15, 000 lbs.

3/4" diameter - 23, 000 lbs.

All anchor rods supplied with heavy square nuts.

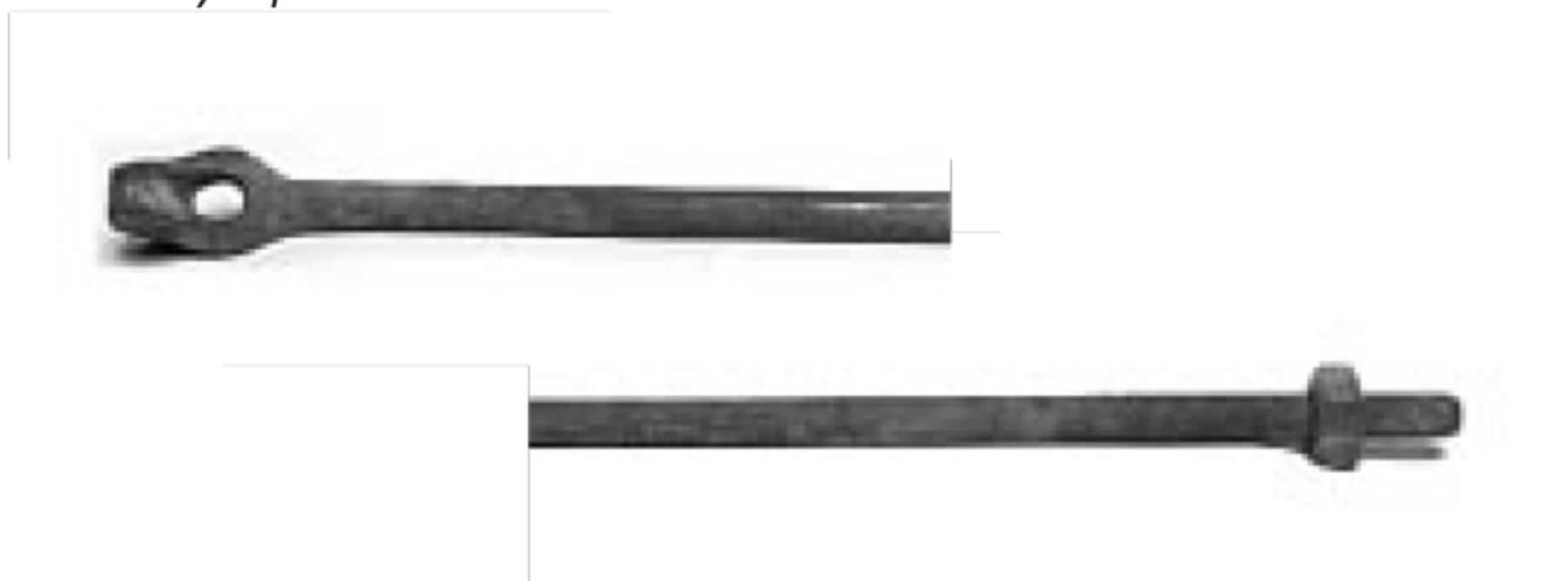

658ADT