

JA Series



100 AMP SOCKET & BREAKER


Breaker not included, Service Entrance Approved

CATALOGUE #	DESCRIPTION	ENCLOSURE SIZE H X W X D	WEIGHT
JA400RW	Conductor range #6 - 1/0 AWG CU/AL (combination)*†	22 ³ / ₈ " x 8 ¹ / ₄ " x 3 ³ / ₄ "	20 lbs.
JA400RWT	As above, c/w 100 amp 2 pole breaker	22 ³ / ₈ " x 8 ¹ / ₄ " x 3 ³ / ₄ "	21 lbs.
JA400PW	Conductor range #6 - 1/0 AWG CU/AL overhead	22 ³ / ₈ " x 8 ¹ / ₄ " x 3 ³ / ₄ "	20 lbs.
JA000PW	Conductor range #6 - #3 copper only (overhead)*†	18 ¹ / ₄ " x 7 ⁵ / ₈ " x 3 ³ / ₄ "	15 lbs.
JA000PWSD	As above but adapted to take SQ D breaker only - "QO" series	18 ¹ / ₄ " x 7 ⁵ / ₈ " x 3 ³ / ₄ "	15 lbs.

- 4 Jaw - 100Amp - 120/240 VOLT
- Combination meter socket & circuit breaker
- CSA weatherproof enclosure 3
- Suitable for mobile homes, farm services, trailers, temporary services, etc.
- JA000 used with the following makes of breakers: Westinghouse - "BR"
ITE - "Q"
CGE - "THQAL"

*Breaker not included (sold separately)
†Select from table below
- Plug-in circuit breakers fully magnetic
- Use SXX503 for 5th Jaw at 9 O'clock

KNOCKOUT CODE	CONDUIT SIZE
A	1/2", 1", 1 1/4"
C	1", 1 1/4", 1 1/2"
E	1", 1 1/4", 1 1/2", 2"

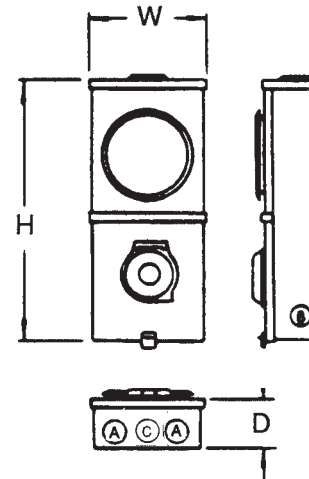

SINGLE POLE

CAT. NO.	AMPS
MP115	15
MP120	20
MP130	30
MP140	40
MP150	50

DOUBLE POLE

CAT. NO.	AMPS
MP215	15
MP220	20
MP230	30
MP240	40
MP250	50

DOUBLE POLE

CAT. NO.	AMPS
MP260	60
MP270	70
MP211	100