



netSELECT® Patch Panels are excellent for designing rack systems for telephone, data and AV systems. Consolidation Blocks are ideal for small user count configurations that mount in or on the wall.

- Meets ANSI/TIA - Category 6 and Category 5e standards
- cULus Listed

**Universal Consolidation Blocks and Patch Panels**

Description	Catalog Number
Category 5e 12-Port Universal Consolidation Block, 89D Bracket Mount	<b>NS5E12U</b>
Category 6 12-Port Universal Consolidation Block, 89D Bracket Mount	<b>NS612U</b>
Category 5e Universal Patch Panel 24-port, 1.75 inch H, 1 Rack Unit 48-port, 3.50 inch H, 2 Rack Units	<b>NS5E24U</b> <b>NS5E48U</b>
Category 6 Universal Patch Panel 24-port, 1.75 inch H, 1 Rack Unit 48-port, 3.50 inch H, 2 Rack Units	<b>NS624U</b> <b>NS648U</b>



**NS5E12U**



**NS612U**



**NS5E24U**



**NS5E48U**



**NS624U**





**NS648U**

netSELECT® Patch Cords allow for quick change of voice/data lines with insertion of modular plugs.

- Meets and exceeds ANSI/TIA - Category 6 and Category 5e standards
- UL and cUL Listed

**Universal Patch Cords, Category 6 and Category 5e**

Description	Color	1-Foot	3-Foot	5-Foot	7-Foot	10-Foot	15-Foot	20-Foot	25-Foot
Cat. 5e Patch Cord 	Blue	<b>HC5EB01</b>	<b>HC5EB03</b>	<b>HC5EB05</b>	<b>HC5EB07</b>	<b>HC5EB10</b>	<b>HC5EB15</b>	<b>HC5EB20</b>	<b>HC5EB25</b>
	Gray	<b>HC5EGY01</b>	<b>HC5EGY03</b>	<b>HC5EGY05</b>	<b>HC5EGY07</b>	<b>HC5EGY10</b>	<b>HC5EGY15</b>	<b>HC5EGY20</b>	<b>HC5EGY25</b>
	Yellow	<b>HC5EY01</b>	<b>HC5EY03</b>	<b>HC5EY05</b>	<b>HC5EY07</b>	<b>HC5EY10</b>	<b>HC5EY15</b>	<b>HC5EY20</b>	<b>HC5EY25</b>
	Red	<b>HC5ER01</b>	<b>HC5ER03</b>	<b>HC5ER05</b>	<b>HC5ER07</b>	<b>HC5ER10</b>	<b>HC5ER15</b>	<b>HC5ER20</b>	<b>HC5ER25</b>
Cat. 6 Patch Cord 	Blue	<b>HC6B01</b>	<b>HC6B03</b>	<b>HC6B05</b>	<b>HC6B07</b>	<b>HC6B10</b>	<b>HC6B15</b>	<b>HC6B20</b>	<b>HC6B25</b>
	Gray	<b>HC6GY01</b>	<b>HC6GY03</b>	<b>HC6GY05</b>	<b>HC6GY07</b>	<b>HC6GY10</b>	<b>HC6GY15</b>	<b>HC6GY20</b>	<b>HC6GY25</b>
	Yellow	<b>HC6Y01</b>	<b>HC6Y03</b>	<b>HC6Y05</b>	<b>HC6Y07</b>	<b>HC6Y10</b>	<b>HC6Y15</b>	<b>HC6Y20</b>	<b>HC6Y25</b>
	Red	<b>HC6R01</b>	<b>HC6R03</b>	<b>HC6R05</b>	<b>HC6R07</b>	<b>HC6R10</b>	<b>HC6R15</b>	<b>HC6R20</b>	<b>HC6R25</b>



netSELECT® Accessories enhance system capabilities. Volume controls expand home audio applications. Cabinet mounted receptacle kits provide convenience power to the enclosure.

- Audio controls available in slide or rotary
- Receptacles available in surge and standard kits

**Accessories**

Description	Color	Catalog Number
Slide Audio Volume Controller, Decorator Styling, Power handling - 70W RMS@20° C. Impedance matching for up to 8 pairs of speakers. Includes both ivory and white slides and frames.	Ivory/White	<b>NSOSAVC</b>
Rotary Audio Volume Controller Power handling - 70W RMS@20° C. Impedance matching for up to 8 pairs of speakers. Includes both ivory and white knobs and frames.	Ivory/White	<b>NSORAVC</b>
Standard Power Kit, Includes tamper-resistant duplex receptacle 15A 125V NEMA 5-15R, electrical steel box and wallplate.		<b>NSOKPTR</b>
Surge Suppression Power Kit, Includes surge receptacle 15A 125V NEMA 5-15R, 240 Joules/15,000A protection per mode, electrical steel box and wallplate.		<b>NSOKPS</b>
Chromed Steel Lock Kit, Includes two keys. Eliminates unwanted tampering.		<b>FLOCK1</b>
Panel Bracket Adapter, For use with Adapter Panels shown below, and FSP series modules. Snap mounts into structured cabling enclosures.		<b>NSOFSB</b>
F-Connector Adapter Panel, with Six Populated Coaxial Connectors.		<b>FSPFP6X</b>
Keystone Adapter Panel, with Six Blank Openings for jacks and snap fits.		<b>FSPHD6X</b>
WiFi Antenna Kit, Use with X2 extensions to assure maximum WiFi coverage.		<b>NSOKA</b>



**NSOSAVC**



**NSORAVC**



**NSOKPS**



**FLOCK1**



**NSOFSB**



**FSPFP6X**




**FSPHD6X**



**NSOKA**



Customize the jack selections and look

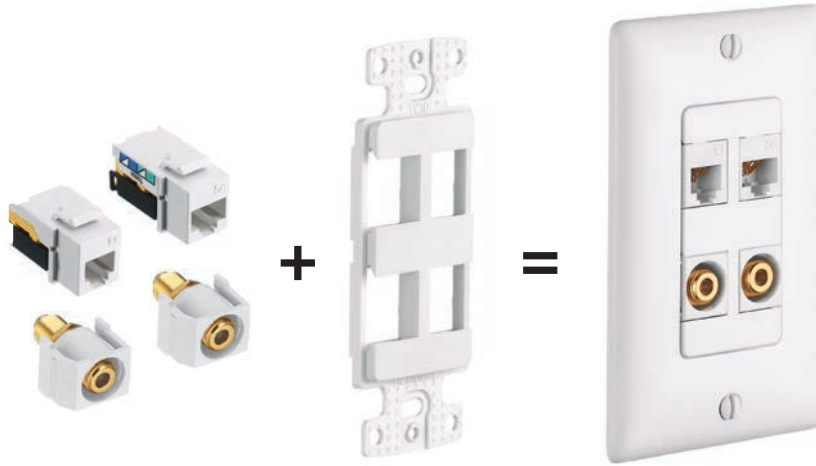

**Molded-In Voice/Low-Speed Data - Modular Snap Fit**

Color	Category 6 Jack (single)	Category 6 Jack (25 pack)	Category 5e Jack (single)	Category 5e Jack (25 pack)	USOC Jack (single)
Black	NSJ6BK	NSJ6BK25	NSJ5EBK	NSJ5EBK25	NSJUBK
Blue	NSJ6B	NSJ6B25	NSJ5EB	NSJ5EB25	NSJUB
Gray	NSJ6GY	NSJ6GY25	NSJ5EGY	NSJ5EGY25	NSJUGY
Green	NSJ6GN	NSJ6GN25	NSJ5EGN	NSJ5EGN25	NSJUGN
Ivory	NSJ6I	NSJ6I25	NSJ5EI	NSJ5EI25	NSJUI
Light Almond	NSJ6LA	NSJ6LA25	NSJ5ELA	NSJ5ELA25	NSJULA
Orange	NSJ6OR	NSJ6OR25	NSJ5EOR	NSJ5EOR25	NSJUOR
Red	NSJ6R	NSJ6R25	NSJ5ER	NSJ5ER25	NSJUR
White	NSJ6W	NSJ6W25	NSJ5EW	NSJ5EW25	NSJUW
Yellow	NSJ6Y	NSJ6Y25	NSJ5EY	NSJ5EY25	NSJUY

**Audio/Video Connectors - Standard Bulkhead**

Color	Nickel F-Type Coupler Bulkhead, Female to Female	Gold F-Type Coupler Bulkhead, Female to Female	RCA Gold Pass Through, Female to Female, Red Interior	RCA Gold Pass Through, Female to Female, White Interior	RCA Gold Pass Through, Female to Female, Yellow Interior	RCA Gold Pass Through, Female to Female, Blue Interior	RCA Gold Pass Through, Female to Female, Green Interior
Black	NSF70BK	SFFGBK	SFRCRFBK	SFRCWFBK	SFRCYFBK	SFRCBFBK	SFRCGNFBK
Gray	NSF70GY	SFFGGY	SFRCRFGY	SFRCWFGY	SFRCYFGY	SFRCBFGY	SFRCGNFGY
Ivory	NSF70I	SFFGEI	SFRCRFEI	SFRCWFEI	SFRCYFEI	SFRCBFEI	SFRCGNFEI
Light Almond	NSF70LA	SFFGLA	SFRCRFLA	SFRCWFLA	SFRCYFLA	SFRCBFLA	SFRCGNFLA
White	NSF70W	SFFGW	SFRCRFFW	SFRCWFFW	SFRCYFFW	SFRCBFFW	SFRCGNFFW

**Audio/Video Connectors - Recessed**

Color	Gold F-Type Coupler Bulkhead, Female to Female	RCA Gold Pass Through, Female to Female, Red Interior	RCA Gold Pass Through, Female to Female, White Interior	RCA Gold Pass Through, Female to Female, Yellow Interior	RCA Gold Pass Through, Female to Female, Blue Interior	RCA Gold Pass Through, Female to Female, Green Interior	Blank Insert
Black	SFGRFBK	SFRCRRBK	SFRCWRBK	SFRCYRBK	SFRCBRBK	SFRCGNRBK	SFSBBK10*
Gray	SFGRFGY	SFRCRRGY	SFRCWRGY	SFRCYRGY	SFRCBRGY	SFRCGNRGY	SFSBGY10*
Ivory	SFGRFEI	SFRCRREI	SFRCWREI	SFRCYREI	SFRCBREI	SFRCGNREI	SFSBEI10*
Light Almond	SFGRFLA	SFRCRRLA	SFRCWRLA	SFRCYRLA	SFRCBRLA	SFRCGNRLA	SFSBLA10*
White	SFGRFW	SFRCRRW	SFRCWRW	SFRCYRW	SFRCBRW	SFRCGNRW	SFSBW10*

Note: \*Sold in a package of 10. Order 1 to receive a bag of 10 blanks.



## Features

Decorator frames provide a stylized look for that finishing touch. This allows all devices to match. Multimedia jacks insert into frame for custom configuration.

- Elongated strap for better wall box mounting
- High impact-resistant thermoplastic frame
- UL Listed 1863 - Communication Circuit Accessory and CSA Certified

## Decorator Frames



Color	1-Gang, 2-Port	1-Gang, 3-Port	1-Gang, 4-Port	1-Gang, 6-Port	1-Gang, Adapter .406" (10.30) Dia. Hole*	1-Gang, Adapter Blank**
Black	<b>NS612BK</b>	<b>NS613BK</b>	<b>NS614BK</b>	<b>NS616BK</b>	<b>NS621BK</b>	<b>NS620BK</b>
Gray	<b>NS612GY</b>	<b>NS613GY</b>	<b>NS614GY</b>	<b>NS616GY</b>	<b>NS621GY</b>	<b>NS620GY</b>
Ivory	<b>NS612I</b>	<b>NS613I</b>	<b>NS614I</b>	<b>NS616I</b>	<b>NS621I</b>	<b>NS620I</b>
Light Almond	<b>NS612LA</b>	<b>NS613LA</b>	<b>NS614LA</b>	<b>NS616LA</b>	<b>NS621LA</b>	<b>NS620LA</b>
White	<b>NS612W</b>	<b>NS613W</b>	<b>NS614W</b>	<b>NS616W</b>	<b>NS621W</b>	<b>NS620W</b>

Note: \*For use with rotary dimmers or to pull through AV or telephone cable.  
 \*\*To fill an extra decorator opening or to create customized openings.

## Multimedia Face Plates



Description	1-Gang, 1-Port Plate		1-Gang, 2-Port Plate		1-Gang, 3-Port Plate	
	Standard (4.63" x 2.88")	Mid-Size (4.88" x 3.13")	Standard (4.63" x 2.88")	Mid-Size (4.88" x 3.13")	Standard (4.63" x 2.88")	Mid-Size (4.88" x 3.13")
Black	<b>NSP11BK</b>	<b>NSP101BK</b>	<b>NSP12BK</b>	<b>NSP102BK</b>	<b>NSP13BK</b>	<b>NSP103BK</b>
Gray	<b>NSP11GY</b>	<b>NSP101GY</b>	<b>NSP12GY</b>	<b>NSP102GY</b>	<b>NSP13GY</b>	<b>NSP103GY</b>
Ivory	<b>NSP11I</b>	<b>NSP101I</b>	<b>NSP12I</b>	<b>NSP102I</b>	<b>NSP13I</b>	<b>NSP103I</b>
Light Almond	<b>NSP11LA</b>	<b>NSP101LA</b>	<b>NSP12LA</b>	<b>NSP102LA</b>	<b>NSP13LA</b>	<b>NSP103LA</b>
White	<b>NSP11W</b>	<b>NSP101W</b>	<b>NSP12W</b>	<b>NSP102W</b>	<b>NSP13W</b>	<b>NSP103W</b>



Description	1-Gang, 4-Port Plate		1-Gang, 6-Port Plate		2-Gang, 4-Port Plate	2-Gang, 6-Port Plate
	Standard (4.63" x 2.88")	Mid-Size (4.88" x 3.13")	Standard (4.63" x 2.88")	Mid-Size (4.88" x 3.13")	Standard (4.63" x 4.69")	Standard (4.63" x 4.69")
Black	<b>NSP14BK</b>	<b>NSP104BK</b>	<b>NSP16BK</b>	<b>NSP106BK</b>	<b>NSP24BK</b>	<b>NSP26BK</b>
Gray	<b>NSP14GY</b>	<b>NSP104GY</b>	<b>NSP16GY</b>	<b>NSP106GY</b>	<b>NSP24GY</b>	<b>NSP26GY</b>
Ivory	<b>NSP14I</b>	<b>NSP104I</b>	<b>NSP16I</b>	<b>NSP106I</b>	<b>NSP24I</b>	<b>NSP26I</b>
Light Almond	<b>NSP14LA</b>	<b>NSP104LA</b>	<b>NSP16LA</b>	<b>NSP106LA</b>	<b>NSP24LA</b>	<b>NSP26LA</b>
White	<b>NSP14W</b>	<b>NSP104W</b>	<b>NSP16W</b>	<b>NSP106W</b>	<b>NSP24W</b>	<b>NSP26W</b>




### Features

Designed to complement decorator styling, these jacks offer voice and Cat. 5e devices to fit within a decorator wallplate.

- High impact-resistant thermoplastic frame
- Meets FCC part 68
- UL Listed 1863 - Communication Circuit Accessory and CSA Certified

### Molded-In Voice/Low-Speed Data

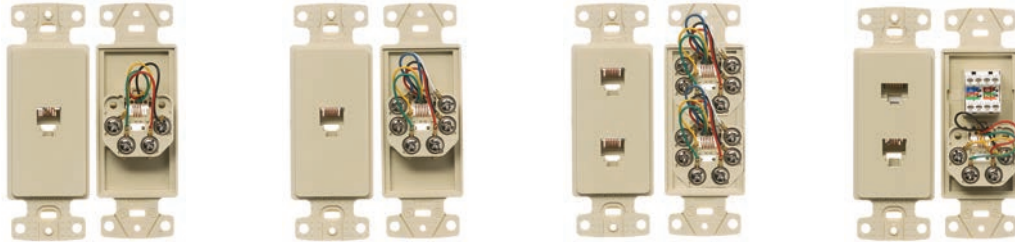


Description	Decorator Frame, One RJ11 Jack, 6-Position, 4-Conductor	Decorator Frame, One RJ11 Jack, 6-Position, 6-Conductor	Decorator Frame, Duplex RJ11 Jacks, 6-Position, 6-Conductor	Decorator Frame, One Cat. 5e 110 Punch-Down, One RJ11 Jack, 6-Position, 4-Conductor
Color	Screw Terminations	Screw Terminations	Screw Terminations	Screw Terminations
Black	<b>NS770BK</b>	—	—	<b>NS784BK</b>
Brown	<b>NS770</b>	<b>NS771</b>	—	<b>NS784</b>
Gray	<b>NS770GY</b>	—	—	<b>NS784GY</b>
Ivory	<b>NS770I</b>	<b>NS771I</b>	<b>NS772I</b>	<b>NS784I</b>
Light Almond	<b>NS770LA</b>	<b>NS771LA</b>	<b>NS772LA</b>	<b>NS784LA</b>
White	<b>NS770W</b>	<b>NS771W</b>	<b>NS772W</b>	<b>NS784W</b>

### Features

Coaxial video and combination jacks complement multimedia needs in a 1-gang decorator opening.

- High impact-resistant thermoplastic frame
- Jacks meet FCC part 68
- UL Listed 1863 - Communication Circuit Accessory and CSA Certified

### Molded-In Voice/Low-Speed Data

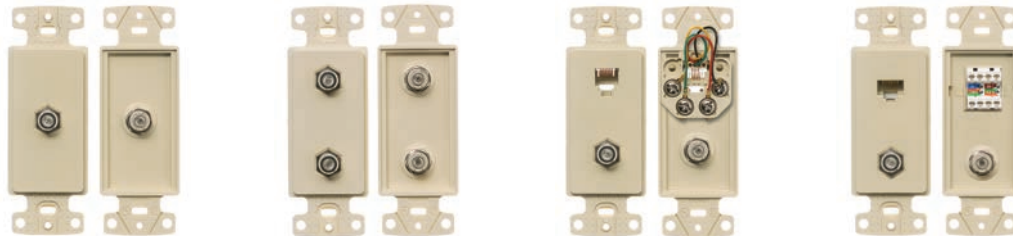

Description	Decorator Frame, Single F-Type Coupler Bulkhead, Female to Female	Decorator Frame, Duplex F-Type Coupler Bulkhead, Female to Female	Decorator Frame, One RJ11 Jack, 6-Position, 4-Conductor, One F-Type Coupler Bulkhead, Female to Female	Decorator Frame, One Cat. 5e 110 Punch-Down, One F-Type Coupler Bulkhead, Female to Female
Color	Screw Terminations	Screw Terminations	Screw Terminations	Screw Terminations
Black	—	—	—	<b>NS785BK</b>
Brown	—	—	—	<b>NS785</b>
Gray	—	—	—	<b>NS785GY</b>
Ivory	<b>NS780I</b>	<b>NS782I</b>	<b>NS783I</b>	<b>NS785I</b>
Light Almond	<b>NS780LA</b>	<b>NS782LA</b>	<b>NS783LA</b>	<b>NS785LA</b>
White	<b>NS780W</b>	<b>NS782W</b>	<b>NS783W</b>	<b>NS785W</b>



**Features**

Designed for voice, these devices provide an economical alternative to wall phone outlet placement.

- High impact-resistant thermoplastic plate
- Convenient screw down terminals
- Meets FCC part 68
- UL Listed 1863 - Communication Circuit Accessory and CSA Certified

**Molded-In Plates for Voice**



1-Gang Plate,  
One RJ11 Jack,  
6-Position, 4-Conductor,  
Screw Terminations



1-Gang Plate,  
One RJ11 Jack,  
6-Position, 6-Conductor,  
Screw Terminations



1-Gang Plate,  
Duplex RJ11 Jacks,  
6-Position, 4-Conductor,  
Screw Terminations



1-Gang Plate,  
Duplex RJ11 Jacks,  
6-Position, 6-Conductor,  
Screw Terminations

Description	1-Gang Plate, One RJ11 Jack, 6-Position, 4-Conductor, Screw Terminations		1-Gang Plate, One RJ11 Jack, 6-Position, 6-Conductor, Screw Terminations		1-Gang Plate, Duplex RJ11 Jacks, 6-Position, 4-Conductor, Screw Terminations		1-Gang Plate, Duplex RJ11 Jacks, 6-Position, 6-Conductor, Screw Terminations	
Color	Standard	Mid-Size	Standard	Standard	Mid-Size	Standard	Mid-Size	Standard
Brown	<b>NS730</b>	<b>NS735</b>	<b>NS732</b>	—	—	—	—	—
Ivory	<b>NS730I</b>	<b>NS735I</b>	<b>NS732I</b>	<b>NS742I</b>	<b>NS745I</b>	<b>NS744I</b>	—	—
Light Almond	<b>NS730LA</b>	<b>NS735LA</b>	<b>NS732LA</b>	<b>NS742LA</b>	—	—	—	—
White	<b>NS730W</b>	<b>NS735W</b>	<b>NS732W</b>	<b>NS742W</b>	<b>NS745W</b>	<b>NS744W</b>	—	<b>NS744W</b>

**Molded-In Plates for Voice and CATV/Satellite**



1-Gang Plate,  
One F-Type Coupler Bulkhead,  
Female to Female,  
One RJ11 Jack,  
6-Position, 6-Conductor



1-Gang Plate,  
One F-Type Coupler Bulkhead,  
Female to Female,  
One RJ11 Jack,  
6-Position, 4-Conductor



1-Gang Plate,  
One F-Type Coupler Bulkhead,  
Female to Female



1-Gang Plate,  
Duplex F-Type Coupler Bulkhead,  
Female to Female

Description	1-Gang Plate, One F-Type Coupler Bulkhead, Female to Female, One RJ11 Jack, 6-Position, 6-Conductor		1-Gang Plate, One F-Type Coupler Bulkhead, Female to Female, One RJ11 Jack, 6-Position, 4-Conductor		1-Gang Plate, One F-Type Coupler Bulkhead, Female to Female		1-Gang Plate, Duplex F-Type Coupler Bulkhead, Female to Female	
Color	Standard	Mid-Size	Standard	Standard	Mid-Size	Standard	Mid-Size	Standard
Ivory	<b>NS748I</b>	<b>NS755I</b>	<b>NS747I</b>	<b>NS750I</b>	<b>NS751I</b>	<b>NS752I</b>	—	—
Light Almond	<b>NS748LA</b>	<b>NS755LA</b>	<b>NS747LA</b>	<b>NS750LA</b>	<b>NS751LA</b>	<b>NS752LA</b>	—	—
White	<b>NS748W</b>	<b>NS755W</b>	<b>NS747W</b>	<b>NS750W</b>	<b>NS751W</b>	<b>NS752W</b>	—	—



1-Gang Plate,  
One Cat. 5e 110 Punch-Down  
One RJ11 Jack,  
6-Position, 4-Conductor  
One F-Type Coupler Bulkhead,  
Female to Female

Description	1-Gang Plate, One Cat. 5e 110 Punch-Down, One RJ11 Jack, 6-Position, 4-Conductor, One F-Type Coupler Bulkhead, Female to Female	
Color	Standard	
Black	<b>NS790BK</b>	
Brown	<b>NS790</b>	
Gray	<b>NS790GY</b>	
Ivory	<b>NS790I</b>	
Light Almond	<b>NS790LA</b>	
White	<b>NS790W</b>	



**Features**

Designed for voice applications, these jacks provide an economical alternative to basic wall mount and performance needs.

- Available in high impact-resistant thermoplastic or stainless steel
- Meets FCC part 68
- UL Listed 1863 - Communication Circuit Accessory and CSA Certified

**Telephone Wall Jacks**

Description	Wall Phone Jack Quick Connect, 6-Position, 4-Conductor, Punch-Down Termination Tool Included	Wall Phone Jack, 6-Position, 4-Conductor, Screw Terminations	Wall Phone Jack, 6-Position, 6-Conductor, Screw Terminations
Ivory	<b>NS721I</b>	<b>NS722I</b>	<b>NS725I</b>
Light Almond	—	—	<b>NS725LA</b>
White	<b>NS721W</b>	<b>NS722W</b>	<b>NS725W</b>
Description	Wall Phone Jack Quick Connect, 6-Position, 4-Conductor, Punch-Down Termination Tool Included	Wall Phone Jack, 6-Position, 4-Conductor, Screw Terminations	
Stainless Steel	<b>NS723SS</b>	<b>NS726SS</b>	

**Features**

Telephone surface mount jacks are available in 4- or 6-conductor configurations for voice. Alternatively, multimedia surface mount boxes can be custom loaded for computer and media use.

- High impact-resistant thermoplastic
- Mounts using screws or double sided tape (both included)
- Meets FCC part 68
- UL Listed 1863 - Communication Circuit Accessory and CSA Certified

**Telephone Wall Jacks**

Description	Telephone Surface Mount Jack, 6-Position, 4-Conductor, Screw Terminations	Telephone Surface Mount Jack, 6-Position, 6-Conductor, Screw Terminations	Multimedia 1-Port Surface Mount Box, Jack Not Included	Multimedia 2-Port Surface Mount Box, Jacks Not Included
Ivory	<b>NS760I</b>	<b>NS761I</b>	<b>ISB1E1*</b>	<b>ISB2E1*</b>
White	<b>NS760W</b>	<b>NS761W</b>	<b>ISB1W*</b>	<b>ISB2W*</b>

Note: \*cULus Listed 1863 - Communication Circuit Accessory. See page W-22 for snap fit multimedia jacks and AV connectors.