


Terminal Block Markers

Specially-designed narrow-width markers. LabelMark™ 5 Software or the Brady Mobile App can auto-serialize these labels to save you time.



Diagram	Catalog #	Color	Label Dimensions		Labels/Roll
			A Inch (mm)	B Inch (mm)	
B-498 – Vinyl Cloth					
Fig. 33	MC-240-498	BK on WT	0.240 (6.09)	16 ft. (4.87 m)	1
Fig. 33	MC-318-498	BK on WT	0.318 (8.07)	16 ft. (4.87 m)	1
Fig. 33	MC-375-498	BK on WT	0.375 (9.52)	16 ft. (4.87 m)	1

 Figure 33



PermaSleeve® PS Wire Marking Sleeves

These heat-shrink sleeves are the ultimate in marker durability, permanence and aesthetic appearance. Fast shrink rate saves time and costs during installation. Available as individual die-cut markers or continuous cut-to-length tubing.



Diagram	Catalog #	Color	Label Dimensions		Wire Gauge	Max. Wire Diameter	Labels/Roll
			A Inch (mm)	B Inch (mm)			
B-342 – PermaSleeve® PS Wire Marking Sleeve							
Fig. 58	MC-125-342	BK on WT	0.235 (5.97)	7 ft (2.13 m)	22 - 16 Gauge	0.046 - 0.110 (1.20 - 2.80 mm)	1
Fig. 58	MC-125-342-YL	BK on YL	0.235 (5.97)	7 ft (2.13 m)	22 - 16 Gauge	0.046 - 0.110 (1.20 - 2.80 mm)	1
Fig. 58	MC-187-342	BK on WT	0.335 (8.51)	7 ft (2.13 m)	20 - 10 Gauge	0.062 - 0.150 (1.60 - 3.80 mm)	1
Fig. 58	MC-187-342-YL	BK on YL	0.335 (8.51)	7 ft (2.13 m)	20 - 10 Gauge	0.062 - 0.150 (1.60 - 3.80 mm)	1
Fig. 58	MC-250-342	BK on WT	0.439 (11.15)	7 ft (2.13 m)	16 - 8 Gauge	0.094 - 0.215 (2.40 - 5.50 mm)	1
Fig. 58	MC-250-342-YL	BK on YL	0.439 (11.15)	7 ft (2.13 m)	16 - 8 Gauge	0.094 - 0.215 (2.40 - 5.50 mm)	1
Fig. 58	MC-375-342	BK on WT	0.645 (16.38)	7 ft (2.13 m)	12 - 4 Gauge	0.125 - 0.320 (3.20 - 8.10 mm)	1
Fig. 38	M-125-1-342	BK on WT	1.015 (25.78)	0.235 (5.96)	22 - 16 Gauge	0.046 - 0.110 (1.20 - 2.80 mm)	80
Fig. 38	M-187-1-342	BK on WT	1.015 (25.78)	0.335 (8.50)	20 - 10 Gauge	0.062 - 0.150 (1.60 - 3.80 mm)	80
Fig. 38	M-250-1-342	BK on WT	1.015 (25.78)	0.439 (11.15)	16 - 8 Gauge	0.094 - 0.215 (2.40 - 5.50 mm)	80
Fig. 38	M-375-1-342	BK on WT	1.015 (25.78)	0.645 (16.38)	12 - 4 Gauge	0.125 - 0.320 (3.20 - 8.10 mm)	80

* Wire gauge based on AWG for THHN wire.

Figure 58


 


Figure 38

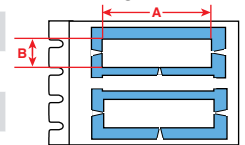

Wrap Around Wire & Cable Markers

Durable vinyl cloth wrap around wire and cable markers made with an adhesive that allows the markers to be removed cleanly and reapplied if necessary.

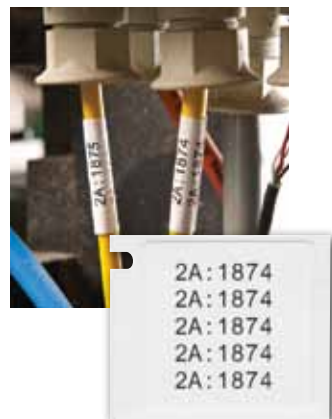


Diagram	Catalog #	Color	Label Dimensions		Wire Gauge	Max. Wire Diameter	Labels/Roll
			A Inch (mm)	B Inch (mm)			
B-498 – Vinyl Cloth							
Fig. 29	M-7-498	BK on WT	0.500 (12.70)	0.500 (12.70)	22 - 16 Gauge	0.110" (2.80 mm)	240
Fig. 29	M-11-498	BK on WT	0.500 (12.70)	0.750 (19.05)	16 - 10 Gauge	0.160" (4.00 mm)	220
Fig. 29	M-163-498	BK on WT	0.500 (12.70)	1.000 (25.40)	12 - 10 Gauge	0.210" (5.00 mm)	180
Fig. 29	M-18-498	BK on WT	0.750 (19.05)	1.000 (25.40)	12 - 10 Gauge	0.210" (5.00 mm)	180
Fig. 29	M-19-498	BK on WT	1.000 (25.40)	1.000 (25.40)	12 - 10 Gauge	0.210" (5.00 mm)	160
Fig. 29	M-31-498	BK on WT	1.000 (25.40)	1.500 (38.10)	10 - 4 Gauge	0.270" (7.00 mm)	160

Figure 29

