

Control Panel and Electrical Panel Labels

Long-lasting, durable materials to quickly identify control and electrical panels.

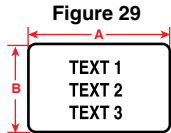


Figure 29

Figure 33

 


Diagram	Catalog #	Color	Label Dimensions		Labels/Roll
			A Inch (mm)	B Inch (mm)	
B-428 – Metallized Polyester					
Fig. 29	M-17-428	BK on SV	1.000 (25.40)	0.500 (12.70)	360
Fig. 29	M-29-428	BK on SV	1.500 (38.10)	0.500 (12.70)	360
Fig. 29	M-20-428	BK on SV	2.000 (50.80)	1.000 (25.40)	80
B-595 – Indoor / Outdoor Vinyl Tape					
Fig. 33	MC-1500-595-WT-BK	BK on WT	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-YL-BK	BK on YL	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-OR-BK	BK on OR	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-BL-WT	WT on BL	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-RD-WT	WT on RD	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-GN-WT	WT on GN	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-WT-RD	RD on WT	1.500 (38.10)	25 ft. (7.62 m)	1
Fig. 33	MC-1500-595-CL-BK	BK on CL	1.500 (38.10)	20 ft. (6.09 m)	1

* For additional general purpose tapes, refer to the Indoor/Outdoor Grade Facility and Safety Labels on page 13.



Get the Job Done Faster with BMP®53 Label Maker Accessories

We have a variety of accessories to speed up the label making process:

- Magnet to apply printer to panel doors, metal ladders or any metal surface
- Li-Ion Battery allows you to print over 3,000 labels on a single charge
- Wireless, Ethernet, USB or Bluetooth options give you the flexibility to network your printer however you'd like

Rough Surface Labels

Ideal for marking texturized or rough surfaces. Available in die-cut pieces or continuous rolls.

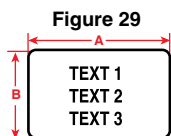


Figure 29

Figure 33



Diagram	Catalog #	Color	Label Dimensions		Labels/Roll
			A Inch (mm)	B Inch (mm)	
B-422 – Gloss Polyester					
Fig. 33	MC-375-422	BK on WT	0.375 (9.53)	25 ft. (7.60 m)	1
Fig. 33	MC-475-422	BK on WT	0.475 (12.07)	25 ft. (7.60 m)	1
Fig. 29	M-7-422	BK on WT	0.500 (12.70)	0.500 (12.70)	280
Fig. 33	MC-500-422	BK on WT	0.500 (12.70)	25 ft. (7.60 m)	1
Fig. 29	M-17-422	BK on WT	1.000 (25.40)	0.500 (12.70)	360
Fig. 29	M-19-422	BK on WT	1.000 (25.40)	1.000 (25.40)	200
Fig. 33	MC-1000-422	BK on WT	1.000 (25.40)	25 ft. (7.60 m)	1
Fig. 29	M-30-422	BK on WT	1.500 (38.10)	0.750 (19.05)	200
Fig. 29	M-29-422	BK on WT	1.500 (38.10)	0.500 (12.70)	360