



**HUBBELL**  
**Advantage**

- Available in Various Depth Rails
- Quick and Easy Assembly
- Universal Mounting Hole Pattern
- Minimal Packaging Reduces Construction Site Waste

**FEATURES**

- Stabilized top angles, excellent for ladder rack mounting
- Rugged construction
- Universal side mounting hole pattern
- Pre-threaded mounting holes, paint free
- Equipment mounting screws with tapered tip
- Rack unit identifiers
  - 2-post racks: RU numbered and divided
  - 4-post racks: rack units lined
- #12-24 tapped mounting rails (front and back) EIA-310-D universal pattern

**SPECIFICATIONS**

- Material:
  - 2-post racks: 6063-T2 aluminum
  - 4-post racks: cold rolled steel
- Finish: durable black powder coat or mill finish
- Weight capacity:
  - 2-post racks: 1,000lb when secured to floor
  - 4-post racks: 2,000lb when secured to floor
- Floor mount racks support 19" EIA-310-D rack-mount equipment
- UL Listed – 7N69 Communications Circuit Accessory

**STANDARDS**

- UL Listed 1863
- EIA-310-D Compliant


**HUBBELL**  
**NEXTFRAME** Equipment Racks



**3" Deep Rack**  
Recommended for Cat 5e/6 cables



**4-Post Rack**  
Recommended for mounting servers

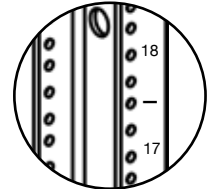

Rack unit identifiers simplify equipment installation

Compatible with Hubbell XXL and VS Series cable organizers

**NEXTFRAME**® Equipment Racks are available in 2- and 4-post. 2-post versions are available with depths of 3" and 6". **NEXTFRAME** racks provide an efficient method and structure for a variety of cross connect configurations. These racks are used in typical cross connect and data center applications to house patch panels, cable organizers, switches, and other network equipment. When used in conjunction with **NEXTFRAME** cable management accessories, these racks provide a solution for handling, routing, and organizing cable and optical fiber.

**APPLICATIONS**

- Use in data centers, equipment rooms and telecommunication rooms to provide racking, cable management, grounding and power distribution for network hardware.



**2-POST RACKS**

Rack ships unassembled.

Contents:

- 2 floor angles
- 2 top angles
- 2 vertical uprights
- 20 #12-24 x 5/8" equipment mounting screws
- 1 assembly hardware kit

Rack Units	Overall Height Inches (mm)	Overall Width Inches (mm)	Post Depth Inches (mm)	Hole Type	Color	Catalog No.
24	48" (1219)	20.2" (518)	3" (76)	#12-24 Threaded	Black	<b>HPW48RR19</b>
36	68.5" (1676)	20.2" (518)	3" (76)	#12-24 Threaded	Black	<b>HPW66RR19</b>
45	84" (2134)	20.2" (518)	3" (76)	#12-24 Threaded	Black	<b>HPW84RR19</b>
48	89.7" (2286)	20.2" (518)	3" (76)	#12-24 Threaded	Black	<b>HPW90RR19</b>
51	96" (2438)	20.2" (518)	3" (76)	#12-24 Threaded	Black	<b>HPW96RR19</b>
24	48" (1219)	24.2" (615)	3" (76)	#12-24 Threaded	Black	<b>HPW48RR23</b>
45	84" (2134)	24.2" (615)	3" (76)	#12-24 Threaded	Black	<b>HPW84RR23</b>
48	89.7" (2286)	24.2" (615)	3" (76)	#12-24 Threaded	Black	<b>HPW90RR23</b>
51	96" (2438)	24.2" (615)	3" (76)	#12-24 Threaded	Black	<b>HPW96RR23</b>
45	84" (2134)	20.2" (518)	6" (152)	#12-24 Threaded	Black	<b>HPW84RR19D</b>

Note: For mill (aluminum) finish rack, add "ML" to the end of catalog number.



HPW84RR19

**SERVER FRAME 4-POST RACKS**

Rack ships unassembled.

Contents:

- 4 cross members
- 4 depth members
- 4 vertical posts
- 50 mounting screws
- 1 assembly hardware kit

Rack Units	Overall Height Inches (mm)	Usable Height Inches (mm)	Overall Width Inches (mm)	Depth Inches (mm)	Hole Type	Color	Catalog No.
45	84" (2134)	79" (2007)	20.2" (513)	24" (610)	#12-24 Threaded	Black	<b>SF841924T</b>
45	84" (2134)	79" (2007)	20.2" (513)	29.23" (742)	#12-24 Threaded	Black	<b>SF841929T</b>
45	84" (2134)	79" (2007)	20.2" (513)	36" (914)	#12-24 Threaded	Black	<b>SF841936T</b>
45	84" (2134)	79" (2007)	20.2" (513)	24" (610)	M6 Square	Black	<b>SF841924</b>
45	84" (2134)	79" (2007)	20.2" (513)	29.23" (742)	M6 Square	Black	<b>SF841929</b>
45	84" (2134)	79" (2007)	20.2" (513)	36" (914)	M6 Square	Black	<b>SF841936</b>



SF841924T

**19" EQUIPMENT RACK WITH 6" WIDE Z-CHANNELS**

Seven-foot cable management rack with 6" wide vertical cable management organizers in a single catalog number for ease in ordering. Use when maximum cable volume is required. Products are available in both black and clear aluminum finishes. Rack ships unassembled.

Contents:

- 1 rack, 7'H (HPW84RR19)
- 2 vertical organizers (VS76/VS76A)

Rack Units	Rack Height, In. (mm)	Cover Style	Finish	Catalog No.
45	7" (2134)	Hinged	Black	<b>CS1976H</b>
45	7" (2134)	Clip on	Black	<b>CS1976</b>
45	7" (2134)	Clip on	Aluminum	<b>CS1976A</b>



CS1976A

**19" EQUIPMENT RACK WITH 3.25" WIDE C-CHANNELS**

Seven-foot cable management rack with 3.25" wide vertical cable management organizers in a single catalog number for ease in ordering. Use when space is limited. Products are available in both black and aluminum finishes. Rack ships unassembled.

Contents:

- 1 rack, 7'H (HPW84RR19)
- 2 vertical organizers (VS73/VS73A)
- 4 covers (VCC3/VCC3A)

Rack Units	Rack Height, In. (mm)	Finish	Cover Style	Catalog No.
45	7" (2134)	Black	Hinged	<b>CS1973H</b>
45	7" (2134)	Black	Clip on	<b>CS1973</b>
45	7" (2134)	Aluminum	Clip on	<b>CS1973A</b>



CS1973A