

LEDTASK™ 24VDC FLEXIBLE SUPER HIGH OUTPUT LED LINEAR RIBBON

GM Lighting's New LEDTask 24VDC Super High Output Flexible LED Ribbon may be the brightest flexible LED linear ribbon on the market. The intense light output is perfect for areas that demand a strong and energy efficient light source. Available in 2700K Warm White, 3500K Warm White or 4200K Natural White.



LTR1200-HO Ribbon Section



- 24VDC ▪ Dimmable ▪ No harmful UV rays
- 50,000 hr. LED life ▪ Cuttable in the field
- Even illumination ▪ Utilizes 3M double stick tape
- Connectors allow for multiple configurations



Catalog No.	Color	Total LED's	Watts	Amps per Reel	Lumens per ft.	Length	LED Life
LTR120024-HO-27	2700K Warm White	1200	.08W (5.85W per ft. 96W per reel)	4.0	314	5M (16.4')	50,000 hrs.
LTR120024-HO-35	3500K Warm White	1200	.08W (5.85W per ft. 96W per reel)	4.0	379	5M (16.4')	50,000 hrs.
LTR120024-HO-42	4200K Natural White	1200	.08W (5.85W per ft.) 96W per reel)	4.0	427	5M (16.4')	50,000 hrs.

Please see Quick Reference Guide on page 41 for maximum single runs. See page 61 for power supplies. Kelvin temperature (color) ± 200K.


Each length includes: (3) DTW-24 and (1) DTW-24 affixed at start of run. DTC Series ribbon to ribbon connectors are ordered separately.




LTR120024 LED Linear Ribbon Connectors and Accessories

DTC-1	Ribbon to ribbon connector
DTC-3	3" flexible ribbon to ribbon connector
DTC-12	12" flexible ribbon to ribbon connector
DTC-24	24" flexible ribbon to ribbon connector
DTC-48	48" flexible ribbon to ribbon connector
DTC-60	60" flexible ribbon to ribbon connector
DTW-6	6" flexible ribbon to power supply connector
DTW-24	24" flexible ribbon to power supply connector
DTW-60	60" flexible ribbon to power supply connector

LTR120024 LED Linear Ribbon Dimensions

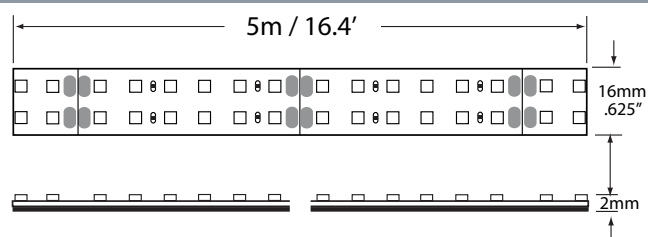

DTC Series

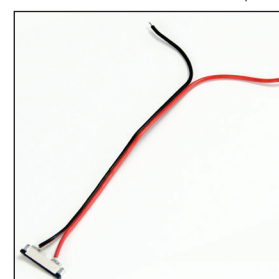

DTW Series