

### LED-CHL-45

PROJECT	TYPE
CATALOG NUMBER	

#### PRODUCT DESCRIPTION

Extruded angled aluminum channel with optional snap-on clear or frosted lens that provides a rigid, deep set linear mounting platform tilted at a 45° angle for the following GM Lighting LEDTask Flexible LED Linear Ribbons:

For the following LEDTask™ Flexible Linear Ribbon Series	
LTR60/300 Series	12VDC High Output - Dry and Wet location
LTR60/300-SO Series	12VDC Standard Output - Dry and Wet location
GM100-24 Series	24VDC Standard Output - Dry and Wet location
LTR30024 Series	24VDC High Output - Dry and Wet location
SLR Series	12VDC Standard Output - Damp location
LTR150-RGB Series	12VDC RGB Series - Dry location
LTR30/150RGB Series	12VDC RGB Series - Wet location

#### MOUNTING

Use LED-CHL-45-MC mounting clips (2) that are supplied with the channel. Flexible LED linear ribbon uses attached 3M mounting tape. Additional clips are available below. Use LED-CHL-45-EC endcaps for a finished look. Ordered separately.

#### LENS:


Can be used with or without clear or frosted diffusion lens. Ordered separately.

**NOTE: Channel may not accommodate ribbon to ribbon and ribbon to power supply connections. Please locate connections outside of channel interior.**

Accessories	
LED-CHL-45-CL-LENS	Clear lens for LED-CHL-45
LED-CHL-45-FR-LENS	Frosted lens for LED-CHL-45
LED-CHL-45-10-LENS	Clear focusing 10° spread lens for LED-CHL-45
LED-CHL-45-EC	Solid end caps (2) for LED-CHL-45
LED-CHL-45-EC-H	End caps with holes (2) for LED-CHL-45
LED-CHL-45-MC	Mounting clips (2)



PLEASE ALLOW THE FOLLOWING VISUAL CLEARANCE TO ALLOW FOR FLEXIBLE RIBBON TO RIBBON CONNECTORS

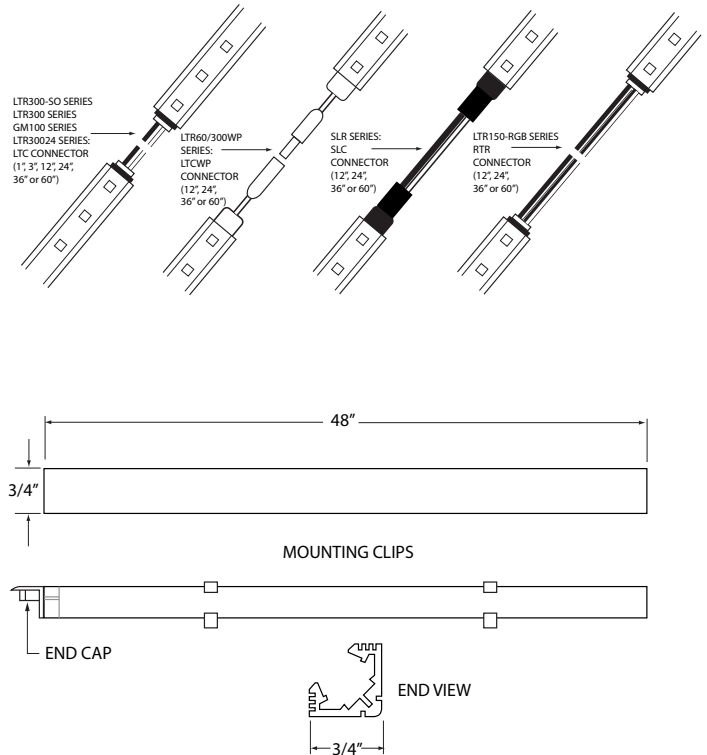

Model Number	Description	Length	Height	Width	Finish
LED-CHL-45	45° angled architectural aluminum channel	48"	3/4"	3/4"	Brushed Aluminum