

**12VDC LED
ELECTRONIC DIMMABLE
20W CLASS 2 POWER
SUPPLY**
by **GM Lighting**

Project: _____

Type: _____

Location: _____

Contact Phone: _____

PRODUCT DESCRIPTION


Hardwire 12VDC LED dimming power supply that works with conventional low voltage electronic wall mount dimmers.

PRODUCT SPECIFICATIONS

- **Output constant voltage 12VDC**
- **Universal AC input/ : 90-130 VAC**
- **Built-in active PFC function**
- **High efficiency : > 84%**
- **Protections: short circuit/over loading**
- **Full protection plastic housing, wiring covers secured with screws**
- **Easy installation**
- **Cooling by free air convection**
- **Works with leading edge and trailing edge TRIAC dimmers**
- **Strong compatibility, flicker-free dimming**
- **Suitable for LED lighting applications**
- **Label: cETLus**
- **Warranty 5 years**



145*55*19.5mm (L*W*H)

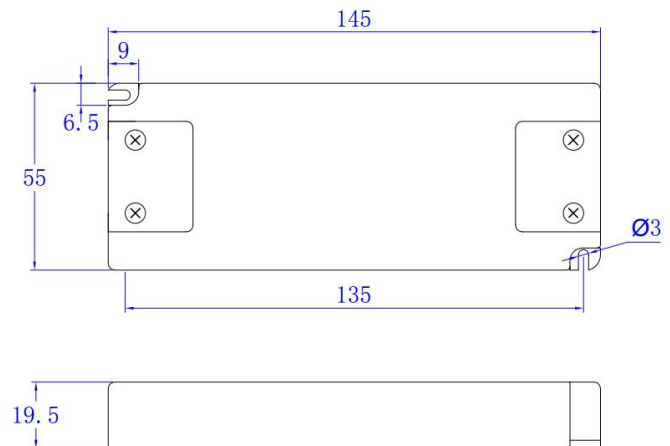

Catalog Number	Max. Wattage	Input Voltage	Output Voltage	Input current	output current	Weight	Dimensions		
							L	W	H
LTHE-20-DIM-12	20W	120V/60Hz	12 VDC	0.16A	1.67A MAX	.41 lbs.	5.75"	2.30"	.80 "

For voltage drop - see www.gmlighting.net/voltagedrop.html or consult GM Lighting 2015 New Product Product Brochure, page .



GM Lighting, LLC • 9830 W. 190th St. • Unit F • Mokena, IL 60448
Toll-Free: (866) 671-0811 FAX: (708) 478-2640 • www.gmlighting.net
e-mail: sales@gmlighting.net • Specifications subject to change without notice. **LTHE-20-DIM-12_092415**