


# LEDTASK MINI LED DIMMABLE RECESSED DOWNLIGHT

GM Lighting introduces a mini-recessed, shallow mount (1-3/8") downlight in a compact, 12VDC luminaire. Perfect as a mini downlight or puck, this tiny fixture works well in book shelves, entertainment centers, marine and aircraft, or anywhere that discreet, shallow mount lighting is required.

GMR-3WW-BA

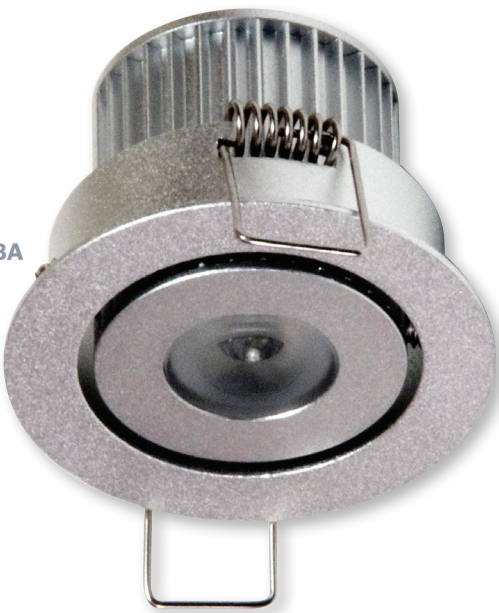


- 3W flush mounted LED lamp
- Dimmable utilizing GM Lighting 12VDC Dimmable Power Supplies
- Warm white 3500K
- For use with remote power supply
- 72" wire leads and steel mounting springs
- ETL listed for interior use only

Catalog No.	Color	Total LED's	Wattage	Lumens	Finish	LED Life
GMR-3WW-W	3500K	1	3W	110	White	50,000 hrs.
GMR-3WW-B	3500K	1	3W	110	Black	50,000 hrs.
GMR-3WW-BA	3500K	1	3W	110	Brushed Aluminum	50,000 hrs.

Kelvin temperature (color) ± 200K.

## Mini LED Adjustable Recessed Downlight Accessories

- GMSB-W** Splice box - white - 2"L x 1"W x 5/8"D
- GMSB-B** Splice box - black - 2"L x 1"W x 5/8"D

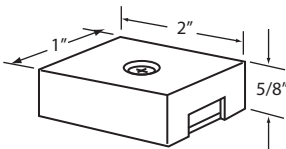

## Mini LED Adjustable Recessed Downlight Dimensions

