

**12VDC LED ELECTRONIC  
25W PLUG-IN POWER SUPPLY**  
by  
**GMLighting**

Project: \_\_\_\_\_

Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact Phone: \_\_\_\_\_

**PRODUCT DESCRIPTION**

LED electronic Class II power supply with 2 prong cord and plug with inline on/off switch. 12 VDC output. 120 AC input. Includes 18" DC jack.


**PRODUCT SPECIFICATIONS**

**Construction:** Power supply is in a fully enclosed plastic case. Standard type P1M plug. LED indicator for power on.

**Electrical:** Output voltage 12 VDC. Short circuit, overload, over voltage and over temperature protections. 126" 2 prong cord and plug with inline on/off switch. 2 amps

**Label:** UL listed.

Not rated for outdoor use.

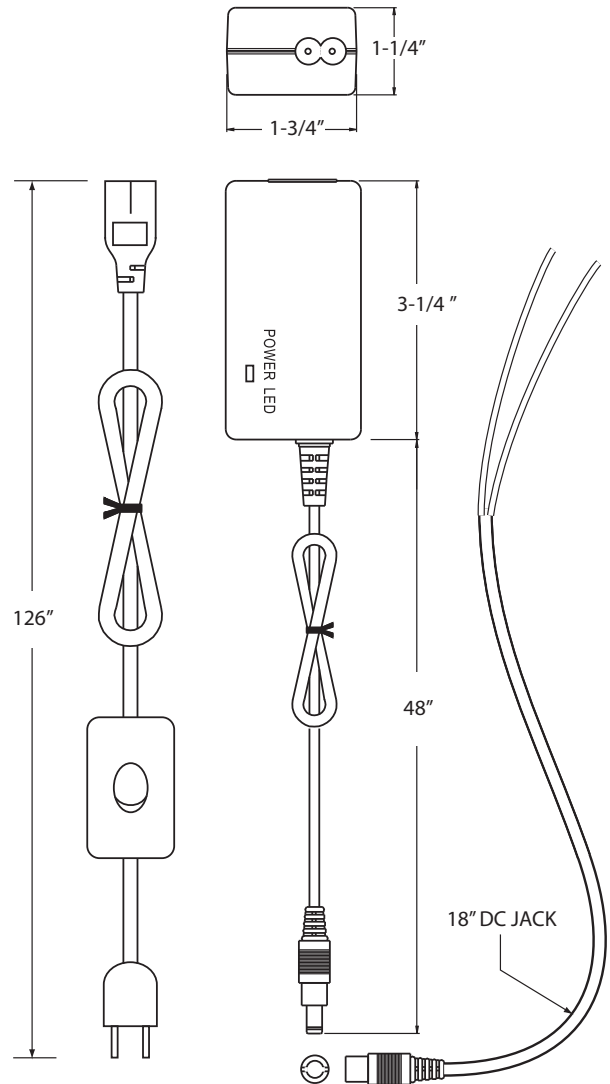

Catalog Number	Max. Wattage	Input Voltage	Amps	Output Voltage	Weight	Dimensions		
						L	W	H
LTP-2	25W	120V	2.0	12 VDC	10.4 oz.	3-1/4"	1-3/4"	1-1/4"

NOTE: For 12V Voltage Drop - Please see our website: [www.gmlighting.net/products/12vdc-electronic-led-power-supplies](http://www.gmlighting.net/products/12vdc-electronic-led-power-supplies). Or see page 30 in GM Lighting's 2013 Product Catalog.

**GMLighting**

GM Lighting, LLC • 9830 W. 190th St. • Unit F • Mokena, IL 60448  
Toll-Free: (866) 671-0811 FAX: (708) 478-2640 • [www.gmlighting.net](http://www.gmlighting.net)  
Specifications subject to change without notice. LTP-2\_072913