

**12VDC LED ELECTRONIC
50W PLUG-IN POWER SUPPLY**
by
GM Lighting

Project: _____
Type: _____
Location: _____
Contact Phone: _____

PRODUCT DESCRIPTION

LED electronic Class II power supply with 2 prong cord and plug with inline on/off switch. 12 VDC output. 120 AC input. Includes 18" DC jack.


PRODUCT SPECIFICATIONS

Construction: Power supply is in a fully enclosed plastic case. Standard type P1M plug. LED indicator for power on.

Electrical: Output voltage 12 VDC. Short circuit, overload, over voltage and over temperature protections. 126" 2 prong cord and plug with inline on/off switch. 5 amps.

Label: ETL listed.

Not rated for outdoor use.

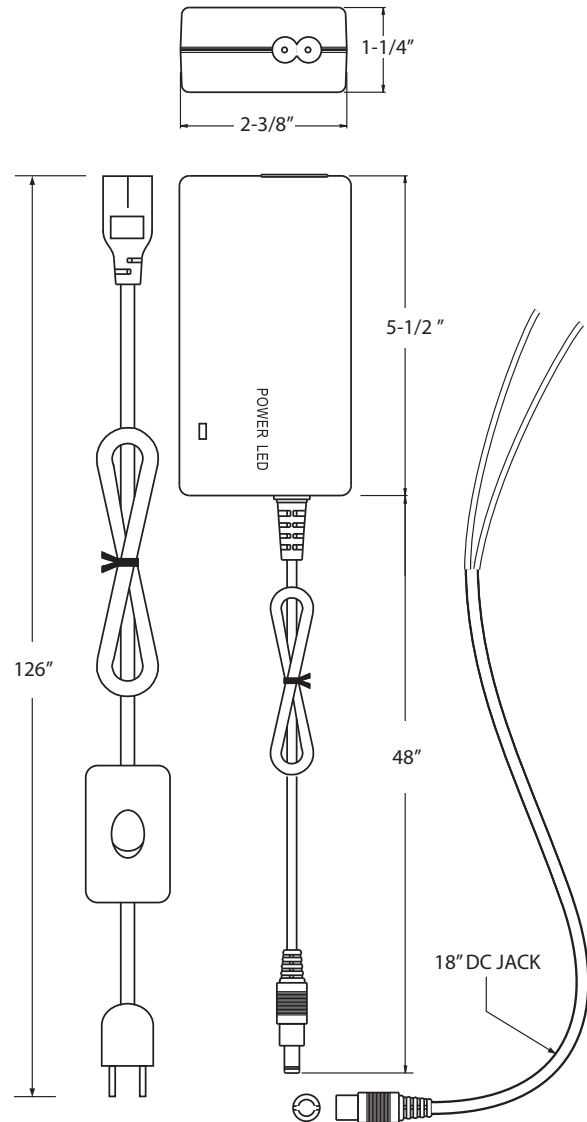

Catalog Number	Max. Wattage	Input Voltage	Amps	Output Voltage	Weight	Dimensions		
						L	W	H
LTP-6	50W	120V	5.0	12 VDC	14.8 oz.	5-1/2"	2-1/4"	1-1/4"

NOTE: For 12V Voltage Drop - Please see our website: <http://www.gmlighting.net/products/12vdc-electronic-led-power-supplies> and click on 12VDC Voltage Drop Chart on the left sidebar, or see page 67 in GM Lighting's 2013 Product Catalog



GM Lighting, LLC • 9830 W. 190th St. • Unit F • Mokena, IL 60448
Toll-Free: (866) 671-0811 FAX: (708) 478-2640 • www.gmlighting.net
Specifications subject to change without notice. LTP-6_090213

