

SLR SERIES 12VDC SILICONE DAMP LOCATION FLEXIBLE LED LINEAR RIBBON

GM Lighting's Silicone Damp Location Flexible LED Ribbon is unique as it is available in 4 different lengths that allow for a variety of different length runs and sophisticated designs. This 4 pin connectable system is "THE" installer's choice. Available in 8", 16", 24" and 118" lengths, this product can be incorporated into any style of lighting design.



4 pin system insures a solid connection.

- Dimmable ▪ No harmful UV rays
- 50,000 hr. LED life
- Cuttable every 3 LED's
- Even illumination
- Utilizes 3M double stick tape
- Accessories allow for multiple configurations



Catalog No.	Color	Total LED's	LED Watts	Amps per Length	Lumens per ft.	Length	LED Life
SLR8-SO-27	2700K - Warm White	12	.08W (1.52W per ft.)	0.08	80	8"	50,000 hrs.
SLR16-SO-27	2700K - Warm White	24	.08W (1.52W per ft.)	0.16	80	16"	50,000 hrs.
SLR24-SO-27	2700K - Warm White	36	.08W (1.52W per ft.)	0.24	80	24"	50,000 hrs.
SLR118-SO-27*	2700K - Warm White	180	.08W (1.52W per ft.)	1.20	80	118"	50,000 hrs.
SLR8-SO-WW	3500K - Warm White	12	.08W (1.52W per ft.)	0.08	95	8"	50,000 hrs.
SLR16-SO-WW	3500K - Warm White	24	.08W (1.52W per ft.)	0.16	95	16"	50,000 hrs.
SLR24-SO-WW	3500K - Warm White	36	.08W (1.52W per ft.)	0.24	95	24"	50,000 hrs.
SLR118-SO-WW*	3500K - Warm White	180	.08W (1.52W per ft.)	1.20	95	118"	50,000 hrs.
SLR8-SO-PW	5500K - Pure White	12	.08W (1.52W per ft.)	0.08	125	8"	50,000 hrs.
SLR16-SO-PW	5500K - Pure White	24	.08W (1.52W per ft.)	0.16	125	16"	50,000 hrs.
SLR24-SO-PW	5500K - Pure White	36	.08W (1.52W per ft.)	0.24	125	24"	50,000 hrs.
SLR118-SO-PW*	5500K - Pure White	180	.08W (1.52W per ft.)	1.20	125	118"	50,000 hrs.


* Includes (1) SLW-24 ribbon to power supply connector. Kelvin temperature (color) $\pm 200K$. Please see Quick Reference Guide on page 30 for maximum single runs. See page 61 for power supplies. **NOTE: The piece of ribbon left over from your cut CANNOT be used. Keep this in mind when designing the layout.**

Each length includes: (1) SLR-FEC, (1) SLR-MEC and (1) SLR-CEC. SLW Series ribbon to power supply connectors are ordered separately except when ordering the SLR118-SO lengths which also includes (1) SLW-24 ribbon to power supply connector.





Damp Location LED Linear Ribbon Connectors and Accessories

SLW-24	24" flexible ribbon to power supply connector
SLW-48	48" flexible ribbon to power supply connector
SLW-60	60" flexible ribbon to power supply connector
SLC-3	3" flexible ribbon to ribbon connector
SLC-12	12" flexible ribbon to ribbon connector
SLC-24	24" flexible ribbon to ribbon connector
SLC-36	36" flexible ribbon to ribbon connector
SLC-60	60" flexible ribbon to ribbon connector
SLR-L	'L' connector - 90° ribbon to ribbon
SLR-T	'T' connector - ribbon to ribbon
SLR-CEC	Cut end cap - for capping cut end of ribbon
SLR-FEC	Female end cap
SLR-MEC	Male end cap
SLR-MC	1 pair of mounting clips with screws
GMSB-W	Splice box - white 2"L x 1"W x 5/8"D
GMSB-B	Splice box - black 2"L x 1"W x 5/8"D

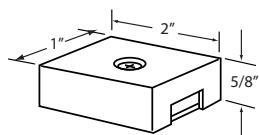

Damp Location LED Linear Ribbon Dimensions

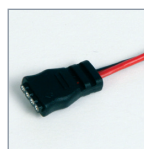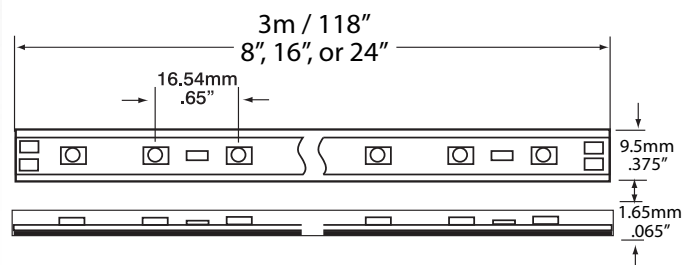

SLW



SLC



SLR-L



SLR-T



SLR-CEC



SLR-MC

See page 43 for aluminum mounting channel.