

12VDC LEDTASK™ STANDARD OUTPUT FLEXIBLE LED LINEAR RIBBON

PROJECT

TYPE

CATALOG NUMBER

PRODUCT DESCRIPTION

LEDTask is a flexible LED linear ribbon that conforms to straight, curved and irregular architectural coves, bannisters, recesses, and other constructs where even, energy saving LED illumination is specified. Available in a 5 meter (16'4") reel, LEDTask can be cut in the field to achieve virtually any custom installation. Available in , 2400K, 2700K*, 3000K*, 3500K*, 4200K*, 5500K* Pure White, Red, Blue, Green, Amber. and Purple.

PRODUCT SPECIFICATIONS

Construction: LEDTask is a flexible LED ribbon that conducts power via the LTW series ribbon to power supply connectors. Included in each reel are 3 LTW-24 connectors and 24" of lead affixed to start of reel. Cuttable every 3 diodes, (2").

Electrical: Each of the 300 LED's per reel (19 LED's per foot) are .08W, equaling 1.52 watts per foot. Total Amps per reel is 2. 50,000 hr. life.


Temperature: 2400K, 2700K, 3000K, 3500K, 4200K and 5500K.

Power Supplies: See chart at right for complete descriptions and catalog numbers.

Dimming: Yes with dimmable power supplies (see at right) utilizing low voltage magnetic on/off wall dimmer (by others).

Mounting: 3M double stick mounting tape pre-affixed to LEDTask Flexible Ribbon.

Label: ETL American Lighting Association

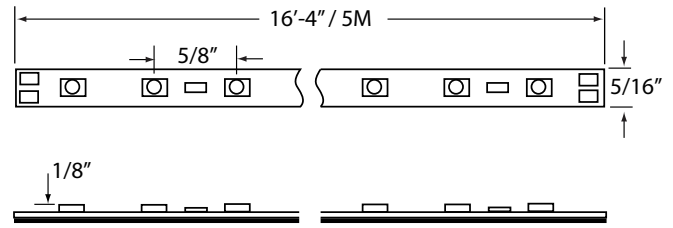

12VDC ELECTRONIC POWER SUPPLIES / DIMMABLE MAGNETIC POWER SUPPLIES

LTP-2	2A - Switchable - 120V Cord & Plug, Class II, 12VDC @ 2 amps. Electronic.
LTP-6	5A - Switchable - 120V Cord & Plug, Class II, 12VDC @ 5 amps. Electronic
LTH-2	2.1A - 12VDC, 25W Metal Chassis Hardwire. Screw Terminals.
LTH-4	4.2A - 12VDC, 50W Metal Chassis Hardwire. Screw Terminals.
LTH-8	8.5A - 12VDC, 100W Metal Chassis Hardwire. Screw Terminals and Mounting Feet. Electronic.
LTH-16	16.7A - 12VDC, 200W Metal Chassis Hardwire. Screw Terminals and Mounting Feet. Electronic
LTH-25	25A - 12VDC, 320W Metal Chassis Hardwire. Screw Terminals and Mounting Feet. Electronic.
LTFD-60	12VDC, 60W, Dimmable Class II, 120V Cord and Plug
LTF-60-12	12VDC, 60W, Dimmable Class II, 120VAC Input, 6 Standard Knockouts
LTF-100-12	12VDC, 100W, Dimmable, 120VAC Input, 6 Standard Knockouts
LTF200-12	12VDC, 200W, Dimmable, 120VAC Input, 6 Standard Knockouts
LTF300-12	12VDC, 300W, Dimmable, 120VAC Input, 6 Standard Knockouts
LTHM50-DIM	Dimmable - Primary: 120VAC, 60Hz, 0.33A Secondary: 12VAC, 12VDC, 4A Max. 50W
LTH-60-DIM	Dimmable - Primary: 120VAC, 60Hz, 0.33A Secondary: 12V AC/DC, 12VDC, 4A Max. 60W
LTHM100-DIM	Dimmable - Input: 120VAC, 60Hz Output: 12VDC 8A Max. 100W, Nema 3 Enclosure
LTHM200-DIM	Dimmable - Primary: 120VAC, 60Hz, 16A Output: 12VDC, Max. 200W UL for indoor and outdoor use.
LTHM300-DIM	Dimmable - Input: 120VAC, 60Hz, 25A, Output: 12VDC, 300W, UL for indoor and outdoor use.
LTHM 150-CL2-DIM	Dimmable - Input: 120VAC, 60Hz, 3 circuit Class II Output: 12VDC x 3, 12A Max. 150W, UL for indoor and outdoor use.

Flexible LED Ribbon Connectors

LTC-1	Ribbon to ribbon connector
LTC-3	3" flexible ribbon to ribbon connector
LTC-12	12" flexible ribbon to ribbon connector
LTC-24	24" flexible ribbon to ribbon connector
LTC-36	36" flexible ribbon to ribbon connector
LTC-60	60" flexible ribbon to ribbon connector
LTC-T	3" flexible Ribbon to Ribbon T connector
LTW-6	6" flexible ribbon to power supply connector
LTW-24	24" flexible ribbon to power supply connector
LTW-48	48" flexible ribbon to power supply connector
LTW-60	60" flexible ribbon to power supply connector
STC-1	Sure Tite Ribbon To Ribbon Connector
STLK-60	60" Sure Tite Flexible Ribbon To Ribbon Connector
STW-60	60" Sure Tite Flexible Ribbon To Power Connector

Model Number	Length	Total LED's	LED Wattage	Total Amps	Lumens per Foot	Color Temp.*	LED Life
LTR300-SO-24	5M / 16'4"	300 (19/ft.)	.08W(1.52/FT.)	2.0	107	2400K	50,000hrs
LTR300-SO-27	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	111	2700k	50,000 hrs.
LTR300-SO-30	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	115	3000k	50,000 hrs.
LTR300-SO-WW	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	134	3500k	50,000 hrs.
LTR300-SO-42	5M / 16'4"	300(19/ft.)	.08W (1.52W/ft)	2.0	144	4200k	50,000 hrs.
LTR300-SO-PW	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	153	5500k	50,000 hrs.
LTR300-RD	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	9	Red	50,000 hrs.
LTR300-BL	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	12	Blue	50,000 hrs.
LTR300-GR	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	34	Green	50,000 hrs.
LTR300-AM	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	10	Amber	50,000 hrs.
LTR300-PR	5M / 16'4"	300 (19/ft.)	.08W (1.52W/ft.)	2.0	0.4	Purple Blacklight	50,000 hrs.

NOTES: Includes (3) LTW-24 Connectors and 24" of lead affixed at start of reel.

*Kelvin temperature (color) ± 200K. For GM Power Supply specs, voltage drop, etc., please see our website at www.gmlighting.net

©2013 GM Lighting
Specifications are subject to change without notice.

9830 W. 190th Street, Unit F
Mokena, IL 60448

Toll-Free: (866) 671-0811
FAX: (708) 478-2640

www.gmlighting.net
sales@gmlighting.net

LTR300_121814



Intertek