



SNAP²IT[®] Duplex Connectors with Insulated Throat

Zinc die-cast.

For AC • MCI-A • HCF steel and aluminum cable • Flexible metal conduit steel and aluminum (regular and reduced wall) • MCI cable • ACG90 • AC90.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
383810AST	10937	3/8	1/2	25	100	2.398	2.035	.840	.624 (2)	.370 - .490
404010AST†	40533	3/8	1/2	25	100	2.398	2.165	.840	.624 (2)	.405 - .612
505010AST	50720	1/2	3/4	25	25	3.054	2.717	1.058	.810 (2)	.590 - .920

†Provided with red tinted inside clips so you can tell the difference between a 383810AST to 404010AST .


Refer to chart on page E-22 for a list of cable types.

Refer to chart on page E-25 for MCI-A cable ranges.

Concrete tight when taped.

SNAP-TITE[®] and SNAP²IT[®] products have been tested and listed by UL in accordance with UL's ground fault requirements.

For additional information see page 6.

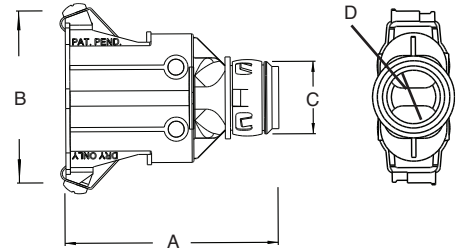

383810AST



404010AST

Secure hold – Easy cable insertion!
Simply snap the cable into the fitting and snap it into the box...no tools needed!
The screw only holds the clip in place.

FOR THE WIDEST TOTAL CABLE RANGES

Flex • AC • MC