


SNAP²IT[®] Connectors with Insulated Throat

Zinc die-cast.

For AC • MCI-A • HCF steel and aluminum cable • Flexible metal conduit steel and aluminum (regular and reduced wall) • MCI cable • ACG90 • AC90.



3810AST

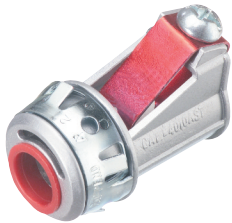

4010AST



5010AST



7510AST


CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	KO SIZE	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D	CABLE RANGE
3810AST	00385	3/8	1/2	50	500	1.473	1.179	.840	.316	.370 - .490
4010AST	40355	3/8	1/2	50	500	1.473	1.244	.840	.404	.405 - .612
5010AST	00517	1/2	1/2	25	250	2.210	1.514	.840	.614	.590 - .920
7510AST	55090	3/4	3/4	25	25	2.496	1.709	1.058	.828	.895 - 1.110

†Provided with red tinted inside clip so you can tell the between from a 3810AST to 4010AST.

Refer to chart on page E-22 for a list of cable types.
Refer to chart on page E-25 for MCI-A cable ranges.
Concrete tight when taped.

SNAP-TITE[®] and SNAP²IT[®] products have been tested and listed by UL in accordance with UL's ground fault requirements.

For additional information see page 6.

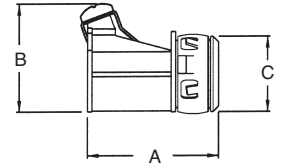

Features and Benefits

- Installs as fast and costs the same as our other SNAP²IT fittings, but cable insertion is even easier!
- Simply snap the cable into the fitting and snap it into the box... no tools needed! The screw only holds the clip in place.
- Widest cable ranges – accommodates cable from 14/2 to 10/4.
- Super-secure – the angled, two-prong clip locks down on MC cable so there's no chance of pullout.
- Cable is removable. Simply loosen the screw on top.

Easy cable insertion – Tight, secure hold!

Top View
Clip holds cable firmly in place

Back View
Note angled, two-prong clip

FOR THE WIDEST TOTAL CABLE RANGES