

## ONE-BOX™ Side Mount Vapor Boxes for Fixtures

Economical L-shaped fan/fixture boxes mount securely to joist with a shipped-in-place center screw.



FB442F



FB442FD

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	DESCRIPTION/ CU. IN.	UNIT PKG	STD PKG	DIM A	DIM B	DIM C	DIM D
FB442F	76220	Joist Mount Single Drywall/ 15.5	25	25	4.240	3.885	.562	2.948
FB443F	76222	Fan or Fixture Single Drywall/ 18.8	25	25	4.240	5.183	.562	4.246
FB442FD*	76221	Joist Mount Double Drywall / 25.0	25	25	4.227	4.635	1.312	2.948
FB443FD*	76223	Fan or Fixture Double Drywall / 28.5	25	25	4.227	5.933	1.312	4.246


\* For use with double drywall installation.

Add suffix "GC" to Catalog # when ordering in Canada, for example FB442FGC.

Refer to chart on page R-18 for load ratings and number of single conductors.

Refer to Q-3 for additional Vapor Boxes.

**PATENTED.**

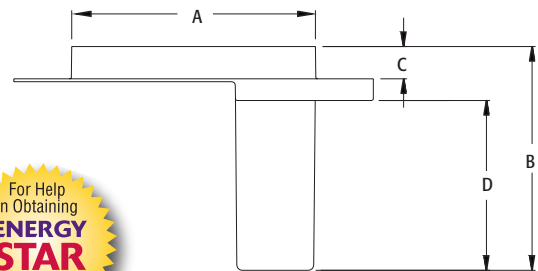

### FEATURES AND BENEFITS

- Fast and easy to install
- Mounts directly to a wood or steel stud for a super secure installation
- Flange forms a protective barrier against air infiltration
- UL Ratings: 70 lb fan/200 lb fixture; CSA: 50 lb fan or fixture