


# MORE! for New Work and Retrofit SNAP2IT® MC Cable Connectors

Made in USA 


*Easy to Install. Snap onto cable, snap into box • No Tools!*

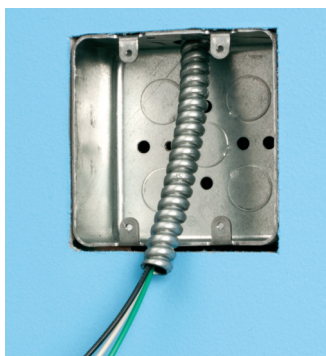


Pull MC cable through knockout in installed old work box.



38RAST with insulated throat

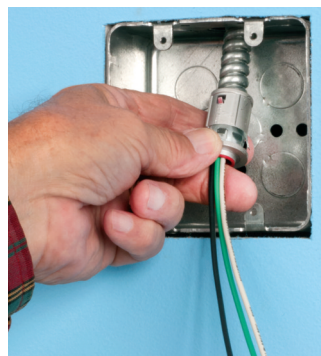

Push assembly into box...

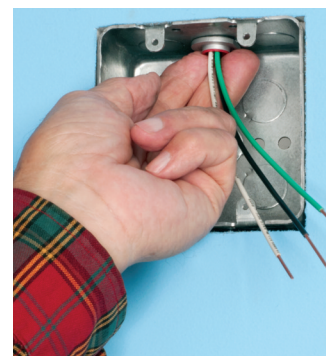

...snapping it into the box.  
Fast and easy. No tools required!


38RAST




Front



Back

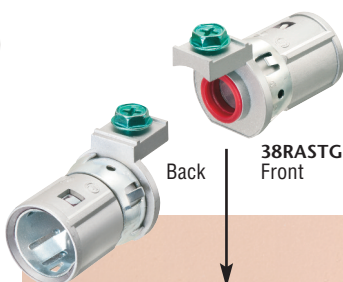

38RASTG Front

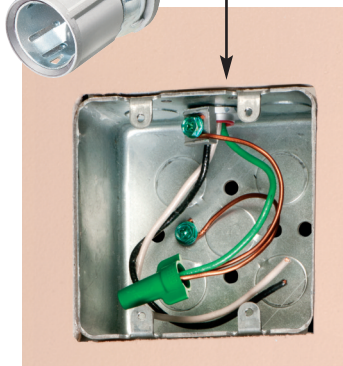

## Snap2It® Connectors with insulated throat for New Work and Retrofit

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997
<b>38RAST</b>	13586
for NEW WORK or RETROFIT	
<b>38RASTG</b>	13588
with built-in ground for NEW WORK or RETROFIT	

CABLE TYPE	DIAMETER RANGE	CABLE RANGE	UNIT PKG	STD PKG
<b>MC/HCF/AC</b> Steel & Aluminum	.405 to .605	14/2 and 12/2	25	25
<b>MCI-A</b> Steel & Aluminum	.440 to .550	w/ and w/o ground	25	25
<b>AC90, ACG90</b>	.440 to .550	14/3, 14/4, 12/3, 12/4, 10/2, 10/3		
<b>Flexible Metal Conduit</b> Steel & Aluminum (RWFMC)	3/8" Flex*			

\*CSA Listed w/ anti-short bushing ONLY

## Tinted red inside fitting


CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997
<b>40RAST</b>	13587
for NEW WORK or RETROFIT	
<b>40RASTG</b>	22091
with built-in ground for NEW WORK or RETROFIT	

CABLE TYPE	DIAMETER RANGE	CABLE RANGE	UNIT PKG	STD PKG
<b>MC/HCF/AC</b> Steel & Aluminum	.485 to .610	14/3, 12/2 and 12/3	25	25
<b>MCI-A</b> Steel & Aluminum	.480 to .580	w/ and w/o ground	25	25
<b>AC90, ACG90</b>	.480 to .550	14/4, 12/4, 10/2, 10/3		
<b>Flexible Metal Conduit</b> Steel & Aluminum (RWFMC)	3/8" Flex*			

\*CSA Listed w/ anti-short bushing ONLY



**Arlington**  
1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
www.aifittings.com

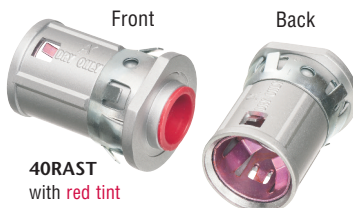

40RAST with red tint



40RASTG with red tint

Distributed by

Patent pending