


QuickPort® BNC Bulkhead Modules & Blank Modules

APPLICATION

QuickPort BNC Bulkhead Modules feature nickel or gold-plated female-to-female connectors with twist-on front and rear connections. The pass-through design is ideal for high-end video, home theater, CCTV and LAN applications. Cable: shielded video and data cable, 50 Ohm. You can fill unused QuickPort openings with QuickPort blank modules.

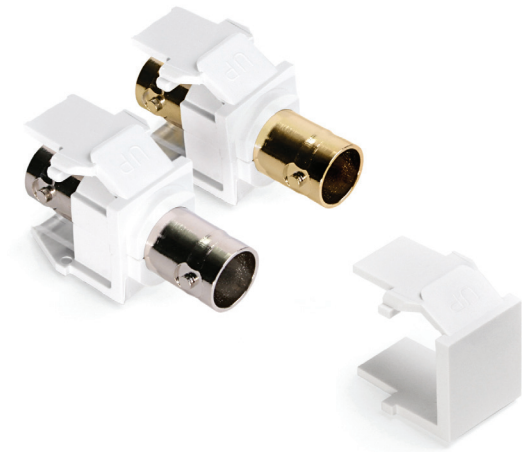

SPECIFICATION

Modules for coaxial cable shall be individual snap-in style female-to-female bulkhead adapters, and shall fit all other installed Leviton telecommunications wallplates, outlets and field-configurable patch panels and patch blocks. Bulkhead modules shall be available in six colors (ivory, white, light almond, grey, black and brown) to match the housings or provide unique color-coding for port I.D. Modules shall be UL listed. All plastics used in construction of the module bodies shall be fire-retardant with a UL flammability rating of 94V-0.

FEATURES

- Female-female BNC bulkhead adapters
- Twist-on front and rear BNC plugs for easy termination
- Available in nickel and gold-plated finishes

DESIGN CONSIDERATIONS

- QuickPort BNC bulkhead and blank modules snap into any housing with the QuickPort name: flush and surface mount outlets; Multimedia Outlet System (with adapter); patch panels; and patch blocks.
- Check clearance behind proposed location of bulkhead BNC module, to ensure space for proper bend-radius.
- Bulkhead BNC and blank modules are available in six colors (ivory, white, almond, light almond, grey, and black) to match the housings or provide unique color-coding for port I.D.
- BNC bulkhead module is for cables that have male connectors already installed on cables.

STANDARDS COMPLIANCE

cULus Listed

PHYSICAL SPECIFICATIONS

Dimensions: BNC Bulkhead: 0.65"H x 0.60"W x 1.40"D
Blank Module: 0.65"H x 0.60"W x 0.90"D

Materials: Snap-in module bodies are high-impact, fire-retardant plastic rated UL 94V-0.

Impedance: 50 Ohms

COUNTRY OF ORIGIN


USA

WARRANTY INFORMATION


For a copy of Leviton product warranties, visit www.leviton.com/warranty.

ELECTRONIC FILES

For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit www.leviton.com.

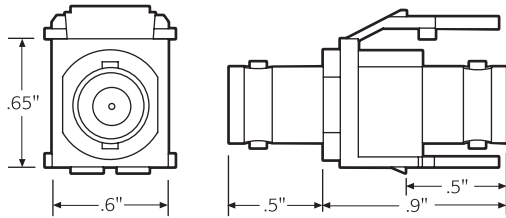

41084-BxF 40832-0Bx

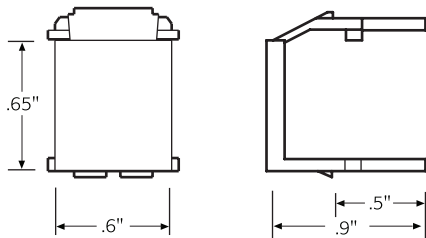

41084-BxB

41084-Bxx, 40832-0Bx

PART NUMBERS

Description	Part No.
BNC Bulkhead Module, Nickel Plated	41084-BxF
BNC Bulkhead Module, Gold Plated	40832-0B*
Blank Module	41084-BxB

x = Colors: Ivory (I), White (W), Grey (G), Black (E), Brown (B), Light Almond (T)

* = Colors: Ivory (I), White (W), Light Almond (T)



Leviton Network Solutions
 2222 - 222nd St. SE
 Bothell, WA 98021-4416

Asia / Pacific
 T +1.631.812.6228
 E infoasean@leviton.com

Canada
 T +1.514.954.1840
 E pcservice@leviton.com

Caribbean
 T +1.954.593.1896
 E infocaribbean@leviton.com

China
 T +852.2774.9876
 E infochina@leviton.com

Colombia
 T +57.1.743.6045
 E infocolombia@leviton.com

tel 1-800-824-3005
 tel +1-425-486-2222
 appeng@leviton.com
 www.leviton.com

Europe
 T +33.6.8869.1380
 E infoeurope@leviton.com

India / SAARC
 T +91.80.4322.5678
 E infoindia@leviton.com

Mexico
 T +52.55.5082.1040
 E lsamarketing@leviton.com

Middle East & Africa
 T +971.4.886.4722
 E lmeinfo@leviton.com

South Korea
 T +82.2.3273.9963
 E infokorea@leviton.com