


QuickPort® Surface Mount Housings & Back Boxes

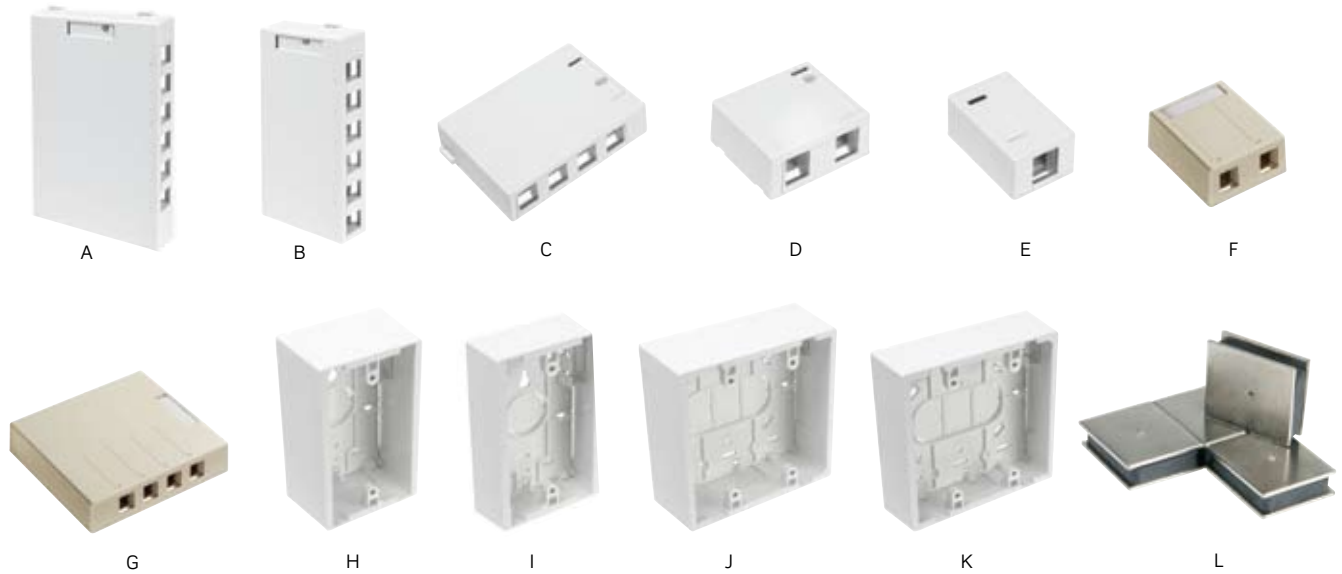

Specifications and Features

- Surface Mount Housings and Back Boxes work in places where it may not be practical to add a wallbox
- Housings mount with the included double-sided tape or screws, modular furniture brackets, or with magnets
- Surface Mount Boxes and Back Boxes have breakouts to match common surface mount raceway systems
- 4S089 products are designed to work with Leviton Shielded or eXtreme® 6A Connectors to allow proper bend radius control

QUICKPORT SURFACE MOUNT HOUSINGS

Description	Cat. No. White	Cat. No. Ivory	Cat. No. Grey	Cat. No. Black
[A] 12-Port Surface Mount Housing, 7.60"W x 5.02"D x 1.13"H	41089-12W	41089-12I	41089-12G	41089-12E
[B] 6-Port Surface Mount Housing, 6.38"W x 3.22"D x 1.08"H	41089-6WP	41089-6IP	41089-6GP	41089-6EP
[C] 4-Port Surface Mount Housing, 4.77"W x 3.21"D x 1.05"H	41089-4WP	41089-4IP	41089-4GP	41089-4EP
[D] 2-Port Surface Mount Housing, 2.52"W x 2.22"D x 1.10"H	41089-2WP	41089-2IP	41089-2GP	41089-2EP
[E] 1-Port Surface Mount Housing, 1.42"W x 2.22"D x 1.10"H	41089-1WP	41089-1IP	41089-1GP	41089-1EP
[F] 2-Port Surface Mount Housing for Shielded Connectors, 2.5"W x 3.00"D x 1.22"H	4S089-2WP	4S089-2IP		
[G] 4-Port Surface Mount Box for Shielded Connectors, 5.6"W x 5.20"D x 1.22"H	4S089-4WP	4S089-4IP		