

Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Pushbutton operators only

Selection and ordering data

Version	Color of actuator	Order no.	List Price	Pack		
			\$	Unit		
Pushbutton with flush cap	black	52PA8A1	20.80	1		
	red	52PA8A2	20.80			
	green	52PA8A3	20.80			
	yellow	52PA8A4	20.80			
	blue	52PA8A5	20.80			
	gray	52PA8A6	20.80			
	orange	52PA8A8	20.80			
	less cap	52PA8	19.30			
	kit with all colors	52PA8AN	24.00			
	Pushbutton with extended cap	black	52PA8B1		20.80	1
		red	52PA8B2		20.80	
		green	52PA8B3		20.80	
		yellow	52PA8B4		20.80	
		blue	52PA8B5		20.80	
gray		52PA8B6	20.80			
orange		52PA8B8	20.80			
less cap		52PA8	19.30			
kit with all colors		52PA8BN	24.00			
Pushbutton with mushroom cap 1 5/8" (41.3mm)		black	52PB9D1	43.80	1	
		red	52PB9D2	43.80		
		green	52PB9D3	43.80		
		yellow	52PB9D4	43.80		
		blue	52PB9D5	43.80		
	gray	52PB9D6	43.80			
	orange	52PB9D8	43.80			
	less cap	52PB9	36.10			
	kit with all colors	52PB9DN	46.10			
	Pushbutton with mushroom cap 2 1/2" (63.5mm)	black	52PB9E1	51.50		1
		red	52PB9E2	51.50		
		green	52PB9E3	51.50		
		yellow	52PB9E4	51.50		
		blue	52PB9E5	51.50		
gray		52PB9E6	51.50			
orange		52PB9E8	51.50			
less cap		52PB9	36.10			
less cap with lens kit		52PB9EN	125.00			
2 position push pull maintained, non illuminated						
Metal Mushroom Head, 1 5/8" (41.3 mm)		red	52PA2A2	69.00	1	
		green	52PA2A3	69.00		
		chrome	52PA2AC	69.00		
Small Plastic Mushroom Head, 1 5/8" (41.3 mm)		black	52PA2W1	59.00	1	
	red	52PA2W2	59.00			
	green	52PA2W3	59.00			
Large Plastic Mushroom Head, 2 1/4" (57.2 mm)	black	52PA2V1	66.70	1		
	red	52PA2V2	66.70			
	green	52PA2V3	66.70			

Flush pushbutton operator



2 position push pull operator





Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Push to test units

Selection and ordering data

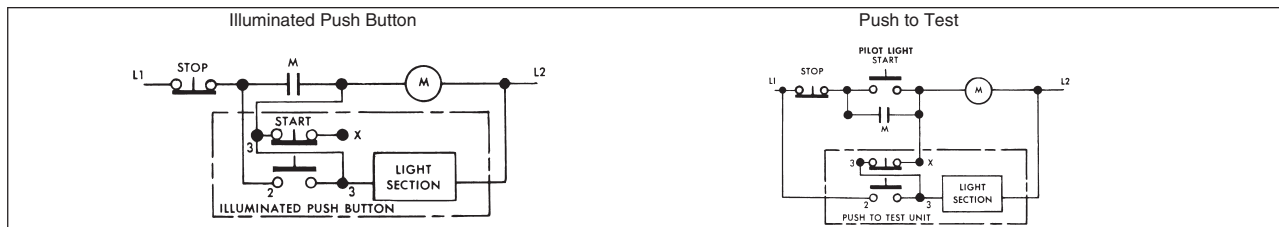
	Version	Color of actuator	Contact blocks	Order no.	List Price	Order no.	List Price	Pack	
				Operators with Incandescent lamp	\$	Operators with LED lamp	\$	Unit	
Push to test/illuminated pushbutton  52PA6D2A	Illuminated pushbuttons/Push to test indicator light with plastic lens - Full voltage type AC/DC ¹⁾ 6-8V with 755 type	red	1NO + 1NC	52PA6B2A	90.40	52PE6B2A	103.40	1	
		green	1NO + 1NC	52PA6B3A	90.40	52PE6B3A	103.40		
		amber	1NO + 1NC	52PA6B9A	90.40	52PE6B9A	103.40		
		less lens	1NO + 1NC	52PA6BNA	85.00	— ²⁾	—		
	24V with 757 type	red	1NO + 1NC	52PA6D2A	90.40	52PE6D2A	103.00	1	
		green	1NO + 1NC	52PA6D3A	90.40	52PE6D3A	103.00		
		amber	1NO + 1NC	52PA6D9A	90.40	52PE6D9A	103.00		
		less lens	1NO + 1NC	52PA6DNA	85.00	— ²⁾	—		
	 52PA6G2A	Illuminated pushbuttons/Push to test indicator light with plastic lens - Transformer type AC/DC ¹⁾ 120V with 6V 755 type lamp	red	1NC + 1NO	52PA6G2A	105.40	52PE6G2A	118.40	1
			green	1NC + 1NO	52PA6G3A	105.40	52PE6G3A	118.40	
			amber	1NC + 1NO	52PA6G9A	105.40	52PE6G9A	118.40	
			less lens	1NC + 1NO	52PA6GNA	100.00	— ²⁾	—	
240V with 6V 755 type lamp		red	1NC + 1NO	52PA6H2A	105.40	52PE6H2A	118.40	1	
		green	1NC + 1NO	52PA6H3A	105.40	52PE6H3A	118.40		
		amber	1NC + 1NO	52PA6H9A	105.40	52PE6H9A	118.40		
		less lens	1NC + 1NO	52PA6HNA	100.00	— ²⁾	—		
480V with 6V 755 type lamp		red	1NC + 1NO	52PA6J2A	105.40	52PE6J2A	118.40	1	
		green	1NC + 1NO	52PA6J3A	105.40	52PE6J3A	118.40		
		amber	1NC + 1NO	52PA6J9A	105.40	52PE6J9A	118.40		
		less lens	1NC + 1NO	52PA6JNA	100.00	— ²⁾	—		
600V with 6V 755 type lamp	red	1NC + 1NO	52PA6K2A	105.40	52PE6K2A	118.40	1		
	green	1NC + 1NO	52PA6K3A	105.40	52PE6K3A	118.40			
	amber	1NC + 1NO	52PA6K9A	105.40	52PE6K9A	118.40			
	less lens	1NC + 1NO	52PA6KNA	100.00	— ²⁾	—			
Push to test indicator light with plastic lens - Resistor type AC/DC	120V with 24V 757 type lamp	red	1NC + 1NO	52PA6M2A	90.40	52PE6M2A	103.40	1	
		green	1NC + 1NO	52PA6M3A	90.40	52PE6M3A	103.40		
		amber	1NC + 1NO	52PA6M9A	90.40	52PE6M9A	103.40		
		less lens	1NC + 1NO	52PA6MNA	85.00	— ²⁾	—		
	240V with 24V 757 type lamp	red	1NC + 1NO	52PA6N2A	90.40	52PE6N2A	103.40	1	
		green	1NC + 1NO	52PA6N3A	90.40	52PE6N3A	103.40		
		amber	1NC + 1NO	52PA6N9A	90.40	52PE6N9A	103.40		
		less lens	1NC + 1NO	52PA6NNA	85.00	— ²⁾	—		

Color code table: blue
clear
white

5
A
B

5
A
B

Wiring Diagrams



1) All illuminated devices come with std. Touch-safe shield per UL stds.








2) LED color must match lens color. Consult Factory for Neon types.

Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Push pull operators

Selection and ordering data

	Version	Color of actuator	Contact blocks	Order no.	List Price \$	Order no.	List Price \$	Pack Unit	
2 position push-pull  52PA2A2A  52PA2ACA  52PA2V2A  52PA2W2A  52PA3W2U	2 Position Push Pull Maintained, Non Illuminated								
	Metal Mushroom Head, 1 5/8" (41.3 mm)	red green chrome	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2A2A 52PA2A3A 52PA2ACA	92.20 92.20 92.20			1	
	Small Plastic Mushroom Head, 1 5/8" (41.3 mm)	black red green	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2W1A 52PA2W2A 52PA2W3A	82.20 82.20 82.20				
	Large Plastic Mushroom Head, 2 1/4" (57.2 mm)	black red green	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2V1A 52PA2V2A 52PA2V3A	99.90 99.90 99.90				
	3 Position Push Pull Momentary, Non-Illuminated (Spring return to center-pull to start, push to stop)¹⁾								
	Metal Mushroom Head, 1 5/8" (41.3 mm)	red green chrome	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA3A2U 52PA3A3U 52PA3ACU	90.20 90.20 90.20			1	
	Small Plastic Mushroom Head, 1 5/8" (41.3 mm)	black red green	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA3W1U 52PA3W2U 52PA3W3U	90.20 90.20 90.20				
	Large Plastic Mushroom Head, 2 1/4" (57.2 mm)	black red green	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA3V1U 52PA3V2U 52PA3V3U	99.90 99.90 90.90				
	2 position push pull with fully illuminated mushroom head  52PA2D2A  52PA2DRA	2 Position Push Pull Maintained, Illuminated			Operators with incandescent lamp		Operators with LED lamp		
		24V Full Voltage	less operating head chrome red chrome green chrome amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2DNA 52PA2D2A 52PA2D3A 52PA2D9A	112.10 129.00 129.00 129.00	***** ²⁾ 52PE2D2A 52PE2D3A 52PE2D9A	— 142.00 142.00 142.00	1
		full red full green full amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2DRA 52PA2DSA 52PA2DTA	129.00 129.00 129.00	52PE2DRA 52PE2DSA 52PE2DTA	142.00 142.00 142.00		
120V transformer with 6V 755 type lamp		less operating head chrome red chrome green chrome amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2GNA 52PA2G2A 52PA2G3A 52PA2G9A	112.10 129.00 129.00 129.00	***** ²⁾ 52PE2G2A 52PE2G3A 52PE2G9A	— 129.00 142.00 142.00	1	
		full red full green full amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2GRA 52PA2GSA 52PA3GTA	129.00 129.00 129.00	52PE2GRA 52PE2GSA 52PE2GTA	142.00 142.00 142.00		
240V transformer with 6V 755 type lamp		less operating head chrome red chrome green chrome amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2HNA 52PA2H2A 52PA2H3A 52PA2H9A	112.10 129.00 129.00 129.00	***** ²⁾ 52PE2H2A 52PE2H3A 52PE2H9A	— 142.00 142.00 142.00	1	
480V transformer with 6V 755 type lamp		less operating head chrome red chrome green chrome amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2JNA 52PA2J2A 52PA2J3A 52PA2J9A	112.10 129.00 129.00 129.00	***** ²⁾ 52PE2J2A 52PE2J3A 52PE2J9A	— 142.00 142.00 142.00	1	
600V transformer with 6V 755 type lamp		less operating head chrome red chrome green chrome amber	1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO 1 NC + 1 NO	52PA2KNA 52PA2K2A 52PA2K3A 52PA2K9A	112.10 129.00 129.00 129.00	***** ²⁾ 52PE2K2A 52PE2K3A 52PE2K9A	— 142.00 142.00 142.00	1	

1) Blocks cannot be interchanged (start-stop circuit).

2) LED color must match lens color.

Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Selector switch operators

Selection and ordering data

Version	Lever type	Color of lever insert	Cam Code ²⁾	Input Voltage	Order no.	List Price \$	Pack unit	
Selector Switches with 2 switching positions								
Maintained operation	Non-Illuminated, short lever	White	A		52SA2AAB	28.50	1	
	Non-Illuminated, long lever	White	A		52SB2AAB	28.50		
Spring return from right operation	Illuminated, short lever ¹⁾ with full voltage 24V, 755 type lamp		A	24V	52SA7ADN	69.00	1	
	Illuminated, short lever ¹⁾ with 50/60 Hz transformer 6V, 755 type lamp		A	120V	52SA7AGN	85.00	1	
	Non-Illuminated, short lever	White	A	240V	52SA7AHN	85.00		
	Non-Illuminated, long lever	White	A		52SB2ACB	44.00	1	
	Non-Illuminated, long lever	White	A		52SB2ACB	44.00		
Selector Switches with 3 switching positions								
Maintained operation	Non-Illuminated, short lever	White	B		52SA2BAB	28.50	1	
	Non-Illuminated, long lever	White	B		52SB2BAB	28.50		
	Non-Illuminated, short lever	White	C ³⁾		52SA2CAB	28.50		
	Non-Illuminated, long lever	White	C ³⁾		52SB2CAB	28.50		
	Non-Illuminated, short lever	White	D		52SA2DAB	28.50		
	Non-Illuminated, long lever	White	D		52SB2DAB	28.50		
	Non-Illuminated, short lever	White	E		52SA2EAB	28.50		
	Non-Illuminated, long lever	White	E		52SB2EAB	28.50		
	Non-Illuminated, short lever	White	G		52SA2GAB	28.50		
	Non-Illuminated, long lever	White	G		52SB2GAB	28.50		
	Illuminated, short lever ¹⁾ with full voltage 24V, 755 type lamp		B	24V	52SA7BDN	69.00	1	
			C ³⁾	24V	52SA7CDN	69.00		
Spring return from right operation	Illuminated, short lever ¹⁾ with 50/60 Hz transformer 6V, 755 type lamp		B	120V	52SA7BGN	85.00	1	
			C ³⁾	120V	52SA7CGN	85.00		
			B	240V	52SA7BHN	85.00		
			C ³⁾	240V	52SA7CHN	85.00		
Spring return from right operation	Non-Illuminated, short lever	White	B		52SA2BCB	44.00	1	
	Non-Illuminated, long lever	White	B		52SB2BCB	44.00		
	Non-Illuminated, short lever	White	C ³⁾		52SA2CCB	44.00		
	Non-Illuminated, long lever	White	C ³⁾		52SB2CCB	44.00		
	Non-Illuminated, short lever	White	D		52SA2DCB	44.00		
	Non-Illuminated, long lever	White	D		52SB2DCB	44.00		
	Non-Illuminated, short lever	White	E		52SA2ECB	44.00		
	Non-Illuminated, long lever	White	E		52SB2ECB	44.00		
	Non-Illuminated, short lever	White	G		52SA2GCB	44.00		
	Non-Illuminated, long lever	White	G		52SB2GCB	44.00		
	Spring return from left operation	Non-Illuminated, short lever	White	B		52SA2BBB	44.00	1
		Non-Illuminated, long lever	White	B		52SB2BBB	44.00	
Non-Illuminated, short lever		White	C ³⁾		52SA2CBB	44.00		
Non-Illuminated, long lever		White	C ³⁾		52SB2CBB	44.00		
Non-Illuminated, short lever		White	D		52SA2DBB	44.00		
Non-Illuminated, long lever		White	D		52SB2DBB	44.00		
Non-Illuminated, short lever		White	E		52SA2EBB	44.00		
Non-Illuminated, long lever		White	E		52SB2EBB	44.00		
Non-Illuminated, short lever		White	G		52SA2GBB	44.00		
Non-Illuminated, long lever		White	G		52SB2GBB	44.00		
Spring return from left and right operation		Non-Illuminated, short lever	White	B		52SA2BDB	44.00	1
		Non-Illuminated, long lever	White	B		52SB2BDB	44.00	
	Non-Illuminated, short lever	White	C ³⁾		52SA2CDB	44.00		
	Non-Illuminated, long lever	White	C ³⁾		52SB2CDB	44.00		
	Non-Illuminated, short lever	White	D		52SA2DDB	44.00		
	Non-Illuminated, long lever	White	D		52SB2DDB	44.00		
	Non-Illuminated, short lever	White	E		52SA2EDB	44.00		
	Non-Illuminated, long lever	White	E		52SB2EDB	44.00		
	Non-Illuminated, short lever	White	G		52SA2GDB	44.00		
	Non-Illuminated, long lever	White	G		52SB2GDB	44.00		
	Selector Switches with 4 switching positions							
	Maintained operation	Non-Illuminated, short lever	White	H		52SA2HAB	28.50	1
Non-Illuminated, long lever		White	H		52SB2HAB	28.50		

1) Illuminated selector switches are provided without lenses. Lens kit must be ordered separately on page 10/154.

2) For contact operation, see cam selection chart on page 10/151.

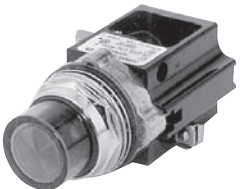
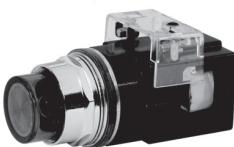
3) The C cam is limited to 4 contact blocks, 1 or 2 pole.

Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Indicator light operators

Selection and ordering data

	Version	Color of actuator	Order no.	List Price	Order no.	List Price	Pack		
			Operators with Incandescent lamp	\$	Operators with LED lamp	\$	Unit		
 <p>Pilot light</p>	Indicator light with plastic lens - Full voltage type AC/DC ¹⁾ ²⁾								
	6-8V with 755 type	red green amber less lens	52PA4B2 52PA4B3 52PA4B9 52PA4BN	67.40 67.40 67.40 62.00	52PE4B2 52PE4B3 52PE4B9 — ³⁾	80.40 80.40 80.40 —	1		
	12V with 757 type	red green amber less lens	52PA4C2 52PA4C3 52PA4C9 52PA4CN	67.40 67.40 67.40 62.00			1		
	24V with 756 type	red green amber less lens	52PA4D2 52PA4D3 52PA4D9 52PA4DN	67.40 67.40 67.40 62.00	52PE4D2 52PE4D3 52PE4D9 — ³⁾	80.40 80.40 80.40 —	1		
	120V with 120MB type	red green amber less lens	52PC4E2 52PC4E3 52PC4E9 52PC4EN	67.40 67.40 67.40 62.00	52PE4E2 52PE4E3 52PE4E9 — ³⁾	80.40 80.40 80.40 —	1		
		Indicator light with plastic lens - Transformer type AC/DC ¹⁾ ²⁾							
		120V with 6V 755 type lamp	red green amber less lens	52PA4G2 52PA4G3 52PA4G9 52PA4GN	82.40 82.40 82.40 77.00	52PE4G2 52PE4G3 52PE4G9 — ³⁾	95.40 95.40 95.40 —	1	
		240V with 6V 755 type lamp	red green amber less lens	52PA4H2 52PA4H3 52PA4H9 52PA4HN	82.40 82.40 82.40 77.00	52PE4H2 52PE4H3 52PE4H9 — ³⁾	95.40 95.40 95.40 —	1	
		277V with 6V 755 type lamp	red green amber less lens	52PA4T2 52PA4T3 52PA4T9 52PA4TN	82.40 82.40 82.40 77.00	52PE4T2 52PE4T3 52PE4T9 — ³⁾	95.40 95.40 95.40 —	1	
		480V with 6V 755 type lamp	red green amber less lens	52PA4J2 52PA4J3 52PA4J9 52PA4JN	82.40 82.40 82.40 77.00	52PE4J2 52PE4J3 52PE4J9 — ³⁾	95.40 95.40 95.40 —	1	
		600V with 6V 755 type lamp	red green amber less lens	52PA4K2 52PA4K3 52PA4K9 52PA4KN	82.40 82.40 82.40 77.00	52PE4K2 52PE4K3 52PE4K9 — ³⁾	95.40 95.40 95.40 —	1	
		Indicator light with plastic lens - Resistor type AC/DC ¹⁾ ²⁾							
		240V with 120V 120MB type lamp	red green amber less lens	52PC4N2 52PC4N3 52PC4N9 52PC4NN	67.40 67.40 67.40 62.00	52PE4N2 52PE4N3 52PE4N9 — ³⁾	80.40 80.40 80.40 —	1	
		Color code table:		blue clear white	5 A B		5 A B		

1) All illuminated devices come with std. Touch-safe shield per UL stds.

2) For factory installed glass lens, replace the 5th character with "5".


3) LED color must match lens color. Consult Factory for Neon types.

Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Accessories and spare parts

Selection and ordering data

Version	Suitable for	Lamp voltage	Color	Order no.	List Price
					\$
Lamps with screw connection, miniature bayonet (BA 9s style)					
Incandescent lamps,					
	Flashing, type 267 lamp (replaces 755 lamp)	51, 52	6 V	52AABNF	11.60
	6V type 755 lamp	51, 52	6 V	52AABN	7.70
	12V type 756	51, 52	12 V	52AACN	7.70
	24V type 757	51, 52	24 V	52AADN	7.00
	120V, 2.5W, type #120MB	52	120 V	52AAENC1	7.70
	Neon (uses resistors) type B2A (NE-51H)	52	120 V	52AAPN	15.90
Candelabra, 120 V, Full voltage type 3S6/5 ¹⁾	52 older revision styles	120 V		52AAENC	7.70
LED's BA9s Style	52	6 V	red	52AEB2	21.00
	52	6 V	green	52AEB3	21.00
	52	6 V	yellow	52AEB4	21.00
	52	6 V	white	52AEBB	21.00
	52	6 V	blue	52AEB5	21.00
	52	24 V	red	52AED2	21.00
	52	24 V	green	52AED3	21.00
	52	24 V	yellow	52AED4	21.00
	52	24 V	white	52AEDB	21.00
	52	24 V	blue	52AED5	21.00
	52	120 V	red	52AEE2	21.00
	52	120 V	green	52AEE3	21.00
	52	120 V	yellow	52AEE4	21.00
	52	120 V	white	52AEEB	21.00
	52	120 V	blue	52AEE5	21.00
LED's, cluster type For use with Class 52 pilot lights only	52	6 V	red	52AEB27	26.50
	52	6 V	green	52AEB37	26.50
	52	6 V	yellow	52AEB47	26.50
	52	24 V	red	52AED27	26.50
	52	24 V	green	52AED37	26.50
	52	24 V	yellow	52AED47	26.50
	52	120 V	red	52AEE27	26.50
	52	120 V	green	52AEE37	26.50
	52	120 V	yellow	52AEE47	26.50



52 BAJ



52 BAK



52 BAR

Touchsafe contact blocks with gold flashing

1 NO		52BAK	11.60
1 NC		52BAJ	11.60
1 NO - 1 NC		52BJK	23.20
1 NO early make	closes before 52BAK	52BAH	11.60
1 NC late break	opens after 52 BAJ	52BAE	11.60
1 NO - 1 NC	Reed switch	52BAR²⁾	46.40
	UL listed for class 1 division 2		
	.25A Max, 150V AC, 10 Watt max		
	.5A Max, 150V DC, 10 Watt max		
1 NC extra late break		52BAU	11.60

1) Design change made in 2003 from candelabra to BA 9s type bulbs. Contact technical support for further information.

2) Hermetically sealed.

Pushbutton Units and Indicator Lights

30 mm Heavy Duty, Watertight/Oiltight, Class 52

Legend plates for Class 51 and 52

Design

The 30 mm legend plates are approved for the use with both Class 51 and Class 52 devices. Automotive legend plates require 2 1/2" mounting centers.

When ordering custom engraved legend plates, specify the required inscription text.

Selection and ordering data

Inscription	Large (1 7/16" x 2") Order No.	List Price \$	Automotive 1) (2 7/16" x 2 7/16") Order No.	List Price \$	Large Plastic 2) (1 7/16" x 2") Order No.	List Price \$	Automotive Plastic 1)2) (2 7/16" x 2 7/16") Order No.	List Price \$
"Blank (brushed aluminum)"	52NL02	2.30	52NA02	3.90	—	—	—	—
"Blank (red)"	52NL02R	2.30	52NA02R	3.90	52ND02R	2.30	52NE02R	3.90
"Blank (Black)"	52NL02B	2.30	52NA02B	3.90	52ND02B	2.30	52NE02B	3.90
Inscribed legend plates with large brushed aluminum background								
Close	52NL18	2.30	52NA18	3.90	—	—	—	—
Down	52NL10	2.30	52NA10	3.90	—	—	—	—
Emerg Stop	52NL16	2.30	52NA16	3.90	—	—	—	—
Emerg Stop (red)	52NL16R	2.30	52NA16R	3.90	—	—	—	—
Fast-Slow	52NL33	2.30	52NA33	3.90	—	—	—	—
Forward	52NL05	2.30	52NA05	3.90	—	—	—	—
For-Off-Rev	52NL38	2.30	52NA38	3.90	—	—	—	—
For-Rev	52NL31	2.30	52NA31	3.90	—	—	—	—
Hand-Off-Auto	52NL37	2.30	52NA37	3.90	—	—	—	—
High	52NL07	2.30	52NA07	3.90	—	—	—	—
High-Low	52NL30	2.30	52NA30	3.90	—	—	—	—
High-Off-Low	52NL44	2.30	52NA44	3.90	—	—	—	—
In	52NL21	2.30	52NA21	3.90	—	—	—	—
Jog	52NL13	2.30	52NA13	3.90	—	—	—	—
Jog-Forward	52NL24	2.30	52NA24	3.90	—	—	—	—
Jog-Reverse	52NL25	2.30	52NA25	3.90	—	—	—	—
Low	52NL08	2.30	52NA08	3.90	—	—	—	—
Lower	52NL20	2.30	52NA20	3.90	—	—	—	—
Man-Suto	52NL35	2.30	52NA35	3.90	—	—	—	—
Off	52NL12	2.30	52NA12	3.90	—	—	—	—
Off-On	52NL26	2.30	52NA26	3.90	—	—	—	—
On	52NL11	2.30	52NA11	3.90	—	—	—	—
On-Off-Auto	52NL40	2.30	52NA40	3.90	—	—	—	—
Open	52NL17	2.30	52NA17	3.90	—	—	—	—
Open-Close	52NL34	2.30	52NA34	3.90	—	—	—	—
Out	52NL41	2.30	52NA41	3.90	—	—	—	—
Pull to Start	52NL22	2.30	52NA22	3.90	—	—	—	—
Push to Stop	52NL47	2.30	52NA47	3.90	—	—	—	—
Raise	52NL19	2.30	52NA19	3.90	—	—	—	—
Raise-Lower	52NL36	2.30	52NA36	3.90	—	—	—	—
Reset	52NL14	2.30	52NA14	3.90	—	—	—	—
Reverse	52NL06	2.30	52NA06	3.90	—	—	—	—
Run	52NL23	2.30	52NA23	3.90	—	—	—	—
Run-Jog	52NL29	2.30	52NA29	3.90	—	—	—	—
Safe-Run	52NL27	2.30	52NA27	3.90	—	—	—	—
Slow-Off-Fast	52NL39	2.30	52NA39	3.90	—	—	—	—
Start	52NL03	2.30	52NA03	3.90	—	—	—	—
Start-Jog	52NL28	2.30	52NA28	3.90	—	—	—	—
Start-Stop	52NL32	2.30	52NA32	3.90	—	—	—	—
Stop	52NL04	2.30	52NA04	3.90	—	—	—	—
Stop (red)	52NL04R	2.30	52NA04R	3.90	—	—	—	—
Up	52NL09	2.30	52NA09	3.90	—	—	—	—
Up-Down	52NL49	2.30	52NA49	3.90	—	—	—	—
Up-Off-Down	52NL42	2.30	52NA42	3.90	—	—	—	—
Inscription plates with custom engraving								
"Custom engraved (brushed aluminum)"	52NL02E	10.00	52NA02E	11.60	—	—	—	—
"Custom engraved (red)"	52NL02RE	10.00	52NA02RE	11.60	52ND02RE	10.00	52NE02RE	11.60
"Custom engraved (Black)"	52NL02BE	10.00	52NA02BE	11.60	52ND02BE	10.00	52NE02BE	11.60
Max. number of rows	2		2		2		2	
Letter height	5/32"		1/4"		5/32"		1/4"	
Characters per row	14		16		14		16	

1) Automotive requires 2 1/2" mounting centers

2) White letters on plastic nameplate.