


CADDY® PYRAMID ST Series

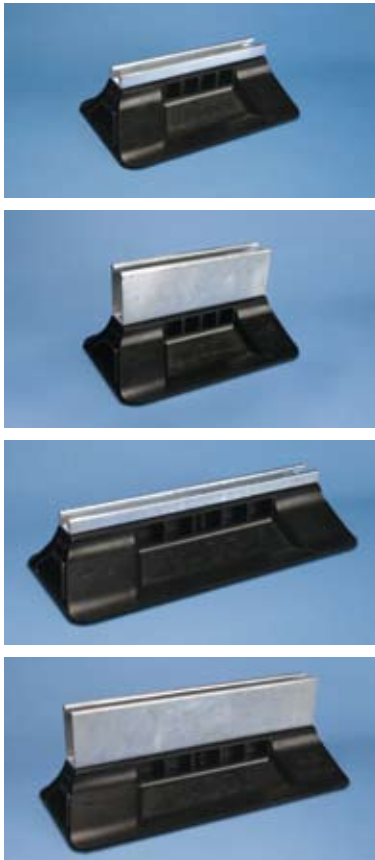


Fixed Strut Supports:

- ▲ Provide fixed-height mounting platform 4" or 6" off the roof surface and 10" or 16" of usable strut length
- ▲ Maximum recommended load is up to 1,500 lbs
- ▲ Hot-dipped galvanized finish provides superior corrosion protection

| Part Number | H (in) | L1 (in) | L2 (in) | W (in) | Surface Area (in ²) | Weight lbs / ea. | Max. Rec. Load (lbs)* |
|-------------|--------|---------|---------|--------|---------------------------------|------------------|-----------------------|
| RPS360400 | 4 | 10 | 12.5 | 8 | 94.3 | 2.95 | 1,000 |
| RPS360401 | 6 | 10 | 12.5 | 8 | 94.3 | 4.65 | 1,000 |
| RPS360403 | 4 | 16 | 18.5 | 8 | 140.8 | 4.40 | 1,500 |
| RPS360404 | 6 | 16 | 18.5 | 8 | 140.8 | 7.05 | 1,500 |

* Max. recommended load at 10.6 psi roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

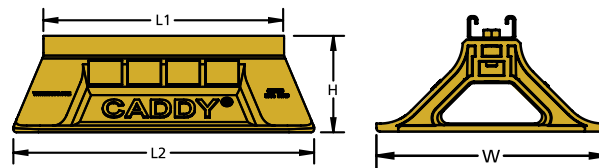

Adjustable-Height Strut Supports:

- ▲ Allow elevation change up to 16" off the roof surface with up to 10" or 16" of usable strut length
- ▲ Maximum recommended load is up to 1,500 lbs
- ▲ Hot-dipped galvanized finish provides superior corrosion protection

| Part Number | H1 (in) | Max. H2 (in) | L1 (in) | L2 (in) | W (in) | Surface Area (in ²) | Weight lbs / ea. | Max. Rec. Load (lbs)* |
|-------------|---------|--------------|---------|---------|--------|---------------------------------|------------------|-----------------------|
| RPS360402 | 4.6 | 12 | 10 | 12.5 | 8 | 94.3 | 4.30 | 1,000 |
| RPS360405 | 5.5 | 17 | 16 | 18.5 | 8 | 140.8 | 6.00 | 1,500 |

* Max. recommended load at 10.6 psi roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

