

CADDY® SPEED LINK LD with Hook





Features

- Complete system includes wire, locking device and pre-assembled hook end fitting
- Hooks to a wide range of CADDY® fasteners
- Fastens to the building structure or hanging services by looping around and hooking to wire rope
- Easy to remove for applications requiring maintenance
- Spring latch helps provide secure connection
- Insert cable through hole and use bottom side of hook as an end stop

Specifications

Static Load Safety Factor: 5:1

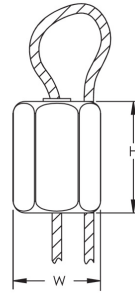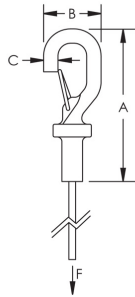

Part Number	Wire Rope Length	Wire Rope Diameter	A	B	C	Static Load F	Standard Packaging Quantity
Material: Steel – Finish: Electro Zinc Plated							
SLD15L1	3.3'	1.5 mm	2.3"	0.9"	1/4"	44 lb	5 x 20 pc
SLD15L1TP	3.3'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc
SLD15L2	6.6'	1.5 mm	2.3"	0.9"	1/4"	44 lb	5 x 20 pc
SLD15L2TP	6.6'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc
SLD15L3	9.9'	1.5 mm	2.3"	0.9"	1/4"	44 lb	5 x 20 pc
SLD15L3TP	9.9'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc
SLD15L5	16.4'	1.5 mm	2.3"	0.9"	1/4"	44 lb	5 x 20 pc
SLD15L5TP	16.4'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc
SLD15L7	22.9'	1.5 mm	2.3"	0.9"	1/4"	44 lb	5 x 20 pc
SLD15L10	32.8'	1.5 mm	2.3"	0.9"	1/4"	44 lb	5 x 20 pc
Material: Stainless Steel 304							
SLD15L2S	6.6'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc
SLD15L2SBP	6.6'	1.5 mm	2.3"	0.9"	1/4"	44 lb	1 pc
SLD15L5S	16.4'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc
SLD15L10S	32.8'	1.5 mm	2.3"	0.9"	1/4"	44 lb	20 x 2 pc

Height H	Width W
3/4"	1/2"