


# CADDY® ALL-IN-ONE Electrical Assemblies

## CADDY® ALL-IN-ONE Between-Stud Assemblies

### CADDY® ALL-IN-ONE Between-Stud Without Mud Ring, Single Box

- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Includes two screws to lock box in position
- Pre-bent tabs on support bracket help to quickly square assembly to stud
- Center marks provide easy height positioning
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Works with standard US and Canadian mud rings
- Made in the USA

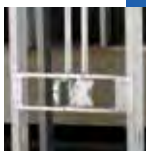


Patent No: 8,598,454

Material: Steel

Finish: Pregalvanized

Knockout Sizes: (8) 1/2"; 3/4", (3) 1/2"



Part Number	Description	
A1BF0G	w/Ground, 3 5/8"	5 pc
A1BF0GTC (Canada)	w/Ground, 3 5/8"	5 pc
A1BF0GS	w/Ground, 2 1/2"	5 pc

Ground wire pigtail is 8".

24" stud spacing requires use of three mounting screws.

Use only with CADDY® ALL-IN-ONE box assemblies.



# CADDY® ALL-IN-ONE Electrical Assemblies

## CADDY® ALL-IN-ONE Between-Stud Assemblies

### CADDY® ALL-IN-ONE Between-Stud Without Mud Ring, Multi-Box

- Comes with multiple boxes pre-assembled for side by side power and data applications
- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Includes two screws to lock box in position
- Pre-bent tabs on support bracket help to quickly square assembly to stud
- Center marks provide easy height positioning
- Includes multiple knockouts on each side of the box
- Works with standard US and Canadian mud rings
- Made in the USA



Patent No: 8,598,454


Material: Steel

Finish: Pregalvanized

Knockout Sizes, Box 1: (8) 1/2" & 3/4"

Knockout Sizes, Box 2: (5) 1/2"; 3/4", (1) 1/2", (3) 1"



Part Number	Description	
A1BF0GDON	3 5/8"	5 pc
A1BF0GDONTC (Canada)	3 5/8"	5 pc
A1BF0GDONS	2 1/2"	5 pc

Ground wire pigtail is 8".

24" stud spacing requires use of three mounting screws.


Use only with CADDY® ALL-IN-ONE box assemblies.

# CADDY® ALL-IN-ONE Electrical Assemblies

## CADDY® ALL-IN-ONE Between-Stud Assemblies


### CADDY® ALL-IN-ONE Between-Stud Bracket

- Versatile bracket for mounting CADDY® ALL-IN-ONE box assemblies
- Provides excellent rigidity and reduces issues at trim out
- CADDY® ALL-IN-ONE box assemblies simply slide and lock in to place with provided screws
- Perfect for jobs when specifications require precise box location
- 24" stud spacing requires use of three mounting screws.
- Made in the USA

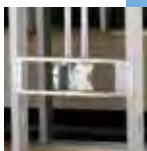

Material: Steel  
Finish: Pregalvanized



Part Number	Description	
A1B1624	CADDY ALL-IN-ONE Between-Stud Bracket	50 pc
A1B1624SP250	CADDY ALL-IN-ONE Between-Stud Bracket	250 pc

Use only with CADDY® ALL-IN-ONE box assemblies.



# CADDY® ALL-IN-ONE Electrical Assemblies

## CADDY® ALL-IN-ONE Floor-Mounted Assemblies

### CADDY® ALL-IN-ONE Floor-Mounted With Integral Mud Ring

- Ingenious design combines box, support bracket and mud ring into a single, integrated unit
- Fewer parts makes the installation faster and easier
- Preset to a finish height of 18" from the floor (adjustable to 12" or 15")
- Integrated first means of support accepts conduit or MC/AC cable
- Accommodates additional CADDY ALL-IN-ONE box assemblies, support brackets and low-voltage mounting plates
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Made in the USA



Patents Pending

Material: Steel


Finish: Pregalvanized

EMT Conduit Size: 1/2", 3/4"

MC/AC Cable Size: 14-2 to 12-3

Knockout Sizes: (8) 1/2"; 3/4", (2) 1/2"



Part Number	Description	
A1FA1GS	1 Gang, w/Ground, 5/8" Drywall, 2 1/2"	5 pc
A1FA1G	1 Gang, w/Ground, 5/8" Drywall, 3 5/8"	5 pc
A1FA2GS	2 Gang, w/Ground, 5/8" Drywall, 2 1/2"	5 pc
A1FA2G	2 Gang, w/Ground, 5/8" Drywall, 3 5/8"	5 pc

Ground wire pigtail is 8".

# CADDY® ALL-IN-ONE Electrical Assemblies

## CADDY® ALL-IN-ONE Floor-Mounted Assemblies

### CADDY® ALL-IN-ONE Floor-Mounted With Removable Mud Ring

- Preset to a finish height of 18" from the floor (adjustable to 12" or 15")
- Removable mud ring provides front access to the interior of the box
- Box remains fixed in place when mud ring is removed
- Integrated first means of support accepts conduit or MC/AC cable
- Accommodates additional CADDY ALL-IN-ONE box assemblies, support brackets and low-voltage mounting plates
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Made in the USA



Patent Pending

Material: Steel


Finish: Pregalvanized

EMT Conduit Size: 1/2", 3/4"

MC/AC Cable Size: 14-2 to 12-3

Knockout Sizes: (8) 1/2"; 3/4", (3) 1/2"



Part Number	Description	
A1FF1GS	1 Gang, w/Ground, 5/8" Drywall, 2 1/2"	5 pc
A1FF1G	1 Gang, w/Ground, 5/8" Drywall, 3 5/8"	5 pc
A1FF3G	1 Gang, w/Ground, 1 1/4" Drywall, 3 5/8"	5 pc
A1FF2GS	2 Gang, w/Ground, 5/8" Drywall, 2 1/2"	5 pc
A1FF2G	2 Gang, w/Ground, 5/8" Drywall, 3 5/8"	5 pc
A1FF4G	2 Gang, w/Ground, 1 1/4" Drywall, 3 5/8"	5 pc

Ground wire pigtail is 8".



# CADDY® ALL-IN-ONE Electrical Assemblies

## CADDY® ALL-IN-ONE Floor-Mounted Assemblies

### CADDY® ALL-IN-ONE Floor-Mounted Without Mud Ring

- Preset to a finish height of 18" from the floor (adjustable to 12" or 15")
- Integrated first means of support accepts conduit or MC/AC cable
- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Accommodates additional CADDY ALL-IN-ONE box assemblies, support brackets and low-voltage mounting plates
- Includes multiple 1/2" and 3/4" knockouts on each side of the box
- Works with standard US and Canadian mud rings
- Made in the USA



Patent Pending

Material: Steel


Finish: Pregalvanized

EMT Conduit Size: 1/2", 3/4"

MC/AC Cable Size: 14-2 to 12-3

Knockout Sizes: (8) 1/2"; 3/4", (3) 1/2"



Part Number	Description	
A1FF0G	w/Ground, 3 5/8"	5 pc
A1FF0GTC (Canada)	w/Ground, 3 5/8"	5 pc
A1FF0GS	w/Ground, 2 1/2"	5 pc

Ground wire pigtail is 8".