



Canadian Products Supplement



Can-TWIST™ Wire Connectors

- Exceptional wire-range capacity, handles wire combinations from 22 to 8 AWG solid and/or stranded wires
- Spring threads are heat-set making them more reliable
- Flexible walls show when wires are firmly connected
- Extended skirt length provides over-strip protection
- Easily removed for repeat usage
- Smaller size makes it easier to work in tight spaces
- Wide mouth and square springs deliver quick pick-up
- Swept wings provide added gripping power
- Easier to twist. Only a few turns are necessary to achieve torque
- CSA 22.2 #188 Certified




Can-Twist
105°C/221°F



Can-Twist Extrême
High-Temp
150°C/302°F

CANADA'S BEST SELLING CONNECTOR

| MODEL | COLOUR | WIRE COMBINATION RANGE | WIRE COMBINATION (MM) | QUANTITY | CAT. NO. |
|--|--------|--|--|------------------|-----------|
| Can-Twist 007 | Blue | 600V No. 22 thru 8 Awg Min. 3 No. 22 Max 3 No. 10 | 600V .64mm DIA to 3.26mm DIA Min .97mm ² Max. 15.78mm ² | Pack of 15 | 30-157 |
| | | | | C-Pak of 100 | 30-207 |
| | | | | Jar of 175 | 30-107J |
| | | | | Jar of 475 | 30-307J |
| | | | | Bag of 500 | 30-607 |
| | | | | Jar of 1,000 | 30-707J |
| | | | | Stubby of 7,500 | 30-817 |
| | | | | Barrel of 25,000 | 30-807 |
| Can-Twist Extrême 007XT High-Temp | Black | 600V No. 22 thru 8 Awg Min. 3 No. 22 Max 4 No. 11 (solid) | 600V .64mm DIA to 3.26mm DIA Min .97mm ² Max. 13.24mm ² | Pack of 15 | 30-157XT |
| | | | | Jar of 175 | 30-107XTJ |
| | | | | Jar of 475 | 30-307XTJ |
| | | | | Stubby of 7,500 | 30-817 |
| | | | | Barrel of 25,000 | 30-807XTJ |

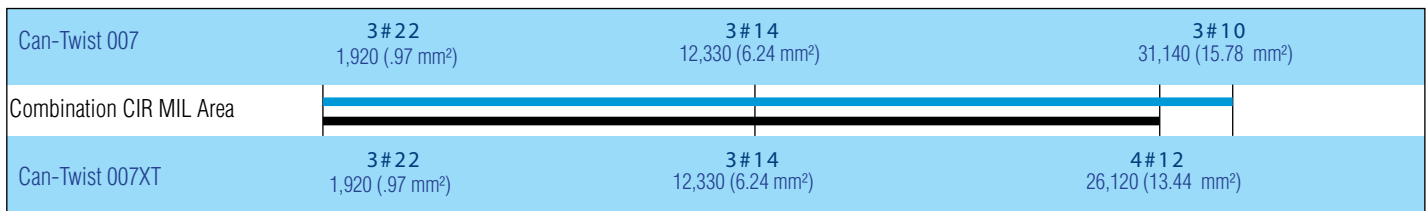

Dimensions for Model Can-Twist 007/Can-Twist Extrême 007XT

| DIMENSIONS | A | B | C | D | E |
|------------|-----|------|-----|------|-------|
| Inches | 1/4 | 7/16 | 3/4 | 7/16 | 1 1/8 |
| mm | 7 | 11.5 | 19 | 11.5 | 29 |

Cu/Cu Only

Ask about volume pricing

Wire Connectors



Wire Connectors



- “Stayset spring” to ensure each and every connector is usable resulting in better cost efficiency
- CSA Certified and UL Listed as a pressure type connector for 600V maximum building wire, and 1000V maximum for in signage/fixture applications
- Superior corrosion resistance
- Designed to appeal to users of wingless connectors



| Model | Colour | Wire Combination Range | Wire Combination Range (mm) | Quantity | Cat. No. |
|-------|--------|--|---|-------------------|----------|
| C3 | Orange | 600V No. 18 thru 14 AWG Min. 2 No. 18 Max. 3 No. 14 | 600V 1.02mm DIA to 1.63mm DIA Min. 1.64mm ² Max. 6.26mm ² | C-Pak of 100 | 30-0C3 |
| | | | | Flip-Tub of 500 | 30-3C3 |
| | | | | Flip-Tub of 1,000 | 30-4C3 |
| | | | | Keg of 10,000 | 30-6C3 |
| | | | | Barrel of 45,000 | 30-8C3 |
| C4 | Yellow | 600V No. 18 thru 10 AWG Min. 1 No. 14 with 2 No. 18 Max. 1 No. 10 with 2 No. 14 | 600V .62mm DIA to 2.59mm DIA Min. 3.74mm ² Max. 9.42mm ² | C-Pak of 100 | 30-0C4 |
| | | | | Flip-Tub of 500 | 30-3C4 |
| | | | | Flip-Tub of 1,000 | 30-4C4 |
| | | | | Keg of 10,000 | 30-6C4 |
| | | | | Barrel of 25,000 | 30-8C4 |
| C6 | Red | 600V No. 18 thru 14 AWG Min. 2 No. 16 with 2 No. 18 Max. 3 No. 10 | 600V 1.02mm DIA to 3.26mm DIA Min. 4.25mm ² Max. 15.78mm ² | C-Pak of 100 | 30-0C6 |
| | | | | Flip-Tub of 200 | 30-1C6 |
| | | | | Flip-Tub of 500 | 30-3C6 |
| | | | | Keg of 8,000 | 30-6C6 |
| | | | | Barrel of 20,000 | 30-8C6 |

Canadian Connector Kit

#30-2088

NEW

- A variety of connectors to fit a large range of wire sizes No. 6 AWG - 26 AWG
- Great for Servicing Technicians
- Convenient and durable carrying case

