


## Nailbiter™ Premium Ship Auger Bits


- Dual-Helix construction with twin cutting edges provides faster and smoother drilling action, even through nail-embedded timbers
- Full body, dual induction heat treatment ensures durability, minimizes warping and delivers long lasting performance
- Heavy-duty lead screw designed for quick gripping power, superior penetration and extra-long life
- Re-sharpenable for extended tool life

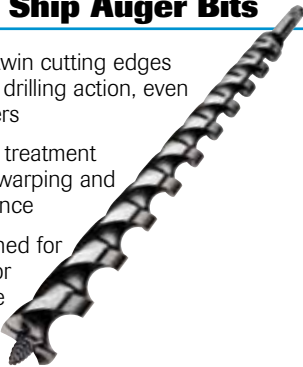

Power Ship Augers - Bit Length = 7-1/2", Twist = 5", Shank = 7/16" Description	Hole Diameter	Overall Length	Twist Length	Cat. No.
5/8 in. Power Ship Auger	5/8 in.	7-1/2 in.	5 in.	<b>35-810</b>
11/16 in. Power Ship Auger	11/16 in.	7-1/2 in.	5 in.	<b>35-811</b>
3/4 in. Power Ship Auger	3/4 in.	7-1/2 in.	5 in.	<b>35-812</b>
13/16 in. Power Ship Auger	13/16 in.	7-1/2 in.	5 in.	<b>35-813</b>
7/8 in. Power Ship Auger	7/8 in.	7-1/2 in.	5 in.	<b>35-814</b>
1 in. Power Ship Auger	1 in.	7-1/2 in.	5 in.	<b>35-815</b>
1-1/8 in. Power Ship Auger	1-1/8 in.	7-1/2 in.	5 in.	<b>35-816</b>
1-1/4 in. Power Ship Auger	1-1/4 in.	7-1/2 in.	5 in.	<b>35-817</b>
Power Ship Augers - Bit Length = 18", Twist = 15", Shank = 7/16" Description	Hole Diameter	Overall Length	Twist Length	Cat. No.
1/2 in. Power Ship Auger	1/2 in.	18 in.	15 in.	<b>35-820</b>
5/8 in. Power Ship Auger	5/8 in.	18 in.	15 in.	<b>35-821</b>
11/16 in. Power Ship Auger	11/16 in.	18 in.	15 in.	<b>35-822</b>
3/4 in. Power Ship Auger	3/4 in.	18 in.	15 in.	<b>35-823</b>
13/16 in. Power Ship Auger	13/16 in.	18 in.	15 in.	<b>35-824</b>
7/8 in. Power Ship Auger	7/8 in.	18 in.	15 in.	<b>35-825</b>
15/16 in. Power Ship Auger	15/16 in.	18 in.	15 in.	<b>35-826</b>
1 in. Power Ship Auger	1 in.	18 in.	15 in.	<b>35-827</b>
1-1/8 in. Power Ship Auger	1-1/8 in.	18 in.	15 in.	<b>35-828</b>
1-1/4 in. Power Ship Auger	1-1/4 in.	18 in.	15 in.	<b>35-829</b>

## Mini™ Utility Bit Augers

- Designed to fit between wall studs when used with common drills
- Eliminates the need for expensive right angle drills

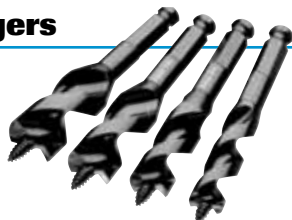

Mini™ Augers - Bit Length = 4-3/4" Twist = 2-1/2", Shank = 7/16" Description	Hole Diameter	Overall Length	Twist Length	Cat. No.
5/8 in. Mini™ Auger	5/8 in.	4-3/4 in.	2-1/2 in.	<b>35-862</b>
3/4 in. Mini™ Auger	3/4 in.	4-3/4 in.	2-1/2 in.	<b>35-864</b>
7/8 in. Mini™ Auger	7/8 in.	4-3/4 in.	2-1/2 in.	<b>35-866</b>
1 in. Power Ship Auger	1 in.	4-3/4 in.	2-1/2 in.	<b>35-868</b>

## RESI-MASTER™ Heavy-Duty Ship Augers

- 62° cutting angle reinforces the cutting edge and provides greater durability
- Hardened lead screw and cutting edge provide increased wear resistance and extended life
- Secondary relief angle evacuates wood chips quickly and prevents auger from jamming
- Oversized cutting head makes hole larger than body of bit for easy ejection from work piece



Power Ship Augers - Bit Length = 7-1/2", Twist = 5", Shank = 7/16" Description	Hole Diameter	Overall Length	Twist Length	Cat. No.
5/8 in. RESI-MASTER™ Auger	5/8 in.	7-1/2 in.	5 in.	<b>35-892</b>
11/16 in. RESI-MASTER™ Auger	11/16 in.	7-1/2 in.	5 in.	<b>35-730</b>
3/4 in. RESI-MASTER™ Auger	3/4 in.	7-1/2 in.	5 in.	<b>35-893</b>
13/16 in. RESI-MASTER™ Auger	13/16 in.	7-1/2 in.	5 in.	<b>35-731</b>
7/8 in. RESI-MASTER™ Auger	7/8 in.	7-1/2 in.	5 in.	<b>35-896</b>
15/16 in. RESI-MASTER™ Auger	15/16 in.	7-1/2 in.	5 in.	<b>35-897</b>
1 in. RESI-MASTER™ Auger	1 in.	7-1/2 in.	5 in.	<b>35-898</b>
1-1/8 in. RESI-MASTER™ Auger	1-1/8 in.	7-1/2 in.	5 in.	<b>35-899</b>
1-1/4 in. RESI-MASTER™ Auger	1-1/4 in.	7-1/2 in.	5 in.	<b>35-732</b>
Power Ship Augers - Bit Length = 18", Twist = 15", Shank = 7/16" Description	Hole Diameter	Overall Length	Twist Length	Cat. No.
1/2 in. RESI-MASTER™ Auger	1/2 in.	18 in.	15 in.	<b>35-726</b>
5/8 in. RESI-MASTER™ Auger	5/8 in.	18 in.	15 in.	<b>35-971</b>
11/16 in. RESI-MASTER™ Auger	11/16 in.	18 in.	15 in.	<b>35-727</b>
3/4 in. RESI-MASTER™ Auger	3/4 in.	18 in.	15 in.	<b>35-972</b>
13/16 in. RESI-MASTER™ Auger	13/16 in.	18 in.	15 in.	<b>35-728</b>
7/8 in. RESI-MASTER™ Auger	7/8 in.	18 in.	15 in.	<b>35-976</b>
15/16 in. RESI-MASTER™ Auger	15/16 in.	18 in.	15 in.	<b>35-977</b>
1 in. RESI-MASTER™ Auger	1 in.	18 in.	15 in.	<b>35-978</b>
1-1/8 in. RESI-MASTER™ Auger	1-1/8 in.	18 in.	15 in.	<b>35-979</b>
1-1/4 in. RESI-MASTER™ Auger	1-1/4 in.	18 in.	15 in.	<b>35-729</b>

## Auger Bit Extensions

\*Dual locking screws



Auger Bit Extensions, 18" Six flats to fit drill chuck - Allen wrench included Description	Cat. No.
Auger Bit Extension - 5/16 in.	<b>35-818</b>
Auger Bit Extension - 7/16 in.	<b>35-819</b>