


## Flexible Drill Bits

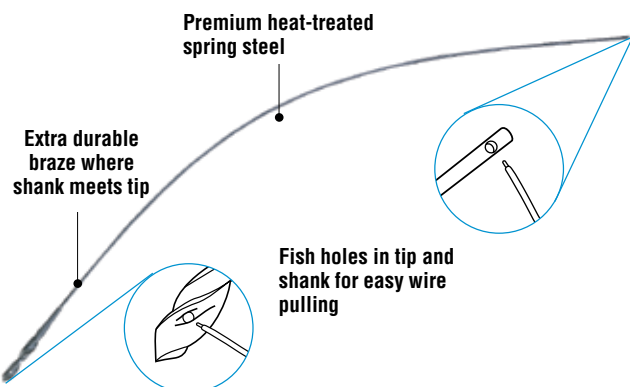

## Screw Point Flexible Drill Bits, Type B

Best for  
WOOD

- Fast and aggressive, self-starting bit
- Ultra-sharp ground threads provide increased pulling power through obstructions
- Designed for easy to tough wood drilling

Description	Shank (in.)	Cat. No.
3/8 in. x 54 in. Screw Point Flexible Bit	3/16	<b>90-082</b>
1/2 in. x 54 in. Screw Point Flexible Bit	3/16	<b>90-085</b>
9/16 in. x 54 in. Screw Point Flexible Bit	3/16	<b>90-088</b>
3/4 in. x 54 in. Screw Point Flexible Bit	1/4	<b>90-091</b>

## Serrated Combination Flexible Bits, Type C

Best for  
light WOOD  
& light METAL

- Fast and aggressive, self-starting bit
- Ultra-sharp ground threads provide increased pulling power through obstructions
- Designed for easy to tough wood and light metal drilling


Description	Shank (in.)	Cat. No.
1/4 in. x 54 in. Serrated Combination Flexible Bit	3/16	<b>90-063</b>
3/8 in. x 54 in. Serrated Combination Flexible Bit	3/16	<b>90-067</b>
1/2 in. x 54 in. Serrated Combination Flexible Bit	3/16	<b>90-070</b>
9/16 in. x 54 in. Serrated Combination Flexible Bit	3/16	<b>90-073</b>

## Flexible Bit Extension

- Connect to chuck end of shaft to increase the length of the bit

Description	Shank	Cat. No.
3/16 in. x 36 in. Flexible Bit Extension	3/16	<b>90-170</b>
1/4 in. x 36 in. Flexible Bit Extension	1/4	<b>90-173</b>

## Flexible Bit Replacement Tool

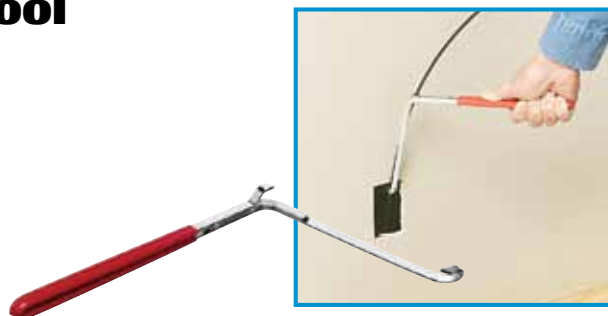

Description	Cat. No.
Flexible Bit Replacement Tool	<b>90-176</b>

## Installer Bits

- Hole in fluted head for pulling wires through walls, ceiling and floors
- Flutes designed for quick chip removal – no clogging or binding
- Premium quality, extra-hard 52-100 carbon bearing steel

Description	Length	Cat. No.
Installer Bit - 1/4 in.	18 in.	<b>35-870</b>
Installer Bit - 3/8 in.	18 in.	<b>35-871</b>
Installer Bit - 1/2 in.	18 in.	<b>35-872</b>

## Power Spade Bits

- The most innovative and fastest spade bit
- Smooth and effortless drilling
- Max operating speed 1500 RPM
- Available in a variety of sizes
- Offers less vibration than other bits



Description	Cat. No.
3/4 in. x 4 in. stubby	<b>36-403</b>
7/8 in. x 4 in. stubby	<b>36-404</b>
1 in. x 4 in. stubby	<b>36-405</b>
1/2 in.	<b>36-413</b>
5/8 in.	<b>36-415</b>
3/4 in.	<b>36-417</b>
7/8 in.	<b>36-419</b>
1 in.	<b>36-421</b>
1-1/8 in.	<b>36-422</b>
1-1/4 in.	<b>36-423</b>
4-pc. Kit with pouch (5/8 in., 3/4 in., 7/8 in., 1 in.)	<b>36-432</b>