

Blued-Steel™ Fish Tapes

- High column strength for longer runs
- Non-oily finish resists rust




Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Rapid-Pak®	Thumb-Winder™	Replacement Tapes
Blued Steel™							
25	1/8 in. x .045 in.	7 in.	Formed hook	–	–	31-012	–
50	1/8 in. x .045 in.	7 in.	Formed hook	–	–	31-010	–
50	1/8 in. x .060 in.	9 in.	Formed hook	31-033**	–	–	–
60	1/8 in. x .060 in.	12 in.	Formed hook	31-055	–	–	31-035
100	1/8 in. x .060 in.	12 in.	Formed hook	–	31-081†	–	31-036
120	1/8 in. x .060 in.	12 in.	Formed hook	31-056	–	–	31-036
200	1/8 in. x .060 in.	12 in.	Formed hook	–	31-098†	–	31-038
240	1/8 in. x .060 in.	12 in.	Formed hook	31-057	–	–	31-038
500	1/8 in. x .060 in.	None	Formed hook	–	–	–	31-3380
700	1/8 in. x .060 in.	None	Formed hook	–	–	–	31-3379
50	1/4 in. x .060 in.	12 in.	Formed hook	31-059	–	–	31-051
100	1/4 in. x .060 in.	12 in.	Formed hook	31-058	–	–	31-050
200	1/4 in. x .060 in.	12 in.	Formed hook	–	–	–	31-052
400	1/4 in. x .060 in.	None	Formed hook	–	–	–	31-2128
15,000	1/4 in. x .060 in.	None	Formed hook	–	–	–	31-2982

†16 in. diameter Rapid-Pak® Case
 **9 in. diameter Tuff-Grip™ Pro Case

Stainless Steel Fish Tapes

- Won't rust or corrode in humid environments
- Stainless steel design provides a smooth pay-out

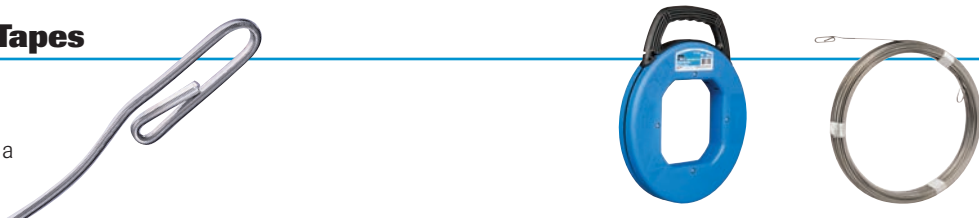

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Replacement Tapes
Stainless Steel					
120	1/8 in. x .060 in.	12 in.	Formed hook	31-066	31-073
240	1/8 in. x .060 in.	12 in.	Formed hook	31-067	31-074

S-Class® Fish Tape

- Non-conductive tape for use around live circuits
- Structural glass core gives you a more durable fiberglass tape



NEW
Speed-Grip™ Pro
handle on
12" models

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Rapid-Pak®	Replacement Tapes
S-Class® Nylon Jacketed Fiberglass						
50	3/16 in. diameter	12 in.	Leader	31-060	31-187†	31-150
50	3/16 in. diameter	12 in.	Eyelet	31-062	31-190†	31-160
100	3/16 in. diameter	12 in.	Leader	31-061	31-186†	31-152
100	3/16 in. diameter	12 in.	Eyelet	31-063	31-189†	31-162
200	3/16 in. diameter	16 in.	Leader	31-064*	31-207†	31-155
200	3/16 in. diameter	16 in.	Eyelet	31-065*	31-208†	31-165
300	3/16 in. diameter	None	Eyelet	-	-	31-2138

* 16 in. diameter Tuff-Grip™ Case † 16 in. diameter Rapid-Pak® Case

Zoom™ Fish Tapes

- Great for hard to navigate piping with multiple bends
- Nylon jacket protects the steel core while adding to the slipperiness of Zoom™



NEW
Speed-Grip™ Pro
handle on
12" models

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Replacement Tapes
Zoom™ Nylon Jacketed Stainless Steel					
50	3/16 in. diameter	12 in.	Eyelet	31-090	31-091
100	3/16 in. diameter	12 in.	Eyelet	31-092	31-093
200	3/16 in. diameter	16 in.	Eyelet	31-096*	31-097

* 16 in. diameter Tuff-Grip™ Case

Volt-Guard™ Fish Tapes

- Non-conductive up to 1000V
- Elliptical design gives the Volt-Guard™ greater pushing power




NEW

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Replacement Tapes
Fiberglass					
60	.1875 in. x .094 in.	12 in.	Eyelet	31-542	31-552
120	.1875 in. x .094 in.	12 in.	Eyelet	31-544	31-554

Gold-Fish® Fish Tape

- Ultra-flexible tape for hard-to-navigate areas
- Brass-plated coils resist rust

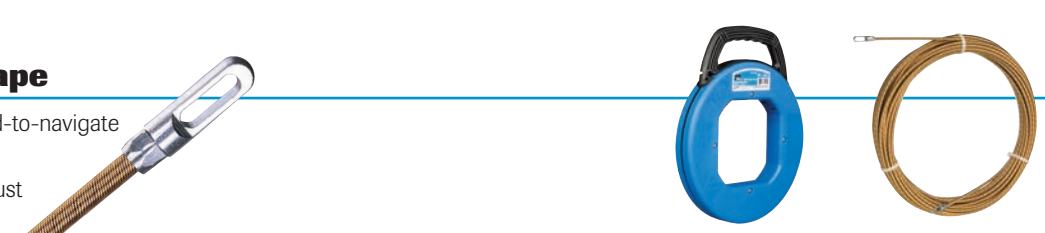

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Replacement Tapes
Gold-Fish® Brass Plated Steel Coil					
25	3/16 in. diameter	None	Eyelet	-	31-140
50	3/16 in. diameter	12 in.	Eyelet	31-144	31-141
100	3/16 in. diameter	None	Eyelet	-	31-142