


## Clamps

- Use to secure wires, cables, pipes, tubing and fiber optics
- Ultraviolet black nylon clamps available for internal and external use
- Use with #10 mounting screw

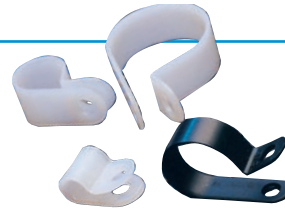

Description	Closed Diameter	Center to Center	Width	Thickness	Mounting Hole	Qty./Bag	Cat. No.
Natural Nylon	.125 in./3.18mm	.343 in./8.71mm	3/8 in.	.050 in./1.27mm	.203 in./5.16mm	100	<b>IT125CCL-C</b>
Natural Nylon	.250 in./6.35mm	.421 in./10.69mm	3/8 in.	.050 in./1.27mm	.203 in./5.16mm	100	<b>IT250CCL-C</b>
UV Black Nylon						100	<b>IT250CCL-C0</b>
Natural Nylon	.375 in./9.52mm	.500 in./12.70mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT375CCL2-C</b>
UV Black Nylon						100	<b>IT375CCL2-C0</b>
Natural Nylon	.500 in./12.70mm	.553 in./14.05mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT500CCL2-C</b>
Natural Nylon	.625 in./15.88mm	.625 in./15.88mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT625CCL2-C</b>
Natural Nylon	.750 in./19.05mm	.699 in./17.75mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT750CCL2-C</b>
Natural Nylon	1.000 in./25.40mm	.825 in./20.96mm	1/2 in.	.060 in./1.52mm	.203 in./5.16mm	100	<b>IT1000CCL2-C</b>

## Flange-Type Plastic Anchors



- Multi-purpose use in solid materials or hollow walls, will not fall through
- For use with sheet-metal or wood screws
- High-impact plastic construction resists moisture, corrosion and deterioration

Description	Screw Size	Drill Size (In.)	Quantity	Cat. No.
Yellow – 7/8 in. long	6-8-10	3/16	100	<b>90-041</b>
Red – 1 in. long	10-12	1/4	100	<b>90-042</b>
White – 1-1/2 in. long	14-16	5/16	50	<b>90-044</b>

## Flange-Type Plastic Anchor Kits



- Kits include flange-type anchors, slotted/Phillips head screws and masonry bit
- Convenient plastic storage container

Contents	Cat. No.
100 #6-8-10 x 7/8 in. Flange-type anchors, 100 #8 x 1 in. combo-head, sheet-metal screws & 1-3/16 in. masonry bit (carbide-tipped)	<b>90-051</b>
100 #10-12 x 1 in. Flange-type anchors, 100 #10 x 1-1/4 in. combo-combo-head, sheet-metal screws & 1-1/4 in. masonry bit (carbide-tipped)	<b>90-052</b>
100 #10-12 x 1 in. Flange-type anchors, 100 #12 x 1 in. combo-head, sheet-metal screws & 1-1/4 in. masonry bit (carbide-tipped)	<b>90-053</b>
40 #14-16 x 1-1/2 in. Flange-type anchors, 40 #14 x 1-1/2 in. combo-head, sheet-metal screws 1-5/16 in. masonry bit (carbide-tipped)	<b>90-054</b>
100 #10-12 x 1 in. Flange-type anchors, 100 #10 x 1 in. combo-head, sheet-metal screws & 1-1/4 in. masonry bit (carbide-tipped)	<b>90-055</b>

## Flexible Tubing\*

- Flexible polyethylene cuts easily to desired length
- Splits open for neat “bundling” of wiring jobs
- Snaps shut to create a continuous protective cover

Description	Qty.	Cat. No.
3/8 in. Flexible Tubing	10 ft.	<b>772240</b>
3/8 in. Flexible Tubing	1,200 ft.	<b>772245</b>
1/2 in. Flexible Tubing	1 ft.	<b>772241</b>
1/2 in. Flexible Tubing	900 ft.	<b>772244</b>
1 in. Flexible Tubing	5 ft.	<b>772242</b>
1 in. Flexible Tubing	250 ft.	<b>772243</b>

\*Buchanan branded

