


## In-Sure™ Push-In Wire Connectors

- No-twist connection reduces repetitive motion fatigue
  - Low insertion force for fast and easy connections
  - Compact size makes installation easy
  - Clear shell gives visual verification of connection
  - UL Listed to 486C and CSA Certified to C22.2 #188
  - UL 467 Listed for grounding and bonding applications
- Accepts the following copper wire sizes
    - **Solid**  
#20 - #12 solid
    - **Stranded**  
#16 - #14 (≤19 str.)  
#18 (≤7 str.)
    - **Stranded (Tin Bonded)**  
#14 - #12 (≤19 str.)  
#16 (≤26 str.)  
#18 (≤16 str.)



Model	Color	Ports	Length		Width		Height		Quantity	Cat. No.
			In.	mm	In.	mm	In.	mm		
84	Red	2	.355	9.02	.434	11.02	.729	18.52	Box of 100	<b>30-084</b>
									Jar of 300	<b>30-084J</b>
									Box of 1,000	<b>30-184</b>
									Box of 5,000	<b>30-684</b>
85	Orange	3	.355	9.02	.591	15.01	.729	18.52	Box of 100	<b>30-085</b>
									Jar of 250	<b>30-085J</b>
									Box of 1,000	<b>30-185</b>
									Box of 5,000	<b>30-685</b>
86	Yellow	4	.355	9.02	.748	18.99	.729	18.52	Box of 100	<b>30-086</b>
									Jar of 200	<b>30-086J</b>
									Box of 1,000	<b>30-186</b>
									Box of 4,000	<b>30-686</b>
87	Gray	5	.355	9.02	.907	23.03	.729	18.52	Box of 50	<b>30-087</b>
									Jar of 150	<b>30-087J</b>
									Box of 1,000	<b>30-187</b>
									Box of 5,000	<b>30-687</b>
88	Blue	6 Stacked	.607	15.42	.603	15.32	.729	18.52	Box of 50	<b>30-088</b>
									Jar of 100	<b>30-088J</b>
									Box of 1,000	<b>30-188</b>
									Box of 5,000	<b>30-688</b>
90	Black	8	.355	9.02	1.38	35.03	.717	18.21	Box of 50	<b>30-090</b>
									Jar of 100	<b>30-090J</b>
									Box of 1,000	<b>30-190</b>
									Box of 2,000	<b>30-690</b>

**Installation as easy as 1-2-3...**

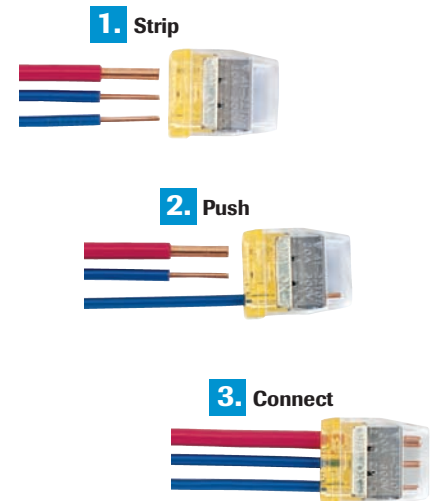

COPPER TO COPPER ONLY. Do not use on aluminum.  
 Temperature rating: 105°C (221°F) maximum  
 600V maximum building wire, 1000V maximum signs or lighting fixtures

