


## Appliance Rocker Switches

- Great for home appliances, computer equipment, automotive and industrial controls
- Appliance Rockers fit standard .55 in. × 1.12 in. panel cut outs
- Miniature Rockers fit .520 in. × .776 in. panel cut outs
- Plain and lighted versions available
- Operating temperature: 32°F to 185°F (0°C to 85°C)
- Bulk packaging of 100 available upon request

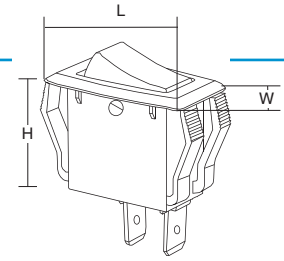

Product	Description	Rocker	Poles	Circuitry	Termination Style	No. of Terminals	Ratings	Dimensions (L" × W" × H")	Cat. No.
	Appliance Rocker Switch	Black	SPST	On-Off	Spade	2	16 Amp 1/3 HP 125 VAC, 10 Amp 1/2 HP 250 VAC	1.24 × 68 × .77	<b>774038</b>
			SPDT	On-On	Spade	3			<b>774049</b>
			SPDT	On-Off-On	Spade	3			<b>774059</b>
	Appliance Rocker Switch	Red Lighted	SPST	On-Off	Spade	3*	16 Amp 1/3 HP 125 VAC, 10 Amp 1/2 HP 250 VAC	1.24 × 68 × .77	<b>774039</b>
	Appliance Rocker Switch**	Visi-Red, Printed On-Off Vertical	SPST	On-Off	Spade	2	16 Amp 125 VAC, 10 Amp 250 VAC, 3/4 HP 125-250 VAC	1.24 × 68 × .72	<b>774047</b>
	Appliance Rocker Switch**	Visi-Red	SPST	On-Off	Spade	2	16 Amp 125 VAC, 10 Amp 250 VAC, 3/4 HP 125-250VAC	1.24 × 68 × .72	<b>774052</b>
	Miniature Rocker Switch	Red Lighted	SPST	On-Off	Spade	3*	16 Amp 1/3 HP 125 VAC, 10 Amp 1/2 HP 250 VAC	.83 × .59 × .50	<b>774048</b>

\*\*   

†Bulk Package of 100

\*3rd terminal to power lighted rocker