

Pilot and Signaling Devices


Heavy-Duty 22.5 mm Watertight/Oiltight Push Buttons

C-2000

Standard
Illuminated
600 VAC Max., 300 VDC Max.
10 Amps Continuous AC, 2.5 Amps Continuous DC

Selection Process

Select operator below + Select power supply from pages 9-92 & 9-93 + Select contact block from page 9-93 + Select nameplate, if required, from pages 9-95 to 9-97 = Complete unit

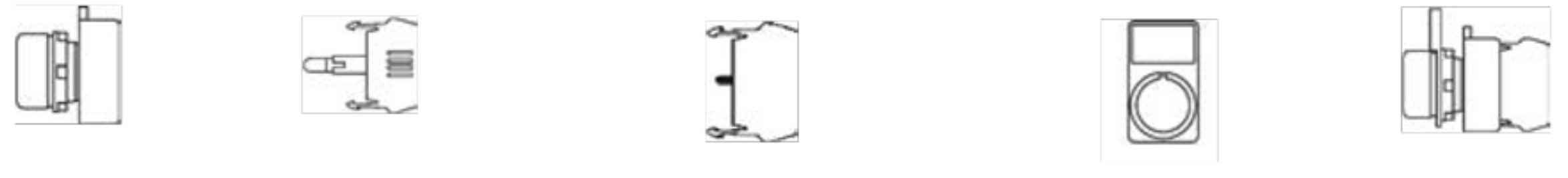

Flush

Operators

Standard Push Button Type	Operator Style	Lens Type	Product Number
Flush	Round Polished Chrome	Diffused	P9CPL*GD
Flush	Round Satin Chrome	Diffused	P9MPL*GD
Flush	Round Engineered Plastic	Diffused	P9XPL*GD
Flush	Squared Engineered Plastic	Diffused	P9SPL*GD
Extended	Round Polished Chrome	Diffused	P9CPL*SD
Extended	Round Satin Chrome	Diffused	P9MPL*SD
Extended	Round Engineered Plastic	Diffused	P9XPL*SD
Extended	Squared Engineered Plastic	Diffused	P9SPL*SD
Recessed	Round Polished Chrome	Diffused	P9CPL*ED
Recessed	Round Satin Chrome	Diffused	P9MPL*ED
Recessed	Round Engineered Plastic	Diffused	P9XPL*ED
Recessed	Squared Engineered Plastic	Diffused	P9SPL*ED



Recessed

Replace asterisk (*) in product number with color code from table below

*Colors

Colors	Red	Green	Yellow	Blue	White	Orange	Clear	No Lens ¹
*Color code	R	V	G	L	B	A	I	0



Square Extended

