

Pilot and Signaling Devices

Heavy-Duty 22.5 mm Watertight/Oiltight Accessories

C-2000

For Base-Mounted Pilot Devices

600 VAC Max., 300 VDC Max.


10 Amps Continuous AC, 2.5 Amps Continuous DC

Plastic Enclosures

(NEMA 1, 3, 3R, 3S, 4, 4X, 12, 13 & IP66)

For use with operators from pages 9-57 to 9-90.

Enclosure Holes	Enclosure Color	For use with	Product Number
1	Gray With Yellow Cover	P9S Plastic Operators P9X Plastic Operators	P9EPEG1
1	Gray	P9S Plastic Operators P9X Plastic Operators	P9EPE01
2	Gray	P9S Plastic Operators P9X Plastic Operators	P9EPE02
3	Gray	P9S Plastic Operators P9X Plastic Operators	P9EPE03
4	Gray	P9S Plastic Operators P9X Plastic Operators	P9EPE04
6	Gray	P9S Plastic Operators P9X Plastic Operators	P9EPE06

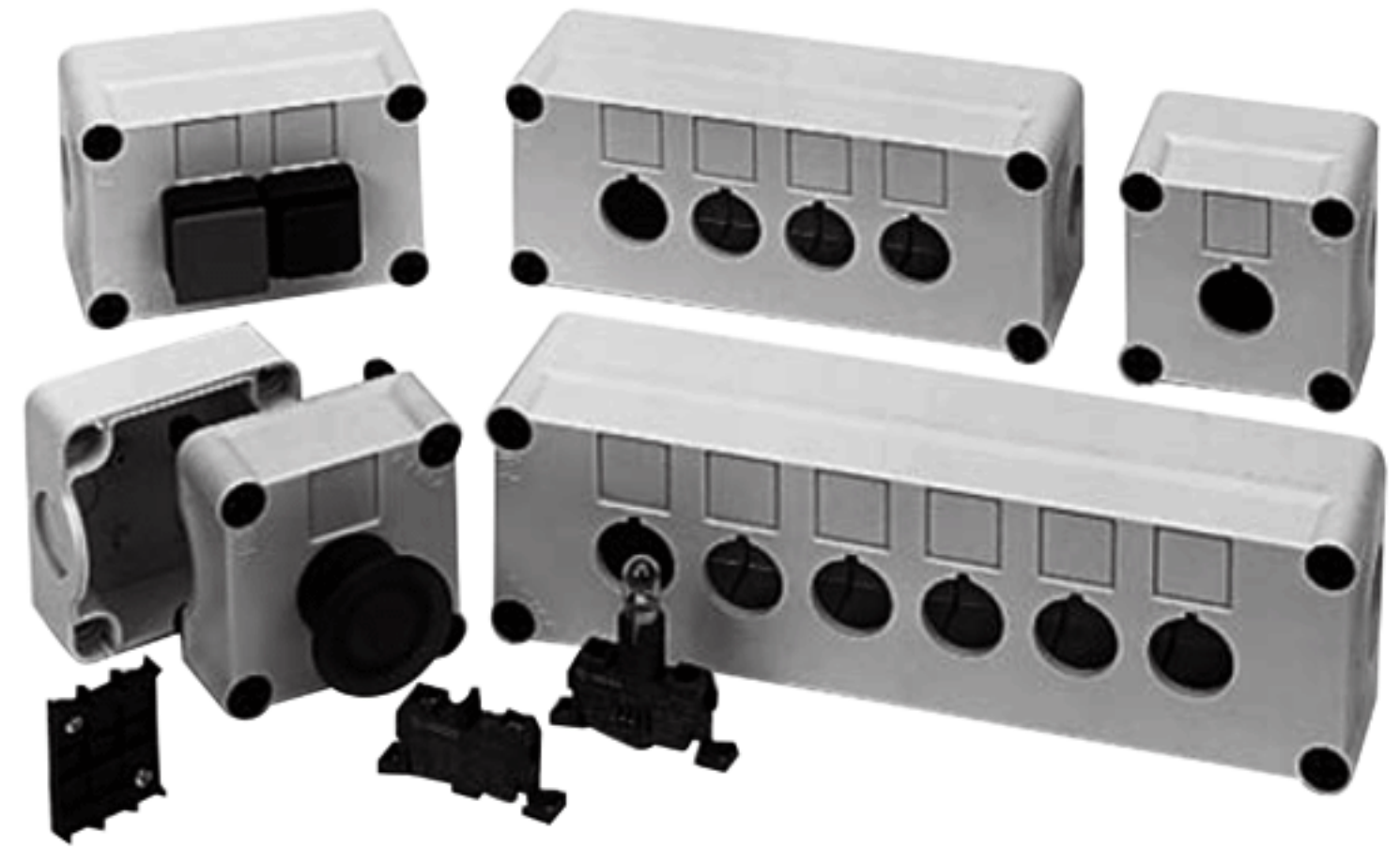

Plastic Enclosures

Legend Plates For Plastic Enclosures

(Self-adhesive, black background)

Marking Language	Legend Plate Marking	Product Number ¹
Symbol	→	P9AELN006
Symbol	I	P9AELN028
Symbol	O	P9AELN029
Symbol	II	P9AELN035
Symbol	III	P9AELN038
Symbol	0-I	P9AELN039
Symbol	I-O-II	P9AELN042
English	Stop	P9AELN201
English	Start	P9AELN202
English	Down	P9AELN203
English	Up	P9AELN204
English	Close	P9AELN205
English	Open	P9AELN206
English	On	P9AELN212
English	Off	P9AELN213
English	Forward	P9AELN214
English	Reverse	P9AELN215
English	Auto	P9AELN219
English	Left	P9AELN222
English	Right	P9AELN224
French	Arret	P9AELN301
French	Arriere	P9AELN302
French	Avant	P9AELN303
French	Descente	P9AELN304
French	Droite	P9AELN305
French	Gauche	P9AELN306
French	Marche	P9AELN308
French	Fermer	P9AELN309
French	Manuel	P9AELN312
French	Ouvrir	P9AELN316
Spanish	Cerrar	P9AELN501
Spanish	Adelante	P9AELN502
Spanish	Izquierda	P9AELN504
Spanish	Bajar	P9AELN505
Spanish	Abrir	P9AELN506
Spanish	Subir	P9AELN507
Spanish	Atras	P9AELN508
Spanish	Derecha	P9AELN509
Spanish	Marcha	P9AELN510
Spanish	Paro	P9AELN511
Spanish	Rapido	P9AELN512
Spanish	Rearme	P9AELN515
Spanish	Linea	P9AELN523
None	Blank	P9AELN
Specify	Custom engraved, seven characters maximum	P9AELNEN

Ground Terminal

Product Number	List Price GO-10GC
P9AEMT	\$1.00

Base-Mount Power Supplies (Screw Terminals Only)

Power Supply Type	Bulb Type	Voltage	Product Number	List Price GO-10GC
Full Voltage	Incandescent	No lamp	P9PDNBO	\$17.50
Full Voltage	Incandescent	6V	P9PDNBA	\$21.00
Full Voltage	Incandescent	12V	P9PDNBB	\$21.00
Full Voltage	Incandescent	24V	P9PDNBD	\$21.00
Full Voltage	Incandescent	48V	P9PDNBDG	\$21.00
Full Voltage	Incandescent	60V	P9PDNBH	\$21.00
Full Voltage	Incandescent	130V	P9PDNBL	\$21.00
Full Voltage	LED	6V	P9PDNBAL*	\$36.00
Full Voltage	LED	12V	P9PDNBBL*	\$36.00
Full Voltage	LED	24V	P9PDNBDL*	\$36.00
Full Voltage	LED	48V	P9PDNBGL*	\$36.00
Full Voltage	LED	120V	P9PDNBGL*	\$36.00
Full Voltage	Neon	110V	P9PDNBIN	\$25.00
Full Voltage	Neon	220V	P9PDNBMN	\$25.00
Resistor	Incandescent	110-120V	P9PRNBJ ²	\$14.00
Resistor	Incandescent	220-240V	P9PRNBN ³	\$14.00
Diode Resistor	Incandescent	220-240V	P9PRDBN ⁴	\$35.00
Long-Life Resistor	Incandescent	110-120V	P9PRLBJ	\$35.00

²Must be used with P9PDNBH full-voltage power supply (wired-in series).

³Must be used with P9PDNBL full-voltage power supply (wired-in series).

⁴AC only.

Replace asterisk (*) in LED product number with code from LED colors table.

*LED Colors

Colors	Red	Green	Yellow	Orange	White	Blue
*Color Code	R	V	G	A	B	L

Contact Blocks (Screw Terminals Only)

Contact Block Type	Contact Configuration	Product Number	List Price GO-10GC
Base Mount	1NO	P9B10BN	\$7.50
Base Mount	1NC	P9B01BN	\$7.50

