

TOOL SPECIFICATIONS

1/2"



CATALOG NUMBER	0300-20	0301-20	0302-20
RPM	0-850	0-850	0-850
VOLTS	120V	120V	120V
AMP	8.0	8.0	8.0
CHUCK	KEYED	KEYED	ALL METAL GRIP-LOK SINGLE SLEEVE
CORD	FIXED, GROUNDED	QUIK-LOK, GROUNDED	QUIK-LOK, GROUNDED
SIDE HANDLE	360° SIDE HANDLE	360° SIDE HANDLE	360° SIDE HANDLE
LOCK-PREVENT BUTTON	AVAILABLE	AVAILABLE	AVAILABLE
CASE	AVAILABLE	AVAILABLE	AVAILABLE

STANDARD EQUIPMENT 0300-20 – 49-15-0265 360° Side Handle, 48-66-1355 1/2" Chuck, 48-66-3280 Chuck Key, 48-66-4045 Flexible Key Holder. **0301-20** – 49-15-0265 360° Side Handle, 48-76-4008 8", 3-wire Quik-Lok Cord, 48-66-1355 1/2" Chuck, 48-66-3280 Chuck Key, 48-66-4045 Flexible Key Holder. **0302-20** – 49-15-0265 360° Side Handle, 48-76-4008 8", 3-wire Quik-Lok Cord, 48-66-1510 1/2" Single Sleeve All Metal Keyless Chuck

3/8"



CATALOG NUMBER	0200-20	0201-20	0202-20
RPM	0-1200	0-2500	0-1200
VOLTS	120V	120V	120V
AMP	7.0	7.0	7.0
CHUCK	KEYED	ALL METAL GRIP-LOK 2-SLEEVE	ALL METAL GRIP-LOK SINGLE SLEEVE
CORD	FIXED, GROUNDED	FIXED 10'	QUIK-LOK, GROUNDED
SIDE HANDLE	360° SIDE HANDLE	360° SIDE HANDLE	360° SIDE HANDLE
LOCK-PREVENT BUTTON	AVAILABLE	AVAILABLE	AVAILABLE
CASE	AVAILABLE	AVAILABLE	AVAILABLE

STANDARD EQUIPMENT 0200-20 – 49-15-0265 360° Side Handle, 48-66-3080 Chuck Key, 48-66-4045 Flexible Key Holder, 48-66-0806 3/8" Chuck. **0201-20** – 49-15-0265 360° Side Handle, 48-66-1530 3/8" 2-Sleeve All Metal Keyless Chuck, 10' 2-wire Fixed Cord. **0202-20** – 49-15-0265 360° Side Handle, 48-76-4008 8" 3-wire Quik-Lok Cord, 48-66-1520 3/8" Single Sleeve All Metal Keyless Chuck

1/4"



CATALOG NUMBER	0100-20	0101-20
RPM	0-2500	0-4000
VOLTS	120V	120V
AMP	7.0	7.0
CHUCK	KEYED	KEYED
CORD	QUIK-LOK, GROUNDED	QUIK-LOK, GROUNDED
SIDE HANDLE	360° SIDE HANDLE	N/A
LOCK-PREVENT BUTTON	AVAILABLE	AVAILABLE
CASE	AVAILABLE	AVAILABLE

STANDARD EQUIPMENT 0100-20 – 48-76-4008 8' 3-wire Quik-Lok Cord, 49-15-0265 360° Side Handle, 48-66-3200 Chuck Key, 48-66-4080 Flexible Key Holder, 48-66-0070 1/4" Chuck. **0101-20** – 48-76-4008 8' 3-wire Quik-Lok Cord, 48-66-3200 Chuck Key, 48-66-4080 Flexible Key Holder, 48-66-0070 1/4" Chuck.

ONE YEAR FREE MAINTENANCE PROGRAM

ONE YEAR FREE MAINTENANCE – The 0100-20, 0101-20, 0200-20, 0201-20, 0202-20, 0300-20, 0301-20, 0302-20 are covered against normal wear for one year from the date of purchase (proof of purchase is required).

Anytime during the first year take your tool or ship prepaid to a Milwaukee Branch Office Service Center where it will be checked and serviced at no charge and returned transportation prepaid. The plan does not apply where evidence of misuse, use of improper accessories or repairs have been made by others.

ACCESSORIES

QUIK-LOK® CORD SETS

Quick detachment from tool for tangle free carrying and storage. Instant field repair and safe replacement. For models 0301-20, 0302-20 0202-20, 0100-20, 0101-20.

Catalog No.	Description	NEMA Plug Type
48-76-4008	3-Wire 8' Quik-Lok	5-15P
48-76-4025	3-Wire 25' Quik-Lok	5-15P



QUIK-LOK® CORD SETS WITH TWIST LOCK PLUG

Catalog No.	Description	NEMA Plug Type
48-76-4108	3-Wire 8' Quik-Lok W/Twist Lock Plug	L5-20P
48-76-4125	3-Wire 25' Quik-Lok W/Twist Lock Plug	L5-20P

LOCK PREVENT BUTTON

31-53-0205 For Pistol Drills and Screwdrivers.

STEEL CARRYING CASE

48-55-0711 For Pistol Drills and Screwdrivers. Overall size 13-1/2" long, 6" high and 8-3/4" wide.



SIDE HANDLE

49-15-0265 360° side handle for Pistol Drills.

ALL-METAL GRIP-LOK™ CHUCKS

All-metal for extreme durability. Grip-Lok™ prevents bit slippage. Hardened jaws for high gripping torque. Lightly knurled for a comfortable grip. Features a thick, clear-coat finish to prevent rusting.

48-66-1530	3/8", two sleeve with 3/8-24 thread.
48-66-1375	1/2", two sleeve with 1/2-20 thread.
48-66-1510	1/2", single sleeve with 1/2-20 thread (for tools with spindle lock integral with the tool).
48-66-1520	3/8", single sleeve with 1/2-20 thread. (for tools with spindle lock integral with the tool).



Available in 3/8" and 1/2"

 
HEAVY-DUTY KEYED CHUCKS

48-66-1355	1/2", 1/2-20 thread.
48-66-0806	3/8", 1/2-20 thread.
48-66-0070	1/4", 3/8-24 thread.

PathFinder™

■ Drill 2 to 3 times FASTER than spade bits.

- Drill 90° holes.
- Drill curved or irregular holes.
- Cuts mortises easily.
- Cuts channels and grooves.
- Drills and counter bores with one bit.




- Leaves clean, smooth holes.
- PathFinder bits are easily resharpened.
- Exclusively from Milwaukee.



PATHFINDER BITS

48-13-8000	1/4" Bit
48-13-8001	3/8" Bit
48-13-8002	1/2" Bit
48-13-8003	5/8" Bit
48-13-8004	3/4" Bit
48-13-8005	7/8" Bit
48-13-8006	1" Bit
48-13-8007	1-1/4" Bit
49-22-8001	3pc. Bit set: 1/2", 3/4", 1"
49-22-8002	5pc. Bit set: 1/4", 1/2", 3/4", 1", 1-1/4"

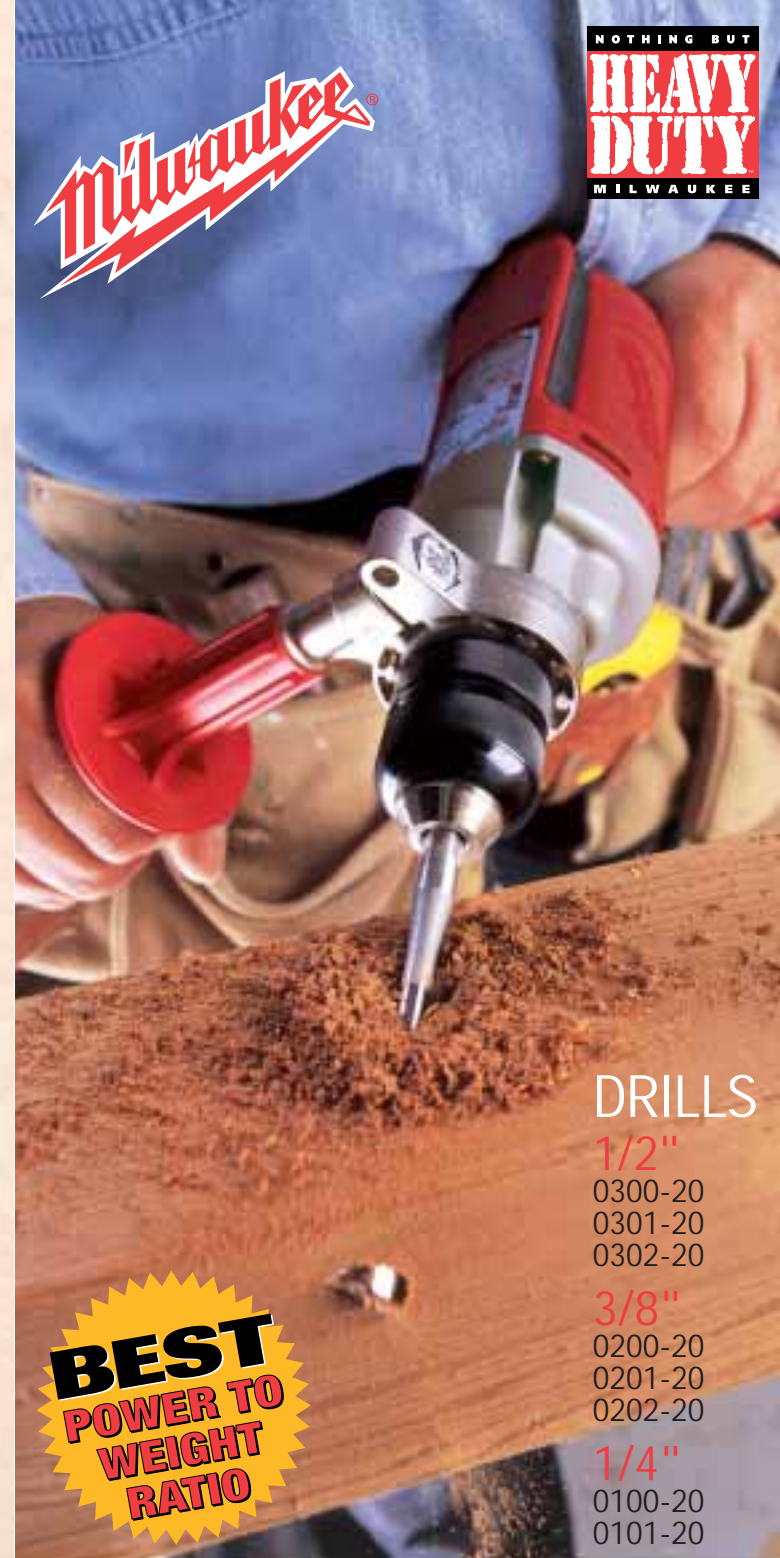

NOTHING BUT
**HEAVY
DUTY**
MILWAUKEE

DRILLS

- 1/2"
 - 0300-20
 - 0301-20
 - 0302-20
- 3/8"
 - 0200-20
 - 0201-20
 - 0202-20
- 1/4"
 - 0100-20
 - 0101-20

**BEST
POWER TO
WEIGHT
RATIO**

MILWAUKEE ELECTRIC TOOL CORPORATION
A Company Within The Atlas Copco Group

FOR MORE INFORMATION CALL 1-800-SAWDUST (800-729-3878)

WWW.MILWAUKEETOOL.COM

DRILLS-R/2-01/C-Graphic/50M/Printed in U.S.A.

