

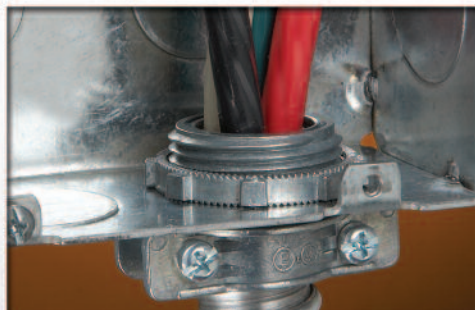


AC/MC CABLE FITTINGS

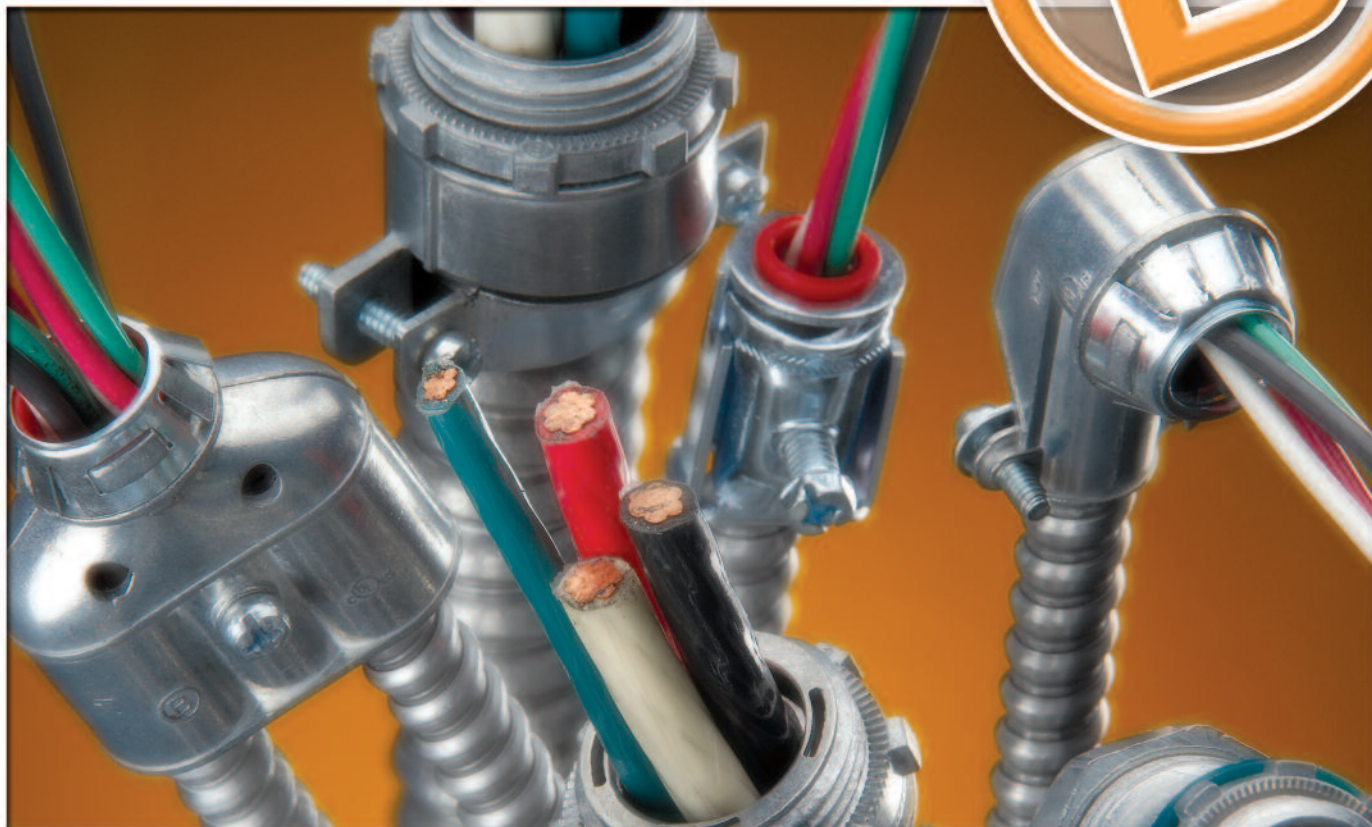

WHEN YOU'RE RUNNING CABLE,
RUN WITH THE BEST.

 **BRIDGEPORT**
www.bptfittings.com

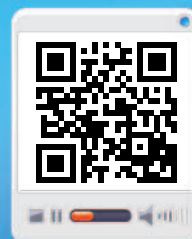

SCAN HERE
TO VISIT OUR
**YOUTUBE
CHANNEL**

SELECTION AND INNOVATION.

GET ALL YOUR AC/MC
CABLE JOBS DONE
FAST, AND DONE RIGHT
WITH BRIDGEPORT.


Quality, innovation, selection and availability – you get it all with the industry's leading AC/MC cable fittings line from Bridgeport. So all the choices you need in steel, malleable and zinc share the most important product attribute: *a Bridgeport Circle B on the fitting.* It's the mark that says you take pride in your work.



From duplex snap-ins and single and double screw connectors to transition couplings and universal straps with stronger straps – Bridgeport's got you covered. We've engineered in performance differences that can help you every day – better fit, faster install and assured quality out of the box. Plus, innovations like deep-slot tri-head screws, tapped locknuts that don't "jump" threads and snap-ins that snap out easy, too.

Make the smart selection and choose Bridgeport cable fittings every time. For installations that last a lifetime.

Call Bridgeport at 203-377-5944 or visit us on-line at www.bptfittings.com and be sure all your AC and MC connections are A-OK.

Because the sure way to spell AC/MC success is with a B. Bridgeport.

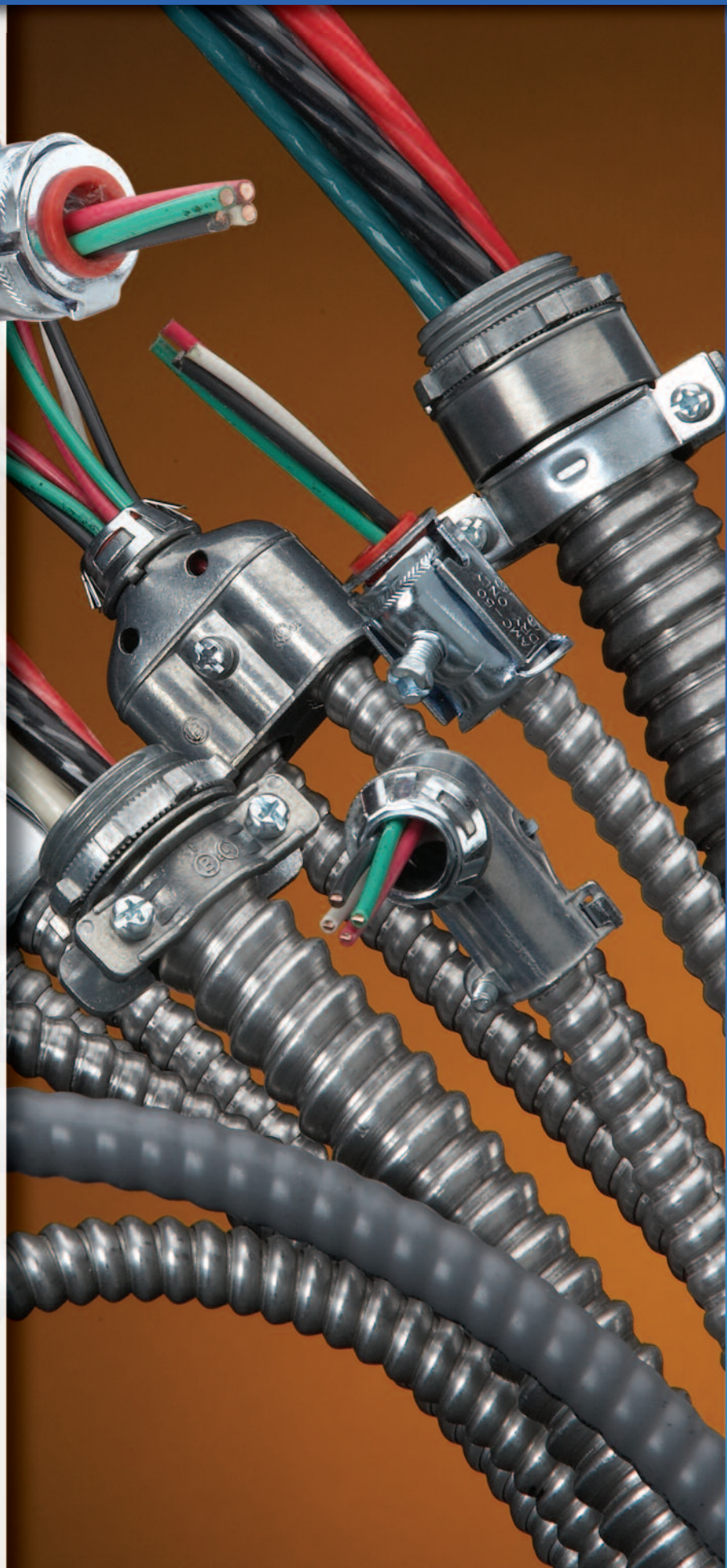

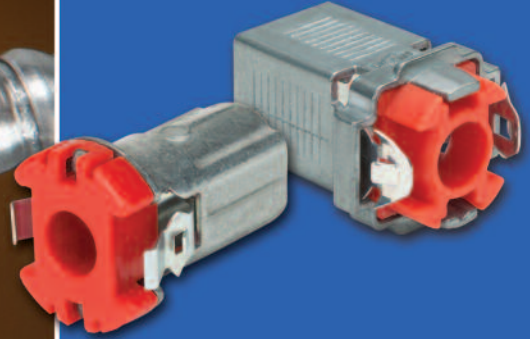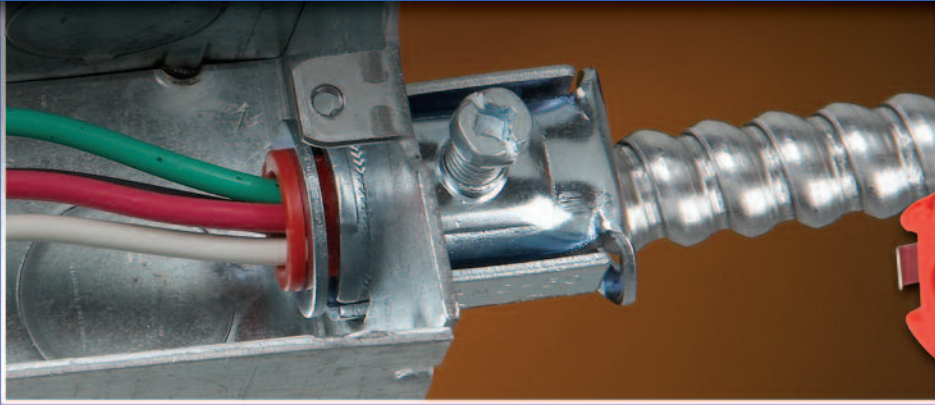

BRIDGEPORT YOUR BEST ALTERNATIVE FOR SNAP-IN FITTINGS

Save time and money with every installation.

Bridgeport's fittings snap right into the box – with the satisfying click of performance.

Convenience.

Pre-assemble cable, or easily install after connector is in the box. Either way, assembly is a snap. You can remove our connectors almost as easy as you pop them in. Simply depress the tabs and remove.

Designed to work the way you work.

On the job, you'll appreciate the attention to detail and the many convenient features that make our line so easy to use.



FEATURED PRODUCT:

WHIPPER-SNAP® Snap-in "U" Shaped Strap Duplex Connector (SG3838ASP)

Connect two 14/2 to 10/3 AC/MC cables or 3/8" flexible metal conduit to a box or enclosure. Simply push the connector into the box for a quick, secure connection every time.



Large Feeder Cable Fittings

Bridgeport's AC/MC Connectors are the industry's finest choice for connecting large branch circuit or feeder MC Cable to boxes, enclosures, load-centers, panelboards, transformers, switchgear, and other electrical equipment. Use Bridgeport's fittings to obtain a robust mechanical connection in commercial and industrial facilities such as paper mills, chemical plants, utility plants, educational facilities, office buildings as well as multi-family, residential complexes.



403-DC2

AC/MC Selection Chart

Catalog Number	UPC Number	Trade Size	K.O. Size	Cable
----------------	------------	------------	-----------	-------

DIE CAST SQUEEZE CONNECTORS

403-DC2	15403	3/8"	1/2"	12/3 thru 10/3 (.58"-.61") AC/MC
---------	-------	------	------	----------------------------------



560-DC2

561-DCI2



560ASP



560SP



BL-17



DIE CAST STRAP TYPE CONNECTORS

560-DC2	15560	3/8"	1/2"	14/4 to 10/4 (.44"-.61") AC/MC/MCI-A
561-DC2	15561	3/4"	3/4"	12/4 thru 8/4 (.61"-.87") AC/MC
560-DCI2	16560	3/8"	1/2"	14/4 to 10/4 (.43"-.61") AC/MC/MCI-A
561-DCI2	16561	3/4"	3/4"	AC/MC: 12/4 thru 8/4 (.61"-.87") AC/MC
560-MCIA2	72560	3/8"	1/2"	14/2 to 10/4 (.38"-.61") MCI-A
560ASP	08560	3/8"	1/2"	14/2 to 10/3 (.43"-.61") AC/MC/MCI-A (Whipper-Snap®)
560MCIA	71560	3/8"	1/2"	14/2 to 10/4 (.42"-.61") AC/MC/MCI-A (Whipper-Snap)
560SP	70560	3/8"	1/2"	14/2 to 10/3 (.43"-.61") AC/MC (Whipper-Snap)
BL-17	15567	1/2"	1/2"	8/3 AC90, 8/3 or 6/3 MCI-A
BL-17I	16567	1/2"	1/2"	8/3 AC90, 8/3 or 6/3 MCI-A
BL-18	15568	3/4"	3/4"	6/3 AC90
BL-18I	16568	3/4"	3/4"	6/3 AC90
BL-19	15569	1"	1"	3/3 AC90
BL-19I	16569	1"	1"	3/3 AC90

DIE CAST 1 OR 2 SCREW CONNECTORS

501-DC2	15501	3/8"	1/2"	14/2-10/3 Steel MC/MCI-A .43"-.61" Steel or AL AC
545-DC2	15545	3/8"	1/2"	14/2 thru 10/3 (.44"-.61") AC/MC
563-DC2	15563	3/8"	1/4"	14/2-12/2 AC/MC/NM
565-DC2	15565	3/8"	1/2"	14/2 to 10/3 (.38"-.53") MC/MCI-A
566-DC2	15566	3/8"	1/2"	14/4 to 10/3 (.44"-.53") ALMC/MCI-A
845ASP	08501	3/8"	1/2"	12/2 to 10/4 (.43"-.61") AC/MC/MCI-A
845SP	70501	3/8"	1/2"	12/2 to 10/4 (.43"-.61") AC/MC/MCI-A
840SP	70566	3/8"	1/2"	14/2 to 10/3 (.44"-.61") AC/MC/MCI-A
8400SP	70565	3/8"	1/2"	14/4 to 10/3 (.44"-.61") AC/MC/MCI-A (Whipper-Snap)
8400ASP	71565	3/8"	1/2"	14/2 to 10/3 (.38"-.53") AC/MC/MCI-A (Whipper-Snap)



501-DC2

545-DC2

563-DC2



565-DC2

566-DC2

840SP



845ASP

845SP

8400SP



403-I

Catalog Number	UPC Number	Trade Size	K.O. Size	Cable
----------------	------------	------------	-----------	-------

MALLEABLE IRON SINGLE SCREW CONNECTORS

403-I	10403	3/8"	1/2"	14/4 to 6/3 AC/MC/MCI-A
-------	-------	------	------	-------------------------


 SG38ASP
 SG38MCIA

SG38SP

DIE CAST LOW PROFILE "U" SHAPED STRAP CONNECTORS

SG38ASP	08570	3/8"	1/2"	14/4 to 10/3 (.43"-.61") AC/MC/MCI-A (Whipper-Snap)
---------	-------	------	------	---

SG38MCIA	71570	3/8"	1/2"	14/2 to 10/3 (.38"-.56") AC/MC/MCI-A (Whipper-Snap)
----------	-------	------	------	---

SG38SP	70570	3/8"	1/2"	14/4 to 10/3 (.43"-.61") AC/MC/MCI-A (Whipper-Snap)
--------	-------	------	------	---



570-DC2

570-DCI2

570-DC2	15570	3/8"	1/2"	14/2 to 10/3 (.38"-.61") AC/MC/MCI-A
---------	-------	------	------	--------------------------------------

570-DCI2	16570	3/8"	1/2"	14/4 to 10/3 (.38"-.61") AC/MC/MCI-A
----------	-------	------	------	--------------------------------------



570-RI

 570-GI
 570-G/RI

DIE CAST COLOR-CODED LOW PROFILE CONNECTORS

570-GI	75706	3/8"	1/2"	14/2 to 10/3 (.38"-.61") HCF/AC (Green color)
--------	-------	------	------	---


570-RI	75708	3/8"	1/2"	18/2 to 12/4 (.38"-.61") Fire Alarm MC (Red color)
--------	-------	------	------	--

DIE CAST 2 SCREW CONNECTORS


653-DC2	15653	1/2"	1/2"	8/2-6/4 (.675"-.90") AC
---------	-------	------	------	-------------------------

655-DC2	15655	3/4"	3/4"	6/3-4/3 (.85"-1.1") AC/MC
---------	-------	------	------	---------------------------

657-DC2	15657	1"	1"	4/3 to 1/3 (1.03"-1.31") AC/MC
---------	-------	----	----	--------------------------------

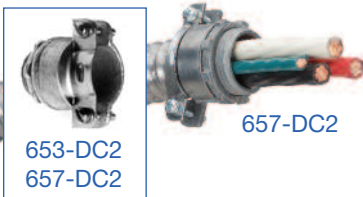
 653-DC2
 657-DC2

657-DC2

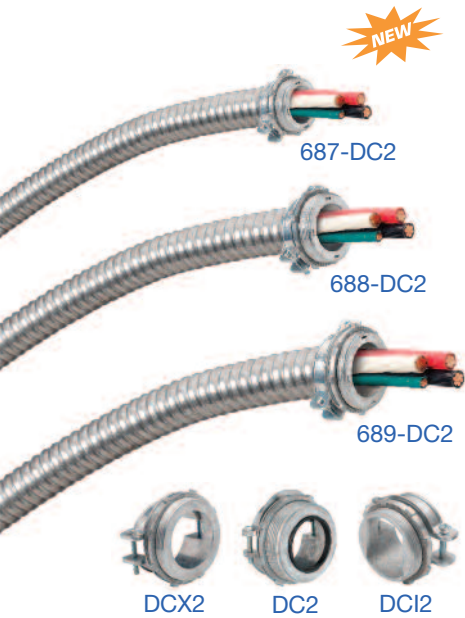

Catalog Number	UPC Number	Trade Size	K.O. Size	Cable
----------------	------------	------------	-----------	-------

DIE CAST LARGE SIZE 2 SCREW, STRAP TYPE CONNECTORS

682-DC2	15682	3/4"	1"	3 #12 to 3 #6 (.525"-.875") AC/MC
683-DC2	15683	1"	1"	3 #4 to 4 #3 (.875"-1.04") MC
683-DCI2	16683	1"	1"	3 #6 to 3 #3 (.75"-1.04") MC
683-DCX2	15683	1"	1"	3 #4 to 4 #3 (.88"-1.04") AC/MC
684-DC2	15684	1 1/4"	1 1/4"	3 #1 to 4 #2 (1.1"-1.25") MC
684-DCX2	15684	1 1/4"	1 1/4"	3 #1 to 4 #2 (1.1"-1.25") AC/MC
685-DC2	15685	1 1/2"	1 1/2"	3 #2/0 to 4 #1/0 (1.25"-1.5") MC
685-DCX2	15685	1 1/2"	1 1/2"	3 #2/0 to 4 #1/0 (1.25"-1.5") AC/MC
686-DC2	15686	2"	2"	3 #350 to 4 #250 (1.75"-2.0") MC
686-DCX2	25686	2"	2"	3 #4/0 to 4 #250 (1.5"-1.85") MC
687-DC2	15687	2 1/2"	2 1/2"	3 #500 to 4 #400 (2.0"-2.5") MC
687-DCX2	15687	2 1/2"	2 1/2"	3 #500 to 4 #400 (2.0"-2.5") AC/MC
688-DC2	15688	3"	3"	3 #600 to 4 #700 (2.375"-3.0") MC
688-DCX2	15688	3"	3"	3 #600 to 4 #700 (2.38"-3.0") AC/MC
689-DC2	15689	3 1/2"	3 1/2"	4 #700 to 4 #750 (2.75"-3.50") MC
689-DCX2	15689	3 1/2"	3 1/2"	4 #700 to 4 #750 (2.75"-3.5") AC/MC

MALLEABLE IRON (REGULAR OPENING) 4 SCREW, STRAP TYPE CONNECTORS



683-XM	00683	1"	1"	3 # 4 to 4 #3 (.81"-1.05") AC/MC
684-XM	00684	1 1/4"	1 1/4"	3 #1 to 4 #2 (1.05"-1.27") AC/MC
685-XM	00685	1 1/2"	1 1/2"	3 #2/0 to 4 #1/0 (1.27"-1.4") AC/MC
686-XM	00686	2"	2"	3-4/0 to 3 #250 (1.4"-1.94") AC/MC
687-XM	00687	2 1/2"	2 1/2"	3 #500 to 4 #400 (1.94"-2.40") AC/MC
688-XM	00688	3"	3"	3 #600 to 4 #700 (2.4"-2.9") AC/MC
689-XM	00689	3 1/2"	3 1/2"	4 #700 to 4 #750 (2.6"-3.2") AC/MC

DIE CAST 90° CONNECTORS




801-DC2	15801	3/8"	1/2"	12/2 to 10/3 (.45"-.625") MC
801-DCI2	16801	3/8"	1/2"	12/2 to 10/3 (.45"-.625") MC
802-MCIA2	75802	3/8"	1/2"	(.42"-.55") MC/MCI-A
802MCIA	71802	3/8"	1/2"	(.42"-.55") MC/MCI-A (Whipper-Snap)
802-DC2	15802	3/8"	1/2"	12/2 to 10/3 (.48"-.58") AC/MC
802-DCI2	16802	3/8"	1/2"	12/2 to 10/3 (.48"-.58") AC/MC
802ASP	08802	3/8"	1/2"	12/2 to 10/3 (.48"-.58") AC/MC (Whipper-Snap)
802SP	70802	3/8"	1/2"	12/2 to 10/3 (.48"-.58") AC/MC (Whipper-Snap)


Catalog Number	UPC Number	Trade Size	K.O. Size	Cable
----------------	------------	------------	-----------	-------

DIE CAST 90° CONNECTORS continued

807-DC2	15807	1"	1"	1.187" to 1.312" MC
808-DC2	15808	1 1/4"	1 1/4"	1.500" to 1.625" MC
807-DCI2	16807	1"	1"	1.187" to 1.312" MC
808-DCI2	16808	1 1/4"	1 1/4"	1.500" to 1.625" MC
804-DC2	15804	1/2"	1/2"	8/4 to 6/3 (.75"-.875") MC
804-DCI2	16804	1/2"	1/2"	8/4 to 6/3 (.75"-.875") MC
806-DC2	15806	3/4"	3/4"	4/2 to 4/3 (.875"-1.0") MC
806-DCI2	16806	3/4"	3/4"	4/2 to 4/3 (.875"-1.0") MC
830-DC2	15830	3/8"	1/2"	14/2 to 10/3 (.44"-.61") AC
850SP	70801	3/8"	1/2"	12/2 to 10/3 (.55"-.61") MC (Whipper-Snap)
851ASP	08851	1/2"	1/2"	1/2" FMC (Whipper-Snap)
851-DC2	15851	1/2"	1/2"	1/2" FMC
851-DCI2	16851	1/2"	1/2"	1/2" FMC
851SP	70851	1/2"	1/2"	1/2" FMC (Whipper-Snap)
84690SP	70830	3/8"		14/2 to 10/3 (.42"-.61") AC/MC/MCI-A

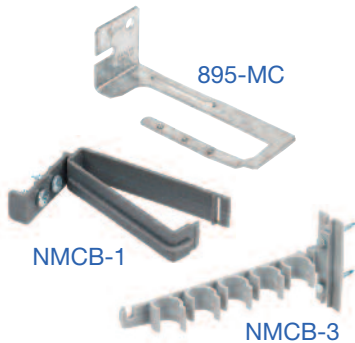
CABLE BRACKETS

895-MC	02895			14/2 to 12/3 (.475"-.59") AC/MC
NMCB-1	40747			14/2, 12/2 NM
NMCB-3	40767			14/2, 10/3 NM


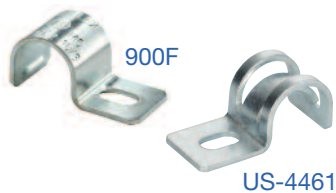

STEEL 1-HOLE STRAPS

890-MC	02890			14/2 to 12/2 (.475"-.525") AC/MC
891-MC	02891			14/3 to 12/3 (.54"-.59") AC/MC
900F	02970			12/4 to 10/3 (.56"-.61") AC/MC
US-4461	02892		3/8"	14/2 to 10/3 MCI-A (.425"-.61") AC/MC

COMBINATION EMT - AC/MC COUPLING

4157-DC	94157			14/2 thru 10/3 to 3/4" EMT (.42"-.61") AC/MC
---------	-------	--	--	--



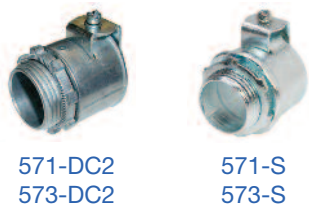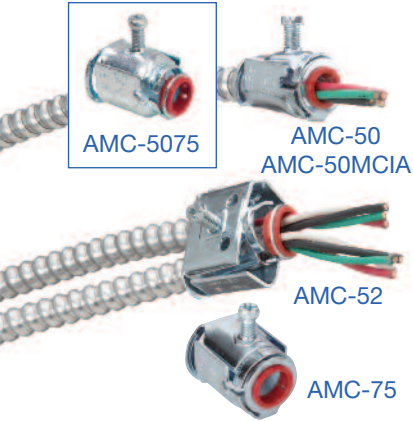

Catalog Number	UPC Number	Trade Size	K.O. Size	Cable
----------------	------------	------------	-----------	-------

STEEL E-Z LOCK SINGLE & DUPLEX CONNECTORS

AMC-50	20570	3/8"	1/2"	14/4 to 10/4 (.40"-.62") AC/MC/MCI-A
AMC-5075	20577	1/2"	1/2"	8/3 to 6/2 (.62"-.92") AC/MC/MCI-A
AMC-52	20580	3/8"	1/2"	14/4 to 10/4 (.43"-.62") AC/MC/MCI-A
AMC-75	20571	3/4"	3/4"	10/3 to 8/4 (.566"-.81") AC/MC/HCF

"U" SHAPED STRAP CONNECTORS

571-DC2	15571	1/2"	1/2"	8/3 to 6/3 (.70"-.855") AC/MC/MCI-A
571-DCI2	16571	1/2"	1/2"	8/3 to 6/2 (.63"-.78") AC/MC/MCI-A
572-DC2	15572	3/4"	3/4"	4/3 to 3/4 (.948"-1.035") AC/MC
573-DC2	15573	1"	1"	2/3 to 2/0-3 (1.18"-1.35") AC/MC
571-S	00571	1/2"	1/2"	8/3 to 6/3 (.701"-.855") AC/MC/MCI-A
571-SI	10571	1/2"	1/2"	8/3 to 6/2 (.63"-.78") AC/MC/MCI-A
572-S	00572	3/4"	3/4"	4/3 to 3/4 (.945"-1.12") AC/MC
573-S	00573	1"	1"	2/3 to 2/0-3 (1.18"-1.35") AC/MC

DIE CAST SNAP-IN CONNECTORS

38ADS Double Snap	08390	3/8"	1/2"	14/2 to 10/3 (.40"-.63") AC/MC/MCI-A/HCF
38ACDS Double Snap for Old Work	08380	3/8"	1/2"	14/2 to 10/3 (.40"-.63") AC/MC/MCI-A/HCF
590-DC2	15590	3/8"	1/2"	14/2 to 10/3 (.43"-.61") AC/MC
590-DCI2	16590	3/8"	1/2"	14/2 to 10/3 (.43"-.61") AC/MC

DIE CAST CONNECTORS FOR PVC & TECK JACKETED MC

595-DC2	15595	3/8"	1/2"	12/3 thru 10/3 PVC Jacketed MC or 14/2, 14/3 or 12/2 TECK Cable with Armor and Jacket (.5"-.61")
595-DCI2	16595	3/8"	1/2"	12/3 thru 10/3 PVC Jacketed MC or 14/2, 14/3 or 12/2 TECK Cable with Armor and Jacket (.5"-.61")
596-DC2	15596	1/2"	1/2"	10/3 thru 8/3 PVC Jacketed MC or 14/2 thru 10/3 TECK Cable with Armor and Jacket (.685"-.80")
596-DCI2	16596	1/2"	1/2"	10/3 thru 8/3 PVC Jacketed MC or 14/2 thru 10/3 TECK Cable with Armor and Jacket (.685"-.80")



USS-6171



830-DC2



601-DC2



3838SP



846SP



3838ASP



SG3838ASP

Catalog Number	UPC Number	Trade Size	K.O. Size	Cable
----------------	------------	------------	-----------	-------

STEEL STRAPS FOR PVC AND TECK JACKETED MC

USS-6171	02893	3/8"	1/2"	(.61"-.71") AC/MC/PVC-MC
----------	-------	------	------	--------------------------

DIE CAST DUPLEX CONNECTORS

601-DC2	15601	3/8"	1/2"	14/2 to 10/4 (.375"-.625") AC/MC/MCI-A
691-DC2	15691	3/8"	1/2"	14/2 to 10/3 (.42"-.61") AC/MC/MCI-A
830-DC2	15830	3/8"	1/2"	14/2 to 10/3 (.44"-.61") AC/MC
846SP	70601	3/8"	1/2"	14/4 to 10/4 (.375"-.625") AC/MC/MCI-A (Whipper-Snap)
3838ASP	08690	3/8"	1/2"	14/4 to 10/4 (.38"-.59") AC/MC/MCI-A (Whipper-Snap)
3838SP	70690	3/8"	1/2"	14/4 to 10/4 (.38"-.59") AC/MC/MCI-A (Whipper-Snap)
SG3838ASP	08691	3/8"	1/2"	14/4 to 10/4 (.42"-.61") AC/MC/MCI-A

Suggested Fittings for Non-PVC Jacketed MC Cable
3 CONDUCTORS WITH GROUND

Size (AWG or kcmil)	Bridgeport Connector
6-6-6-6	653-DC2
4-4-4-6	683-DC2
2-2-2-4	683-DC2
1-1-1-4	684-DC2
1/0-1/0-1/0-4	684-DC2
2/0-2/0-2/0-4	685-DC2
3/0-3/0-3/0-4	685-DC2
4/0-4/0-4/0-2	686-DCX2
250-250-250-2	686-DCX2
300-300-300-1	686-DC2
350-350-350-1	686-DC2
400-400-400-1	687-DC2
500-500-500-1	687-DC2
500-500-500-2/0	687-DC2
500-500-500-250	688-DC2
600-600-600-1/0	687-DC2
750-750-750-1/0	688-DC2
750-750-750-3/0	688-DC2

4 CONDUCTORS WITH GROUND

Size (AWG or kcmil)	Bridgeport Connector
6-6-6-6-6	653-DC2
4-4-4-4-6	683-DC2
2-2-2-2-4	657-DC2
1-1-1-1-4	684-DC2
1/0-1/0-1/0-1/0-4	685-DC2
2/0-2/0-2/0-2/0-4	685-DC2
3/0-3/0-3/0-3/0-4	686-DCX2
4/0-4/0-4/0-4/0-2	686-DCX2
250-250-250-250-1	686-DC2
300-300-300-300-1	687-DC2
350-350-350-350-1/0	687-DC2
400-400-400-400-3/0	687-DC2
500-500-500-500-3/0	687-DC2
500-500-500-500-250	687-DC2
600-600-600-600-3/0	688-DC2
600-600-600-600-400	688-DC2
750-750-750-750-3/0	688-DC2
750-750-750-750-500	689-DC2
900-900-900-900-250	689-DC2

Bridgeport MCI-A Cable Fittings

Cable Fitting	Enclosure Opening KO Size	Cable Outer Diameter (O.D.) Range	Cable Types Listed To:	Healthcare Facility Cable	Flexible Metal Conduit	Recommended Cable Types
			Note: Includes Steel and Aluminum		Note: Includes Steel and Aluminum (RWFMC)	Note: Verify with cable O.D. Includes Steel and Aluminum
38ADS	1/2"	.40-.63	AC/MC/MCI-A	HCF	3/8" FMC/RWFMC	14/2 - 10/3
38ACDS	1/2"	.40-.63	AC/MC/MCI-A	HCF	3/8" FMC/RWFMC	14/2 - 10/3
3838ASP	1/2"	.38-.59	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/2
3838SP	1/2"	.38-.59	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/2
403-DC2	1/2"	.56-.61	AC/MC	HCF	3/8" FMC	12/3 to 10/3
407-DC2	1/2"	.86-.92	AC	HCF		
407-DCI2	1/2"	.86-.92	AC	HCF		
501-DC2	1/2"	.43-.61	MC ONLY			14/2 - 10/3
545-DC2	1/2"	.44-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 - 10/3
560ASP	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
560-DC2	1/2"	.44-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	12/2 to 10/4
560-DCI2	1/2"	.44-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	12/2 to 10/4
560MCIA	1/2"	.38-.55	MC/MCI-A	HCFMCI-A		14/2 - 10/3
560-MCIA2	1/2"	.38-.61	MC/MCI-A	HCFMCI-A		14/2 to 10/3
560SP	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
561-DC2	3/4"	.61-.87	AC/MC	HCF		10/4 to 8/3
561-DCI2	3/4"	.61-.87	AC/MC	HCF		10/4 to 8/3
563-DC2	1/4"		AC/MC	HCF		14/2 to 12/2
565-DC2	1/2"	.38-.53	MC/MCI-A	HCFMCI-A		14/2 to 10/3
566-DC2	1/2"	.44-.53	AC/MC/MCI-A	HCF/HCFMCI-A		12/2 to 10/3
570-DC2	1/2"	.38-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 to 10/3
570-DCI2	1/2"	.38-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 to 10/3
570-DCR2	1/2"	.38-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 to 10/3
570-GI	1/2"	.38-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 to 10/3
570-RI	1/2"	.38-.61	AC/MC/MCI-A	HCF/HCFMCI-A		18/2 - 12/4
571-DC2	1/2"	.70-.855	AC/MC/MCI-A	HCF/HCFMCI-A	1/2" FMC	8/3 - 6/3
571-DCI2	1/2"	.70-.855	AC/MC/MCI-A	HCF/HCFMCI-A	1/2" FMC	8/3 - 6/3
571-S	1/2"	.701-.855	MC/MCI-A	HCFMCI-A	1/2" FMC	8/3 - 6/3
571-SI	1/2"	.701-.855	MC/MCI-A	HCFMCI-A	1/2" FMC	8/3 - 6/3
572-DC2	3/4"	.945-1.035	MC		3/4" FMC	4/3 - 3/4
572-DCI2	3/4"	.945-1.035	MC		3/4" FMC	4/3 - 3/4
572-S	3/4"	0.945	MC		3/4" FMC	4/3
572-SI	3/4"	0.945	MC		3/4" FMC	4/3
573-DC2	1"	1.18-1.35	MC		1" FMC	2/3 - 3 2/0
573-DCI2	1"	1.18-1.35	MC		1" FMC	2/3 - 3 2/0
573-S	1"	1.18-1.35	MC		1" FMC	2/3 - 3 2/0
573-SI	1"	1.18-1.35	MC		1" FMC	2/3 - 3 2/0
590-DC2	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
590-DCI2	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
595-DC2	1/2"	.50-.61	JMC/ TECK90			12/2 - 10/3
595-DC2C	1/2"	.50-.61	JMC/ TECK90			12/2 - 10/3
595-DCI2	1/2"	.50-.61	JMC/ TECK90			12/2 - 10/
596-DC2	1/2"	.61-.69	JMC/ TECK90			10/4 to 8/3
596-DC2C	1/2"	.61-.69	JMC/ TECK90			10/4 to 8/3
596-DCI2	1/2"	.61-.69	JMC/ TECK90			10/4 to 8/3
601-DC2	1/2"	.375-.625	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
653-DC2	1/2"	.675-.90	AC	HCF	1/2" FMC	8/2 - 6/4
655-DC2	3/4"	.85-1.10	AC/MC	HCF	3/4" FMC	6/3 - 4/3
657-DC2	1"	1.03-1.31	AC/MC	HCF	1" FMC	4/3 - 1/3
682-DC2	3/4"	.575-.875	AC/MC	HCF		10/3 to 6/4
683-DC2	1"	.875-1.04	MC			6/4 to 4/3
684-DC2	1-1/4"	1.1-1.25	MC			4/4 to 3/4
685-DC2	1-1/2"	1.25-1.5	MC			2/4 to 3-2/0
686-DC2	2"	1.75-2.00	MC			4-4/0 to 4-250 MCM
687-DC2	2-1/2"	2-2.5	MC			4-300 MCM to 4-500 MCM
688-DC2	3"	2.375-3	MC			4-500 MCM to 4-750 MCM
689-DC2	3-1/2"	2.75-3.50	MC			4-600 MCM to 4-750 MCM
683-DCI2	1"	.750-1.04	MC			6/4 to 4/3
684-DCI2	1-1/4"	1.1-1.25	MC			4/4 to 3/4
685-DCI2	1-1/2"	1.25-1.5	MC			2/4 to 3-2/0
686-DCI2	2"	1.75-2.00	MC			4-4/0 to 4-250 MCM
687-DCI2	2-1/2"	2-2.5	MC			4-300 MCM to 4-500 MCM

Bridgeport MCI-A Cable Fittings

Cable Fitting	Enclosure Opening KO Size	Cable Outer Diameter (O.D.) Range	Cable Types Listed To: Note: Includes Steel and Aluminum	Healthcare Facility Cable	Flexible Metal Conduit Note: Includes Steel and Aluminum (RWFMC)	Recommended Cable Types Note: Verify with cable O.D. Includes Steel and Aluminum
688-DCI2	3"	2.375-3	MC			4-500 MCM to 4-750 MCM
689-DCI2	3-1/2"	2.75-3.50	MC			4-600 MCM to 4-750 MCM
683-DCX2	1"	.875-1.04	MC			6/4 to 4/3
684-DCX2	1-1/4"	1.1-1.25	MC			4/4 to 3/4
685-DCX2	1-1/2"	1.25-1.5	MC			2/4 to 3-2/0
686-DCX2	2"	1.5-1.85	MC			3-4/0 to 4-250 MCM
687-DCX2	2-1/2"	2-2.5	MC			4-300 MCM to 4-500 MCM
688-DCX2	3"	2.375-3	MC			4-500 MCM to 4-750 MCM
689-DCX2	3-1/2"	2.75-3.50	MC			4-600 MCM to 4-750 MCM
683-XM	1"	0.81-1.05	AC/MC	HCF		6/4 to 4/3
684-XM	1-1/4"	1.05-1.27	AC/MC	HCF		4/4 to 3/4
685-XM	1-1/2"	1.27-1.4	AC/MC	HCF		4-2/0 to 3-350 MCM
686-XM	2"	1.4-1.94	AC/MC	HCF		3-4/0 to 4-250 MCM
687-XM	2-1/2"	1.94-2.4	MC			4-300 MCM to 4-500 MCM
688-XM	3"	2.4-2.9	MC			4-500 MCM to 4-750 MCM
689-XM	3-1/2"	2.6-3.2	MC			4-600 MCM to 4-750 MCM
691-DC2	1/2"	.42-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
801-DC2	1/2"	.45-.625	MC/MCI-A	HCFMCI-A	3/8" FMC	14/4 - 10/4
802ASP	1/2"	.48-.58	AC/MC	HCF	3/8" FMC	12/2 to 10/3
802-DC2	1/2"	.48-.58	AC/MC	HCF	3/8" FMC	12/2 to 10/3
802-DCI2	1/2"	.48-.58	AC/MC	HCF	3/8" FMC	12/2 to 10/3
802SP	1/2"	.48-.58	AC/MC	HCF	3/8" FMC	12/2 to 10/3
802MCIA	1/2"	.42-.55	MC/MCI-A	HCFMCI-A		14/4 to 10/3
802-MCIA2	1/2"	.42-.55	MC/MCI-A	HCFMCI-A		14/4 to 10/3
804-DC2	1/2"	.75-.875	MC		1/2" FMC	
804-DCI2	1/2"	.75-.875	MC		1/2" FMC	
806-DC2	3/4"	.875-1.00	MC		3/4" FMC	
806-DCI2	3/4"	.875-1.00	MC		3/4" FMC	
807-DC2	1"	1.187-1.312	MC		1" FMC	
807-DCI2	1"	1.187-1.312	MC		1" FMC	
808-DC2	1-1/4"	1.50-1.625	MC		1-1/4" FMC	
808-DCI2	1-1/4"	1.50-1.625	MC		1-1/4" FMC	
830-DC2	1/2"	.44-.61	AC	HCF	3/8" FMC	12/2 - 10/3
8400ASP	1/2"	.38-.525	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 - 12/3
8400SP	1/2"	.38-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 - 10/3
840SP	1/2"	.44-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/4 - 10/3
845ASP	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 - 10/3
845SP	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A		14/2 - 10/3
84690SP	1/2"	.42-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/4 - 10/3
846SP	1/2"	.38-.625	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/4
850SP	1/2"	.55-.61	AC/MC	HCF	3/8" FMC	12/2 - 10/3
851ASP	1/2"				1/2" FMC	
851-DC2	1/2"				1/2" FMC	
851-DCI2	1/2"				1/2" FMC	
851SP	1/2"				1/2" FMC	
895-DC2	1/2"	.50-.61	JMC/ TECK90			12/2 - 10/3
895-DCI2	1/2"	.50-.61	JMC/ TECK90			12/2 - 10/3
AMC-50	1/2"	.40-.62	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 to 10/3
AMC-5075	1/2"	.62-.92	AC/MC/MCI-A	HCF/HCFMCI-A	1/2" FMC	10/4 to 6/4
AMC-52	1/2"	.43-.62	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 to 10/3
AMC-75	3/4"	.56-.81	AC/MC	HCF	1/2" FMC	10/3 - 6/3
BL-17	1/2"	.701-803	8/3 AC90	HCF	1/2" FMC	8/3 - 6/3
BL-17I	1/2"	.701-803	8/3 AC90	HCF	1/2" FMC	8/3 - 6/3
BL-18	3/4"		6/3 AC90 ONLY		3/4" FMC	6/3
BL-18I	3/4"		6/3 AC90 ONLY		3/4" FMC	6/3
BL-19	1"		3/3 AC90		1" FMC	3/3
BL-19I	1"		3/3 AC90		1" FMC	3/3
SG3838ASP	1/2"	.42-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/2 - 10/3
SG38ASP	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/4 - 10/3
SG38SP	1/2"	.43-.61	AC/MC/MCI-A	HCF/HCFMCI-A	3/8" FMC	14/4 - 10/3
SG38MCIA	1/2"	.38-.56	MC/MCI-A	HCFMCI-A		14/2 - 10/3



 
BUY AMERICAN. BUY BRIDGEPORT.

Stimulus from Bridgeport.

When you think American, think Bridgeport. We're investing in our U.S.-based manufacturing operation in Stratford, Connecticut. We're investing in equipment, improving process automation and developing new products – all in the U.S. And still today, nearly three-quarters of our product volume is manufactured in the U.S. Find the American-made products for your projects at: www.bptfittings.com/american



Distributed by:



Bridgeport Fittings, Inc.
705 Lordship Blvd.
Stratford, CT 06615-7313

Voice: 203.377.5944
Fax: 203.381.3488
E-mail: sales@bptfittings.com

www.bptfittings.com



Printed in the U.S.A.
© 2013 Bridgeport Fittings, Inc. All rights reserved.
WHIPPER-SNAP and 38 Special are trademarks of Bridgeport Fittings, Inc.



03/13 5000 BP070