


Catalogue Number	Alternate Cat. No.	Size or Description	Packaging		List Price
			Case	Box	

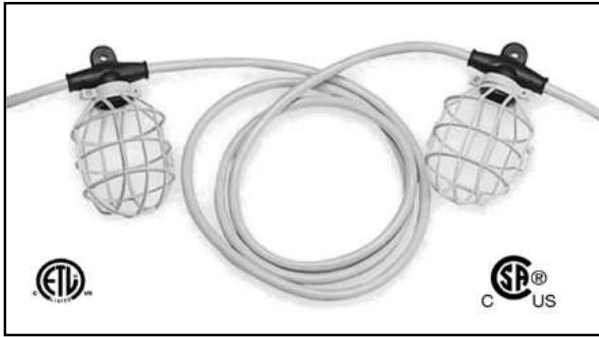

**NESCO - Industrial Grade Temporary Lighting**  
 ★ Available in 12/2 (SL2-100) or 12/3 (SL3-100) STW cable with 10 cages at 10' intervals.  
 ★ Hanging holes on each socket allow installation with either spikes or S-holes

**Industrial Grade Stringlights**

						List/Each
<b>SL2-100</b>		12/2 STW 100', 10 plastic cages, high visibility yellow		1	\$	231.00
<b>SL3-100</b>		12/3 STW, 100', 10 plastic cages, high visibility yellow		1	\$	315.00
<b>SL3M-100</b>		METAL CAGES - 12/3 STW, 100', 10 metal cages, high visibility yellow		1	\$	368.00
<b>SL-CAGE</b>		Replacement Cage - plastic		1	\$	5.00

**Lamp Holder - Plastic**



<b>KLH-1</b>	Medium Base 2-piece design Individually bagged	-	50	\$	305.00
--------------	--	---	----	----	--------

**Lamp Holder - Plastic with Pull Chain**



<b>KLH-2</b>	Medium Base 2-piece design Individually bagged	-	50	\$	420.00
--------------	--	---	----	----	--------

**Lamp Holder - Porcelain**



<b>KPLH-1</b>	Medium Base Individually boxed, master case of 50 pieces	-	50	\$	630.00
---------------	---	---	----	----	--------

**Rubber Pigtail Light bulb Socket**



<b>PT-123</b>	cULus Listed	-	100	\$	315.00
<b>PT-123B</b>	cULus Listed	-	250	\$	315.00

**Swivel Fixture Aligner**



<b>BA-07R</b>	4" Round 50 lbs. Load Rating Allows 20° Swing from Vertical	3/4" cw RB0705	-	10	\$	1,422.00
---------------	---	----------------	---	----	----	----------



<b>BA-07</b>	4" SQUARE 50 lbs. Load Rating Allows 20° Swing from Vertical	3/4" cw RB0705	-	10	\$	1,422.00
--------------	--	----------------	---	----	----	----------

**"KWICK-HANG"**

<b>SC-5075HF</b>	4" Square	1/2" or 3/4"	-	25	\$	1,785.00
<b>SC-5075HFR</b>	4" Round 50 lbs. Load Rating Allows 20° Swing from Vertical	1/2" or 3/4"	-	25	\$	1,635.00