


GENERAL PURPOSE SNAP ACTION

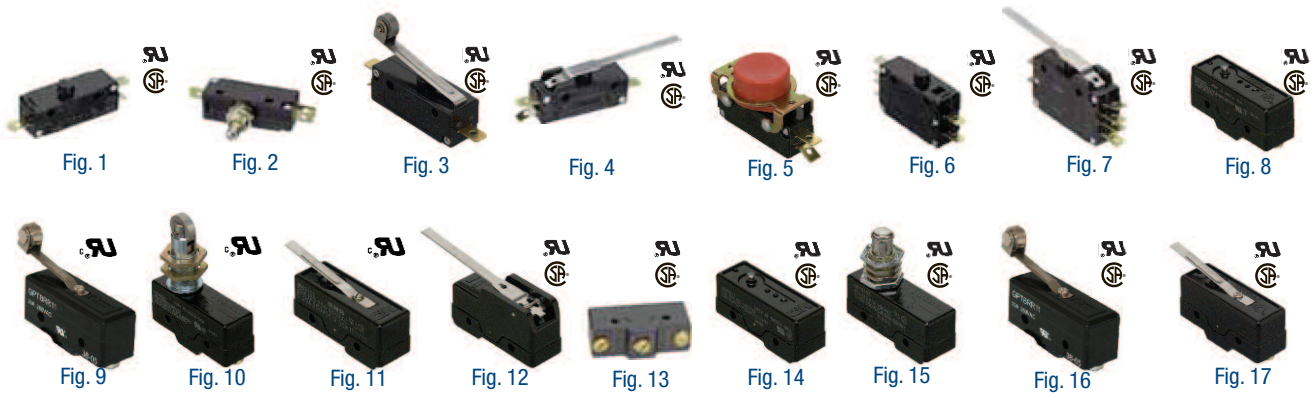

Retail Part No.	Bulk Part No.	Figure No.	Amps **VAC	Amps 125 VDC	Amps 250 VDC	HP 125 VAC	HP 250 VAC	PT Max. (In)	OT Min. (In)	DT Max. (In)	OF Max. Oz. (grams)	Actuator	Actuator Length (In)	Terminal Type	Spec. Drawing Page No.
35-461	35-461-BU	1	15								20 (567)	PI		QC .250"	I-33 A
35-462	35-462-BU	2	15					3/4	1-1/2	0.050	0.050	0.010		QC .250"	I-33 B
35-463	35-463-BU	3	15					3/4	1-1/2	0.281	0.062	0.094	1.50	QC .250"	I-33 C
35-464	35-464-BU	4	15					3/4	1-1/2	0.312	0.187	0.062	2.50	QC .250"	I-33 D
35-830	35-830-BU	5	15					3/4	1-1/2	0.050	0.050	0.010		QC .250"	I-33 E
35-831	35-831-BU	5	15					3/4	1-1/2	0.050	0.050	0.010		QC .250"	I-33 E
35-990	35-990-BU	*6	15					3/4	1-1/2	0.050	0.050	0.010		QC .250"	I-33 F
35-992	35-992-BU	*7	15					3/4	1-1/2	0.312	0.187	0.062	2.50	QC .250"	I-33 F
35-3900	35-3900-BU	8	15					1/8	1/4	0.016	0.005	0.002		Sc	I-33 G
35-3901	35-3901-BU	8	15	1/2	1/4			0.016	0.005	0.002	12.3 (350)			Sc	I-33 G
35-3907	35-3907-BU	9	15					0.158	0.063	0.002	5.3 (151)	LRO	1.783	Sc	I-33 O
35-3910	35-3910-BU	10	20	1/2	1/4	1	2	0.028	0.140	0.008	22.9 (650)	RP		Sc	I-33 I
35-3911	35-3911-BU	10	15					0.016	0.140	0.002	12.3 (349)	RP		Sc	I-33 I
35-828	35-828-BU	11	20	1/2	1/4	1	2	0.156	0.062	0.050	5-13 (142-370)	LL	1.95	Sc	I-33 H
35-829	35-829-BU	11	15	1/2	1/4	1	2	0.156	0.062	0.050	5-13 (142-370)	LL	1.97	Sd	I-33 H
35-890	35-890-BU	12	20	1/2	1/4			0.380	0.190	0.156	3.5-26 (100-740)	Lever	2.50	Sc	I-33 J
35-892	35-892-BU	13	20	1/2	1/4	1	2	0.020	0.055	0.002	12.3 (350)	SP		Sd/Sc	I-33 K&L
35-894	35-894-BU	14	20	1/2	1/4	1	2	0.020	0.005	0.002	12.3 (350)	PP		Sd/Sc	I-33 L
35-896	35-896-BU	15	20	1/2	1/4	1	2	0.020	0.063	0.002	12.3 (350)	PI w/OT		Sd/Sc	I-33 M
35-980	35-980-BU	14	20	1/2	1/4			0.030	0.005	0.005	26 (740)	PP		Sd/Sc	I-33 L
35-982	35-982-BU	15	20	1/2	1/4			0.030	0.220	0.005	26 (740)	PI		Sd/Sc	I-33 M
35-984	35-984-BU	12	20	1/2	1/4			0.380	0.190	0.047	2.5-9 (60-255)	Lever	2.50	Sd/Sc	I-33 J
35-987	35-987-BU	16	20	1/2	1/4	1/2	1	0.468	0.062	0.085	3.5 (100)	Ro	1.91	Sc	I-33 N
35-3903	35-3903-BU	13	20	1/2	1/4	3/4	1 1/2	0.020	0.055	0.002	12.3 (350)	SP		Sc	I-33 K
35-3904	35-3904-BU	17	20	1/2	1/4	1/2	1	0.158	0.062	0.050	5.3 (150)	LL	1.95	Sc	I-33 H
35-3906	35-3906-BU	16	20	1/2	1/4	1	2	0.156	0.062	0.050	5-13 (142-370)	LRO	1.78	Sc	I-33 O

Notes: All of the above have momentary action

*DPDT

**125/250VAC

All have SPDT, but 35-990 & 35-992

DT = Differential Travel

HP = Horse Power

HRO = Hinged Roller

LRO = Leaf Rollers

LL = Leaf Lever

OF = Operating Force

OT = Over Travel

Pb = Pushbuttons

PI = Plunger

PT = Pre-Travel

QC = Quick Connect

RP = Roller Plunger

Sc = Screw

Sd = Solder

ShRo = Short Roller

SP = Stub Plunger

PP = Pin Plunger

Ro = Roller

Note: All figures are for illustration purpose only, and the number/type of terminals may vary.

All quantities are single; BU's are packages of 25 Unless otherwise noted.

