

CALRAD

30 Series - Connectors

Technical drawings and specifications are available for these connectors. Please ask your Calrad sales representative for details.



30-412A
Closed Circuit 1/4"
Mono Audio Jack.
.35" x .29" bushing.
.36" hole size, will
work with standard
.375" hole.




30-395
Open Circuit.
30-396
1/4" Audio Jack.
Closed Circuit
2-Conductor.
3/8" bushing.
Mounts in .355" hole.



30-397
1/4" Audio Jack.
Open Circuit
3-Conductor.
3/8" bushing.
Mounts in
.355" hole.



30-398
1/4" Audio Jack.
3-Circuit,
2 Closed.
3/8" bushing.
Mounts in
.355" hole.

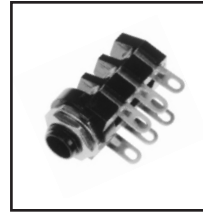

30-399
1/4" Audio Jack.
3-Circuit,
3 Closed.
3/8" bushing.
Mounts in
.355" hole.



30-385
Stereo 1/4" Audio
Jack. with DPDT
normally closed and
normally open
circuits.



30-337
Coax AC/DC power
plug 2.35mm O.D.,
.7mm I.D.
.17" cable opening
with strain relief.



30-336
Coaxial AC/DC
power plug.
1.0mm I.D.
3.8mm O.D.
.17" cable opening.



30-372
Coax power plug.
1.3mm I.D.
3.5mm O.D.
9.5mm long.
.15" cable opening.
30-372-P
With strain relief.
.16" cable opening.



30-635
Coax AC/DC power
plug 4.75mm O.D.,
1.7mm I.D., 9.2mm
long, .17" cable
opening.
30-632
same as 30-635
with O.D. of 4mm.



30-373
Bakelite Barrel
30-373-P
With Strain Relief.
Coax power plug. 2.1
mm I.D. 5.5 mm O.D.
9.5 mm long.
.15" cable opening.



30-373-14MM
2.1mm Version
30-374-14MM
2.5mm Version 14mm
connector shaft,
plastic body with
strain relief, .15" cable
opening.



30-333 2.1mm
30-334 2.5mm
coax inline Female
connector. Available in
2.1mm and 2.5mm
versions
O.D. = 5.5mm
.15" cable opening.



30-374
Bakelite Barrel
30-374-P
With Strain Relief.
Coax power plug.
2.5mm I.D. 5.5mm
O.D. 9.5 mm long.
.15" cable opening.



30-617-2.1
30-617-2.5
Locking DC power
coax plug 5.5 O.D.,
9.5mm long. Insert into
30-616 jack and twist
clockwise to lock.
.14" cable opening.



30-623-2.1
30-623-2.5
Locking DC power
coax plug. Mates with
30-624 jack.
Threaded locking
style. Available in
2.1mm or 2.5mm I.D.
.18" cable opening.



30-375
DC coax power plug.
3mm I.D.,
6.3mm O.D.,
9.5mm long.
With strain relief. .20"
cable opening.



30-720-2.1
2.1mm version
30-720-2.5
2.5mm version
Chassis mount snap-in
coax power jack. Nickel
plated connector with
black molded trim.
Mounts in .375" hole, up
to .07" panel thickness



30-624-2.1
30-624-2.5
Chassis mount
locking DC power
coax jack. Mates
with **30-623** plug.
Mounts in panels
up to .07".



30-616-2.1
30-616-2.5
Locking DC power coax
jack with N/C switch on
sleeve side of the
connector. Insert
30-617 plug and twist
clockwise to lock.



30-371
Coax power jack,
standard chassis
mount, 2.1mm pin.
Switched circuit.
17mm mount
center.



30-370-2.1
2.1 mm pin,
30-370-2.5
2.5 mm pin,
PC mount coax
power jack,
switched circuit.



30-314
2.1mm I.D. X 5.5mm O.D.
30-315
2.5mm I.D. X 5.5mm O.D.
Chassis mount coax
power jack. Plastic
housing. Mounts in 1/2"
dia. hole. N/C switch.



30-730
2.1mm solderless
inline DC Coax
power plug.
30-731
2.1mm solderless
inline DC Coax
power jack.