



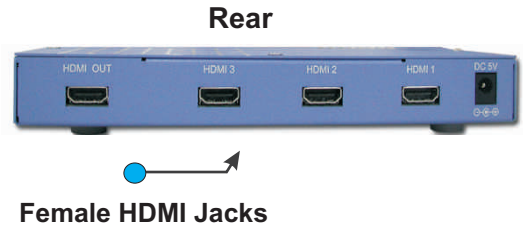

819 N. Highland Ave.
Los Angeles, CA 90038

Tel: (323) 465-2131, Fax: (323) 465-3504
Visit us on the web at www.calrad.com

Part No: 40-992 IR Controlled HDMI 3 Input Digital Switcher

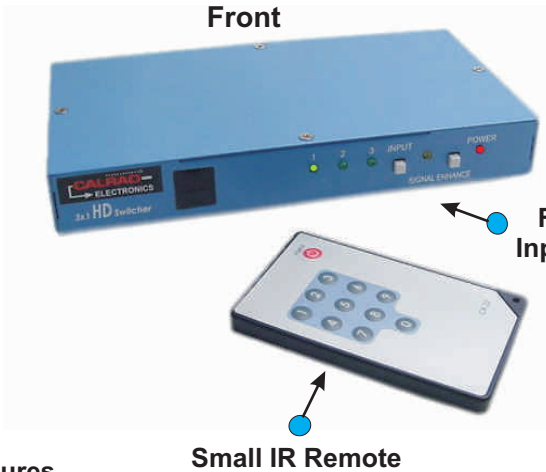

Features

- HDCP 1.1 Compliant switcher, 3 Inputs to 1 Output (Manual or IR control)
- Small Compact metal case, plug and play installation
- L.E.D signal selection indicators for inputs, Enhance, Power
- IR Remote Selects power (On\Off) and discrete 1-3 inputs
- Supports HDTV 480P, 720P, 1080I, 1080P, 7.1 Digital Audio, CEC codes
- Switch DVI-D digital signals only, using Calrad 35 series adapters
- Selectable Signal Enhancement circuitry for long distance transmission

35 Series HDMI \ DVI Adapters




Calrad 35-711
HDMI Female
to DVI-D Male
Adapter



Calrad 35-712
HDMI Male to
DVI-D Female
Adapter

Typical Hookup

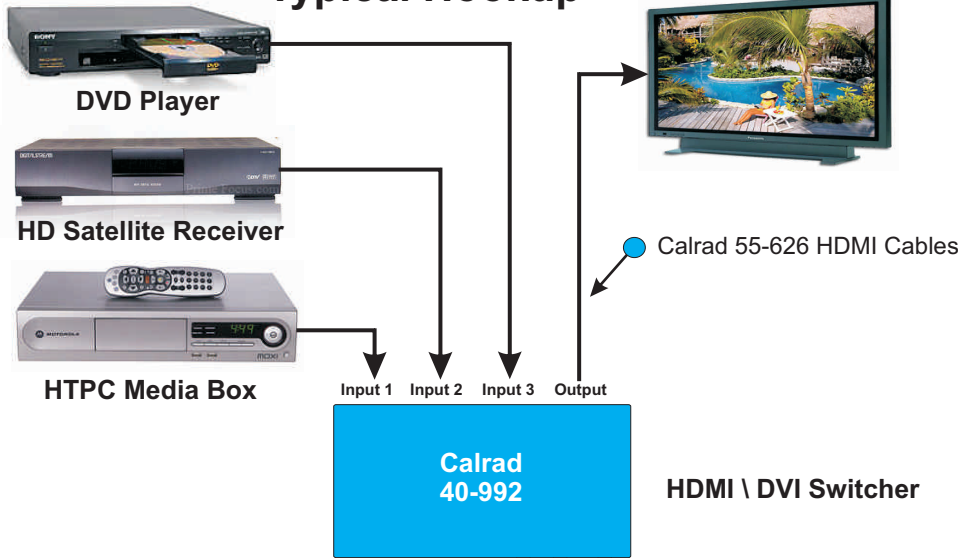

Calrad 35-716
6" adapter cable DVI-D
Female to HDMI Male
Adapter



Calrad 35-715
6" adapter cable DVI-D
Male to HDMI Female
Adapter

Specifications:

IR Distance 30-35 ft.
Frequency Bandwidth: 1.65 Gbps
Supporting Graphic Resolutions: Supports HDTV resolution of 480p, 720p, 1080i and 1080p & Supports VGA, SVGA, SXGA(1280x1024), UXGA(1600x1200)
Connectors: Female 19 pin HDMI Gold plated jacks x 4
Power requirements DC Power 5V, 1.5A, Remote 3V lithium button cell
Size: Length: 8.0", Width: 4.1", Height: .99"
Weight: (1.25 lbs)

All specifications subject to change without notice, Calrad 2005