



92-341
Lighting
Control Module,
Remote




92-354
RGB Power
Amplifier
72 Watts



92-340
Manual RGB
Controller



92-348
RGB Controller
with Remote
144 Watts

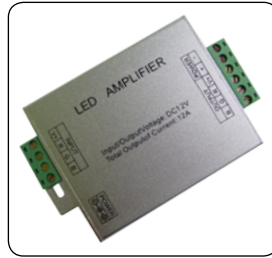

92-353
RGB Power
Amplifier
144 Watts



92-336
PIR Motion
Sensor Switch
8 Amp



92-337
PIR Motion
Sensor 5 Amp



92-343
ON/OFF Compact
Power Supply
In Line Switch



92-344
ON/OFF Compact
Power Supply
1 by 2 InLine
Switch



45-608
12VDC, 5 AMP L.E.D.
LIGHTING POWER SUPPLY

Calrad's new high efficiency switchmode power supply is specifically designed for White or colored (RGB) L.E.D. lighting applications. Using Calrad's 30-333T adapter you can easily connect wiring to (+), (-) screw terminals without the need for soldering or splicing cables together.

SPECIFICATIONS:

- Operates on 110-220 Vac
- Soft-start current can reduce the AC input impact to 12Vdc loads
- CE, FCC approved, RoHS Compliant
- Over voltage protection: 120%min
- Over Current protection: 120%min
- Short-circuit protection: Automatic recovery
- Load regulation: ±5% • Input Voltage: 110-220Vac
- Output Voltage: 12Vdc
- Output Current: 5Amps (White Color)/ 6Amps (Black Color)
- Output Termination: 2.1mm Male Coax Plug, positive center, 6 ft. cord.
- Size: L-4.6" x W-2.35" x H-1.5"



45-608-HG
12VDC, 6 AMP L.E.D.
LIGHTING POWER SUPPLY



45-609-HG
12VDC, 29 AMP L.E.D.
LIGHTING POWER SUPPLY



30-333T
SOLDERLESS COAX
POWER CONNECTORS
DC 2.1mm female jack to 2 pin
screw terminal block adapter.
Excepts up to 18 Awg wire.



30-373T
SOLDERLESS COAX
POWER CONNECTORS
DC 2.1mm male plug to 2 pin
screw terminal block adapter.
Excepts up to 18 Awg wire.