

# CALRAD

## 90 & 92 Series - L.E.D. Lighting

### 90-701-XLR-RA PRO-AUDIO LAMP WITH 8 L.E.D LIGHTS

Perfect for mixing consoles or desk top, public address usage. Terminates to a male XLR connector. Over 50 year Avg. L.E.D lamp life. Material color: Black.

#### Specifications:

Power 8 L.E.D lamps operates on 12Vdc.  
Current consumption .....250mA.  
Gooseneck length.....12"  
Wiring XLR Pin 1=ground, Pin 2=12Vdc  
Material color .....Black



### 90-702 CIGARETTE LIGHTER LAMP WITH 8 L.E.D. LIGHTS

For use in Car's or truck's. Provides a bright pure white light for reading. Never gets hot, easy to handle and operate. Terminates to a male cigarette lighter connector with ON/OFF switch. Over 50 year Avg. L.E.D lamp life.Fuse protected.

#### Specifications:


Power 8 L.E.D lamps operates on 12Vdc.  
Current consumption .....250mA.  
Gooseneck length.....12"  
Material color .....Black



### 2-WIRE / 4 WIRE 12VDC L.E.D. STRIP LIGHTING

**92-300** White 2-Wire LED Strip Lighting. 16 ft. rolls.

**92-301** RGB 4-Wire LED Strip Lighting. 16 ft rolls.

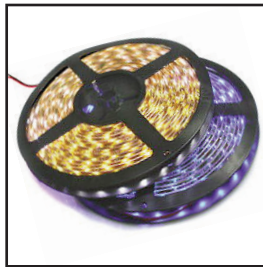

### Mini LED Flashlights

- 92-203-BK**.....Black
- 92-203-BU**.....Blue
- 92-203-GY**.....Grey
- 92-203-RD**.....Red
- 92-203-WH**.....White



Calrads new line of L.E.D. waterproof strip lighting provides the unique ability to select each independant color of Red, Green or Blue or combinations to create(256 shade levels each color, 16 million shades) of lighting in a small thin form factor. The flexible silicon PCB can be bent to a maximum radius of 2cm. 50 L.E.D's per meter 4 watts per meter. Cut between every 3 LEDs to create the size length for your application. Creates stunning visual effects, Little or no heat, Solid-state, high shock / vibration resistant, very bright & low power consumption. 16 ft. String requires a 12Vdc, 1.5 amp power supply.

### 92-200 6" AVIATOR COMPACT FLASHLIGHT

Shock proof construction, heavy duty machined Aircraft Aluminium with high quality black anodized finish.

Fully adjustable focus head. All weather housing with sealed O-ring lamp and battery housing. One-handed tail rubber push button switch.


Shatter proof lense, includes spare bulb, belt style carrying case with velcro flap and 2 x AA Batteries.




See page 103 for 12Vdc power supplies



92-340

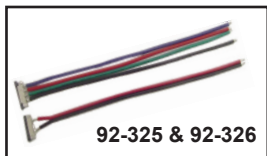

92-325 & 92-326

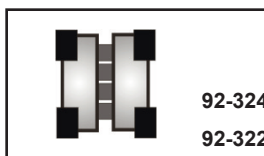

92-324  
92-322

### 92-201 COMPACT AVIATOR FLASHLIGHT ON A 18" FLEXIBLE GOOSENECK



92-201

### 90-1000 PERSONAL L.E.D SAFETY LIGHT

With the mini-flash unit on at night, you will stay visible to motorists while walking or jogging on the road. Clip the mini -flash either on your hat or clothes.

Momentary push on/off power switch. Bright flashing red L.E.D. . Easy to replace 3V lithium battery CR2032.



### 90-1000-BAT

3V lithium replacement battery CR2302.

### 2-WIRE LED STRIP LIGHTING

**92-325** LED Strip Lighting Clips With 6" Leads

**92-326** LED Strip Lighting Clips With 6" Leads

**92-340** RGB Manual Control Module

**92-341** RGB Control Module and IR Remote

**92-322** 2 Wire LED Strip Lighting Coupler

**92-324** 4 Wire LED Strip Lighting Coupler