 


Switch Boxes



SSV




SSQV


With nonmetallic sheathed cable clamps



SWB
Ears flush for old work

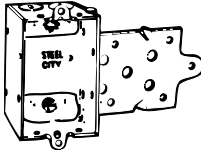

811-SW
"S" bracket recessed 3/8"

 


LXMWOW
Ears flush for old work




LXMOV
Ears flush for old work




LCOW-25
Ears flush old work

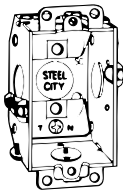


LCOWC
Adapts to any wall thickness up to 3/4"

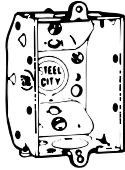


LCLE

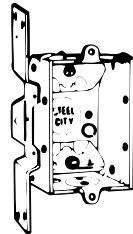


LCV
"CV" bracket recessed 3/4"

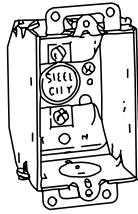


LCNOW
Ears flush old work

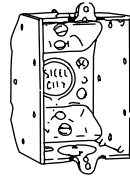


A-1-2

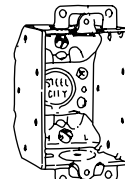

A-1-2E
Ears flush

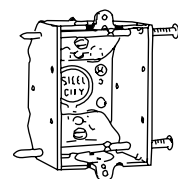

A-16
With nails

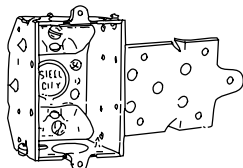

802-S
"S" bracket recessed 3/8"

3 3/4" x 2" Switch Boxes

Cat. No.	Clamps	Ears	Brkts.	Knockouts	Std. Ctn.
1" deep non-gangable-6.5 cubic inch capacity					
SSV	-	-	Flat	2 Pry-outs one end	25
SSQV	Yes	-	Flat	2 Pry-outs one end with nonmetallic cable clamps	25

Not U.L. Listed

3" x 2" Switch Boxes

Cat. No.	Clamps	Ears	Brkts.	Knockouts			Std. Ctn.
				Ea. End Conduit	Ea. End Cable	Bottom Conduit	
1 1/2" deep non-gangable-with nonmetallic sheathed cable clamps-7.5 cubic inch capacity							
SWB-25	C-5	Yes	-	-	2	2	25
811-SW	C-5	-	S	-	2	2	50

2" deep gangable-with nonmetallic cable clamps-10.5 cubic inch capacity								
LXMWOW-25	C-5	Yes	-	-	2	-	1-1/2"	25

2" deep gangable-with armored cable/metal clad clamps-10.5 cubic inch capacity								
LXMOW-25	C-3	Yes	-	-	2	-	1-1/2"	25

Cat. No.	Clamps	Ears	Brkts.	Knockouts			Std. Ctn.
				Ea. End Conduit	Cable	Bottom Conduit	
2 1/4" deep gangable-beveled corners-with nonmetallic sheathed cable clamps-10.5 cubic inch capacity							
LCOW-25	C-1	Yes	-	1-1/2"	2	1-1/2"	25
LCOWC	C-1	Yes	-	1-1/2"	2	1-1/2"	25
LCLE-25	C-1	-	-	1-1/2"	2	1-1/2"	25
LCV-25	C-1	-	CV	1-1/2"	2	1-1/2"	25
LCNOW-25	C-1	Yes	-	1-1/2"	2	1-1/2"	25
802-S	C-1	-	S	1-1/2"	2	1-1/2"	25

2 1/4" deep non-gangable-with nonmetallic sheathed cable clamps-10.5 cubic inch capacity							
A-1-2-25	C-1	-	-	1-1/2"	2	1-1/2"	25
A-1-2E-25	C-1	Yes	-	1-1/2"	2	1-1/2"	25
A-16-25	C-1	-	-	1-1/2"	2	1-1/2"	25