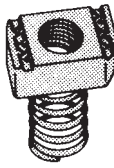
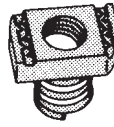
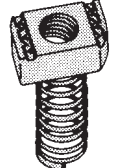



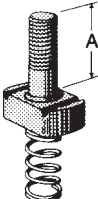
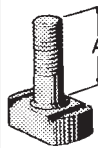
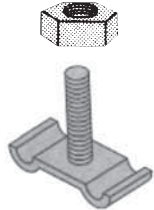


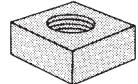

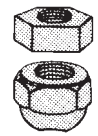



<p><b>A100</b> Regular Spring Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>A100-1/4EGC</td><td>1/4</td><td>8</td></tr> <tr><td>A100-5/16EGC</td><td>5/16</td><td>9</td></tr> <tr><td>A100-3/8EGC</td><td>3/8</td><td>10</td></tr> <tr><td>A100-1/2EGC</td><td>1/2</td><td>12</td></tr> <tr><td colspan="3">Nut is square over 1/2" size.</td></tr> <tr><td>A100-5/8EGC</td><td>5/8</td><td>19</td></tr> <tr><td>A100-3/4</td><td>3/4</td><td>19</td></tr> <tr><td>A100-7/8</td><td>7/8</td><td>18</td></tr> </tbody> </table> <p>Available in Stainless Steel 316. For all A and C series channel and inserts.</p>	Cat. No.	Size	Wt./C lb	A100-1/4EGC	1/4	8	A100-5/16EGC	5/16	9	A100-3/8EGC	3/8	10	A100-1/2EGC	1/2	12	Nut is square over 1/2" size.			A100-5/8EGC	5/8	19	A100-3/4	3/4	19	A100-7/8	7/8	18	<p><b>B100</b> Short Spring Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>B100-1/4EGC</td><td>1/4</td><td>7</td></tr> <tr><td>B100-5/16EGC</td><td>5/16</td><td>8</td></tr> <tr><td>B100-3/8EGC</td><td>3/8</td><td>9</td></tr> <tr><td>B100-1/2EGC</td><td>1/2</td><td>9</td></tr> </tbody> </table> <p>For all B and D series channel and inserts.</p>	Cat. No.	Size	Wt./C lb	B100-1/4EGC	1/4	7	B100-5/16EGC	5/16	8	B100-3/8EGC	3/8	9	B100-1/2EGC	1/2	9	<p><b>H100</b> Long Spring Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>H100-3/8EGC</td><td>3/8</td><td>10</td></tr> <tr><td>H100-1/2EGC</td><td>1/2</td><td>14</td></tr> </tbody> </table> <p>For all E and H series channel and inserts.</p>	Cat. No.	Size	Wt./C lb	H100-3/8EGC	3/8	10	H100-1/2EGC	1/2	14			
Cat. No.	Size	Wt./C lb																																																						
A100-1/4EGC	1/4	8																																																						
A100-5/16EGC	5/16	9																																																						
A100-3/8EGC	3/8	10																																																						
A100-1/2EGC	1/2	12																																																						
Nut is square over 1/2" size.																																																								
A100-5/8EGC	5/8	19																																																						
A100-3/4	3/4	19																																																						
A100-7/8	7/8	18																																																						
Cat. No.	Size	Wt./C lb																																																						
B100-1/4EGC	1/4	7																																																						
B100-5/16EGC	5/16	8																																																						
B100-3/8EGC	3/8	9																																																						
B100-1/2EGC	1/2	9																																																						
Cat. No.	Size	Wt./C lb																																																						
H100-3/8EGC	3/8	10																																																						
H100-1/2EGC	1/2	14																																																						
<p><b>AB100</b> Springless Nut 1/4" thick</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>AB100-1/4EGC</td><td>1/4</td><td>7</td></tr> <tr><td>AB100-5/16EGC</td><td>5/16</td><td>8</td></tr> <tr><td>AB100-3/8EGC</td><td>3/8</td><td>9</td></tr> <tr><td>AB100-1/2EG</td><td>1/2</td><td>9</td></tr> <tr><td colspan="3">Nut is square over 1/2" size</td></tr> <tr><td>AB100-5/8EG</td><td>5/8</td><td>10</td></tr> <tr><td>AB100-3/4EG</td><td>3/4</td><td>10</td></tr> </tbody> </table> <p>For use with all channels.</p>	Cat. No.	Size	Wt./C lb	AB100-1/4EGC	1/4	7	AB100-5/16EGC	5/16	8	AB100-3/8EGC	3/8	9	AB100-1/2EG	1/2	9	Nut is square over 1/2" size			AB100-5/8EG	5/8	10	AB100-3/4EG	3/4	10	<p><b>AC100</b> Springless Nut Heavy duty 3/8" thick</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>AC100-1/4EGC</td><td>1/4</td><td>7</td></tr> <tr><td>AC100-3/8EGC</td><td>3/8</td><td>9</td></tr> <tr><td>AC100-1/2EGC</td><td>1/2</td><td>11</td></tr> <tr><td colspan="3">Nut is square over 1/2" size</td></tr> <tr><td>AC100-5/8EGC</td><td>5/8</td><td>18</td></tr> <tr><td>AC100-3/4EGC</td><td>3/4</td><td>18</td></tr> </tbody> </table> <p>For all A, C, E and H series channel and inserts.</p>	Cat. No.	Size	Wt./C lb	AC100-1/4EGC	1/4	7	AC100-3/8EGC	3/8	9	AC100-1/2EGC	1/2	11	Nut is square over 1/2" size			AC100-5/8EGC	5/8	18	AC100-3/4EGC	3/4	18	<p><b>813EG</b> Springless Nut Light Duty</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>813EG</td><td>1/4</td><td>5</td></tr> </tbody> </table> <p>For use with all channels.</p>	Cat. No.	Size	Wt./C lb	813EG	1/4	5			
Cat. No.	Size	Wt./C lb																																																						
AB100-1/4EGC	1/4	7																																																						
AB100-5/16EGC	5/16	8																																																						
AB100-3/8EGC	3/8	9																																																						
AB100-1/2EG	1/2	9																																																						
Nut is square over 1/2" size																																																								
AB100-5/8EG	5/8	10																																																						
AB100-3/4EG	3/4	10																																																						
Cat. No.	Size	Wt./C lb																																																						
AC100-1/4EGC	1/4	7																																																						
AC100-3/8EGC	3/8	9																																																						
AC100-1/2EGC	1/2	11																																																						
Nut is square over 1/2" size																																																								
AC100-5/8EGC	5/8	18																																																						
AC100-3/4EGC	3/4	18																																																						
Cat. No.	Size	Wt./C lb																																																						
813EG	1/4	5																																																						
<p><b>A182 to A185</b> Regular Spring Stud Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Bolt Dia.</th> <th>Length A</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>A182-1/4x100EG</td><td>1/4</td><td>1</td><td>10</td></tr> <tr><td>A182-1/4x125EG</td><td>1/4</td><td>1-1/4</td><td>15</td></tr> <tr><td>A184-3/8x100EG</td><td>3/8</td><td>1</td><td>10</td></tr> <tr><td>A184-3/8x125EG</td><td>3/8</td><td>1-1/4</td><td>15</td></tr> <tr><td>A185-1/2x100EG</td><td>1/2</td><td>1</td><td>10</td></tr> <tr><td>A185-1/2x125EG</td><td>1/2</td><td>1-1/4</td><td>15</td></tr> </tbody> </table> <p>For all A and C series channels.</p>	Cat. No.	Bolt Dia.	Length A	Wt./C lb	A182-1/4x100EG	1/4	1	10	A182-1/4x125EG	1/4	1-1/4	15	A184-3/8x100EG	3/8	1	10	A184-3/8x125EG	3/8	1-1/4	15	A185-1/2x100EG	1/2	1	10	A185-1/2x125EG	1/2	1-1/4	15	<p><b>A177 to A180</b> Springless Stud Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Bolt Dia.</th> <th>Length A</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>A177-1/4x100EG</td><td>1/4</td><td>1</td><td>8</td></tr> <tr><td>A177-1/4x125EG</td><td>1/4</td><td>1-1/4</td><td>10</td></tr> <tr><td>A179-3/8x100EG</td><td>3/8</td><td>1</td><td>13</td></tr> <tr><td>A179-3/8x125EG</td><td>3/8</td><td>1-1/4</td><td>13.5</td></tr> </tbody> </table> <p>For use with all channels.</p>	Cat. No.	Bolt Dia.	Length A	Wt./C lb	A177-1/4x100EG	1/4	1	8	A177-1/4x125EG	1/4	1-1/4	10	A179-3/8x100EG	3/8	1	13	A179-3/8x125EG	3/8	1-1/4	13.5	<p><b>812</b> Stud Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>For Channel</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>812-1EG</td><td>1/4 x 1</td><td>6</td></tr> </tbody> </table> <p>For attaching fixture to channel slot down or to channel slot up knockouts. Specify length. Hex nut included.</p>	Cat. No.	For Channel	Wt./C lb	812-1EG	1/4 x 1	6
Cat. No.	Bolt Dia.	Length A	Wt./C lb																																																					
A182-1/4x100EG	1/4	1	10																																																					
A182-1/4x125EG	1/4	1-1/4	15																																																					
A184-3/8x100EG	3/8	1	10																																																					
A184-3/8x125EG	3/8	1-1/4	15																																																					
A185-1/2x100EG	1/2	1	10																																																					
A185-1/2x125EG	1/2	1-1/4	15																																																					
Cat. No.	Bolt Dia.	Length A	Wt./C lb																																																					
A177-1/4x100EG	1/4	1	8																																																					
A177-1/4x125EG	1/4	1-1/4	10																																																					
A179-3/8x100EG	3/8	1	13																																																					
A179-3/8x125EG	3/8	1-1/4	13.5																																																					
Cat. No.	For Channel	Wt./C lb																																																						
812-1EG	1/4 x 1	6																																																						
<p><b>CM100</b> Nylon Cone Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>CM100-1/4</td><td>1/4</td><td>8</td></tr> <tr><td>CM100-3/8</td><td>3/8</td><td>10</td></tr> <tr><td>* CM100-1/2</td><td>1/2</td><td>12</td></tr> <tr><td>** CM100B-1/2</td><td>1/2</td><td>10</td></tr> </tbody> </table> <p>GoldGalv® only For all 1-5/8" channel *Will not fit B Series channel **For B Series channel</p>	Cat. No.	Size	Wt./C lb	CM100-1/4	1/4	8	CM100-3/8	3/8	10	* CM100-1/2	1/2	12	** CM100B-1/2	1/2	10	<p><b>UC100</b> Universal Nylon Cone Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>UC100-1/4</td><td>1/4</td><td>8</td></tr> <tr><td>UC100-3/8</td><td>3/8</td><td>10</td></tr> <tr><td>UC100-1/2</td><td>1/2</td><td>12</td></tr> </tbody> </table> <p>GoldGalv® only For all 1-5/8" and 1-1/2" channels May be used with ALL Strut Depths. Can be used for CM100 Series, A100 Series, B100 Series and AB100 Series.</p>	Cat. No.	Size	Wt./C lb	UC100-1/4	1/4	8	UC100-3/8	3/8	10	UC100-1/2	1/2	12	<p><b>AB102</b> Unhardened Square Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>AB102-1/4</td><td>1/4</td><td>13</td></tr> <tr><td>AB102-3/8</td><td>3/8</td><td>14</td></tr> <tr><td>AB102-1/2</td><td>1/2</td><td>14</td></tr> <tr><td>AB102-5/8</td><td>5/8</td><td>12</td></tr> <tr><td>AB102-3/4</td><td>3/4</td><td>11</td></tr> <tr><td>AB102-7/8</td><td>7/8</td><td>10</td></tr> </tbody> </table>	Cat. No.	Size	Wt./C lb	AB102-1/4	1/4	13	AB102-3/8	3/8	14	AB102-1/2	1/2	14	AB102-5/8	5/8	12	AB102-3/4	3/4	11	AB102-7/8	7/8	10						
Cat. No.	Size	Wt./C lb																																																						
CM100-1/4	1/4	8																																																						
CM100-3/8	3/8	10																																																						
* CM100-1/2	1/2	12																																																						
** CM100B-1/2	1/2	10																																																						
Cat. No.	Size	Wt./C lb																																																						
UC100-1/4	1/4	8																																																						
UC100-3/8	3/8	10																																																						
UC100-1/2	1/2	12																																																						
Cat. No.	Size	Wt./C lb																																																						
AB102-1/4	1/4	13																																																						
AB102-3/8	3/8	14																																																						
AB102-1/2	1/2	14																																																						
AB102-5/8	5/8	12																																																						
AB102-3/4	3/4	11																																																						
AB102-7/8	7/8	10																																																						
<p><b>E145</b> Standard Hex Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>E145-1/4EGC</td><td>1/4</td><td>.72</td></tr> <tr><td>E145-3/8EGC</td><td>3/8</td><td>1.60</td></tr> <tr><td>E145-1/2EGC</td><td>1/2</td><td>2.78</td></tr> <tr><td>E145-5/8EG</td><td>5/8</td><td>6.92</td></tr> <tr><td>E145-3/4EGC</td><td>3/4</td><td>12.70</td></tr> <tr><td>E145-7/8EGC</td><td>7/8</td><td>19.00</td></tr> <tr><td>E145-1EGC</td><td>1</td><td>28.00</td></tr> </tbody> </table>	Cat. No.	Size	Wt./C lb	E145-1/4EGC	1/4	.72	E145-3/8EGC	3/8	1.60	E145-1/2EGC	1/2	2.78	E145-5/8EG	5/8	6.92	E145-3/4EGC	3/4	12.70	E145-7/8EGC	7/8	19.00	E145-1EGC	1	28.00	<p><b>ES145</b> Swivel Nut and Jam Nut Combinations</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>ES145-3/8</td><td>3/8</td><td>5.5</td></tr> <tr><td>ES145-1/2</td><td>1/2</td><td>6.0</td></tr> </tbody> </table>	Cat. No.	Size	Wt./C lb	ES145-3/8	3/8	5.5	ES145-1/2	1/2	6.0	<p><b>E146</b> Standard Square Nut</p>  <p><b>STD PACK: 100</b></p> <table border="1"> <thead> <tr> <th>Cat. No.</th> <th>Size</th> <th>Wt./C lb</th> </tr> </thead> <tbody> <tr><td>E146-1/4HDGC</td><td>1/4</td><td>.93</td></tr> <tr><td>E146-5/16HDGC</td><td>5/16</td><td>1.60</td></tr> <tr><td>E146-3/8HDGC</td><td>3/8</td><td>2.65</td></tr> <tr><td>E146-5/8HDGC</td><td>5/8</td><td>10.80</td></tr> </tbody> </table>	Cat. No.	Size	Wt./C lb	E146-1/4HDGC	1/4	.93	E146-5/16HDGC	5/16	1.60	E146-3/8HDGC	3/8	2.65	E146-5/8HDGC	5/8	10.80						
Cat. No.	Size	Wt./C lb																																																						
E145-1/4EGC	1/4	.72																																																						
E145-3/8EGC	3/8	1.60																																																						
E145-1/2EGC	1/2	2.78																																																						
E145-5/8EG	5/8	6.92																																																						
E145-3/4EGC	3/4	12.70																																																						
E145-7/8EGC	7/8	19.00																																																						
E145-1EGC	1	28.00																																																						
Cat. No.	Size	Wt./C lb																																																						
ES145-3/8	3/8	5.5																																																						
ES145-1/2	1/2	6.0																																																						
Cat. No.	Size	Wt./C lb																																																						
E146-1/4HDGC	1/4	.93																																																						
E146-5/16HDGC	5/16	1.60																																																						
E146-3/8HDGC	3/8	2.65																																																						
E146-5/8HDGC	5/8	10.80																																																						