

Blackburn®

Ground Rod Clamps

Blackburn® Grounding

Compresses #8 AWG through 4/0 AWG cable.

Signal Reference Grid Connector

- Clamps onto pedestal posts up to 1" diameter square and 1¼" round
- Can be used as an "X" or "T" configuration cable to post
- High-conductivity wrought-copper construction




CAT. NO.	CONDUCTOR RANGE	INSTALLING TOOLS AND DIE CODES TBM14M AND TBM15I		
		DIE CAT. NO.	DIE CODE	COLOR CODE
SRG8-4	#8	15527	29	GRAY
	#6 to #4	15528	33	BROWN
SRG2-1	#2 & #1	15508	42	PINK
SRG10-20	1/0 & 2/0	15530	50	ORANGE
SRG30-40	3/0 & 4/0	15511	54	PURPLE

Secures signal reference grid wire to raised-floor support posts.

Signal Reference Grid Clamp

- Range-taking design accepts #8 to #4 AWG grid wire and fits 1" round and ¾" square trade size support posts
- Lay-in feature means no kinks or bends
- Quick, easy installation
- Only one screw to tighten
- Enables grid wire to make direct, low-resistance contact with support posts
- Stamped-steel construction, zinc plated

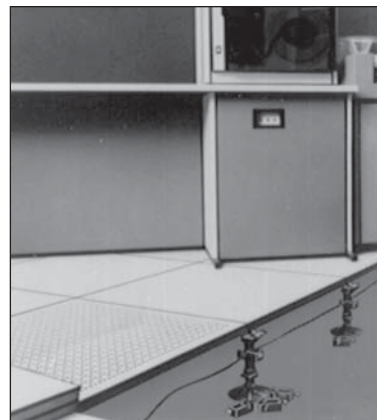

CAT. NO.	DESCRIPTION	WIRE RANGE
3900	¾" square to 1" round	#8-#4
3900BP (Bulk Pack)	¾" square to 1" round	#8-#4

UL File No. E-3060

Approved for grounding and bonding per UL 467.

Ground Electrode Boxes



CAT. NO.	DESCRIPTION	WT/ 100		STANDARD PACKAGE
		LB.	KGS.	
51628	Pregalvanized steel	1180	536.3	5
51629	Hot dip galvanized	1200	545.4	5

14 gauge steel. 10" diameter, 12" depth.

Thomas & Betts

United States
Tel: 901.252.8000
800.816.7809
Fax: 901.252.1354

Technical Services
Tel: 888.862.3289