

Blackburn®

LOCKTITE® Connectors — Code Copper Conductor (for 600V)

All the same features as the standard LOCKTITE® lug — with two or three barrels.

Double-Barrel/Triple-Barrel NEMA-Drilled Lugs for 600V Applications

- Screw tightening
- Serrated saddle
- Built-in lockwasher

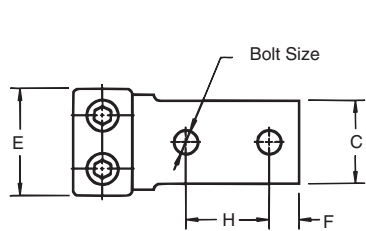
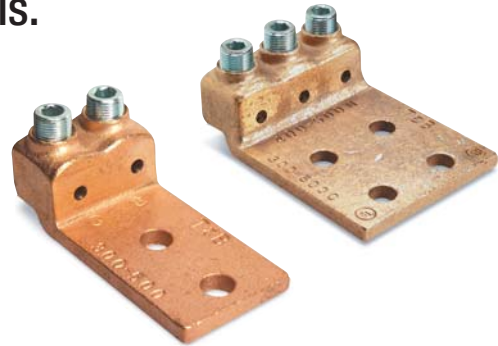


Fig. A

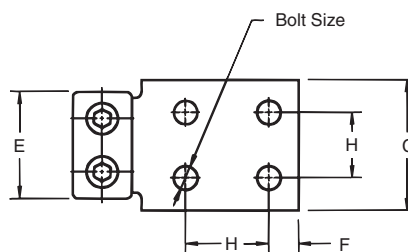


Fig. B

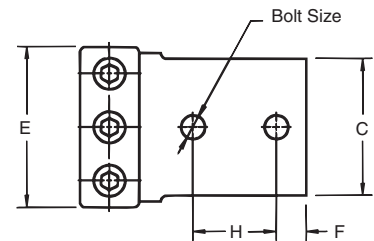


Fig. C

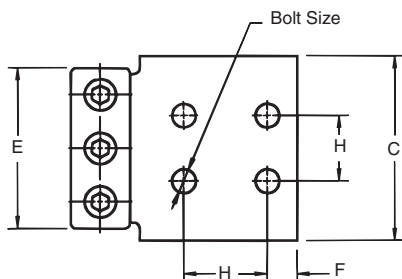


Fig. D



CAT. NO.	CABLE SIZE	FIG.		DIMENSIONS (IN.)							
			BOLT SIZE	A	B	C	D	E	F	H	J
32003BD†	14 to 8	A	¼	2⅜	1¼	⅝	⅞	1⅞	⅞	⅝	1⅝
32005BD†	8 to 4	A	¼	2½	2	1	⅞	1	⅞	⅝	1⅞
32007BD	4 to 1	A	⅜	2⅞	2	1¼	⅞	1¼	⅞	1	2⅞
32009BD	1 to 2/0	A	½	4⅞	3½	1½	¼	1⅞	⅝	1¼	1⅞
32011BD	2/0 to 4/0	A	½	4⅞	3½	1¼	⅞	1¾	⅝	1¼	1⅞
32013BD	4/0 to 300	A	½	4⅞	3½	2	⅞	2⅞	⅝	1¼	1⅞
32015BD	300 to 500	A	½	5⅞	3⅞	2½	1⅞	2⅞	⅝	1¼	1⅞
32017BD	500 to 700	B	½	5⅞	4	4	1⅞	2⅞	⅝	1¼	2⅞
32019BD	750 to 1000	B	½	5⅞	4	4	1⅞	3⅞	⅝	1¼	2⅞
32011TB	2/0 to 4/0	C	½	4⅞	3½	2½	⅞	2⅞	⅝	1¼	1⅞
32013TB	4/0 to 300	C	½	4⅞	3½	3	⅞	3⅞	⅝	1¼	1⅞
32015TB	300 to 500	D	½	5⅞	4	4	1⅞	3⅞	⅝	1¼	1⅞
32017TB	500 to 750	D	½	5⅞	4	4	1⅞	4⅞	⅝	1¼	2⅞
32019TB	750 to 1,000	D	½	5⅞	4	4	1⅞	4⅞	⅝	1¼	2⅞

†With Filister Head Screw.

For torque requirements, see page C-49.

Thomas & Betts

United States
Tel: 901.252.8000
800.816.7809
Fax: 901.252.1354

Technical Services
Tel: 888.862.3289