

Thomas&Betts

The New EZCODE Label Printer Redefines Easy to Use!

EZCODE[®]
PROFESSIONAL LABELING SYSTEM

EZL500 Thermal
Label Printer



EZL500 Thermal Label Printer

The industry's most sophisticated label printer is also the easiest to use. It's so smart, it's simple!

- Large LCD screen makes viewing easy
- Powerful firmware is easy to use and update
- Ergonomic design makes it easy to carry
- Thermal transfer technology enables you to print non-smearing labels
- Cut a label with just the touch of a button
- Large tape cassette maximizes the amount of tape media
- Wide output port makes it easy to collect your printed labels
- Backlit display enables use in low-light environments
- Oversized keys and spacing make it easy to type labels
- Integral cassette sensor automatically adjusts the unit to your tapes width and media type, eliminating reprogramming with each tape switch
- Can be outfitted with a long-life, rechargeable, 7.4 volt Li-ion battery



With the EZCODE[®] EZL500 thermal label printer, you can print the widest variety of labels used on the most surface types – and you can use it in more work environments than any other thermal label printer on the market. Best of all, it's easier to use than any other thermal label printer. With the EZL500 printer, you'll be labeling cable jackets and other surfaces in no time at all!

It's easy to get a handle on things

The printer's simple-to use but powerful firmware makes operation intuitive, so you won't spend valuable time reading the instruction manual. The ergonomically designed EZL500 printer fits a firm grip and helps to protect the unit in case of an accidental drop. The EZL500 printer features the largest backlit LCD screen among all handheld thermal labels printers. It enables you to easily see information on display and is especially useful in low-light conditions.

Just print, cut and stick

Using thermal transfer technology, the EZL500 unit prints labels that won't smear. Based on average usage, the print head can be expected to last up to 10 years. Now that's reliability! The automatic cutter function enables you to cut a label with the touch of a button. And unlike some competing models, the cutting blade can be changed easily.

Size matters

You'll appreciate the EZL500 printer's oversized, wide-spaced keys, so you won't hit multiple buttons by mistake. Use hard-coded function keys for immediate access to frequently used functions. Soft-menu keys are ideal for infrequent functions. Able to handle a variety of tapes ranging from a quarter-inch to an inch wide, the EZL500 printer enables you to use more media than any other thermal label printer. The integral cassette sensor automatically adjusts the unit to your tape's width and media type – so you don't have to reprogram the printer with each cassette change!




Do more, do more longer

The EZL500 printer runs on six standard AA batteries or an optional, rechargeable 7.4 volt Li-ion battery. The Li-ion battery has a longer life than standard batteries and lasts longer than most other rechargeable batteries.

In short, the EZL500 printer is ready to work on the lengthy jobs you have now and the ones you'll be doing years down the road.



When you're working in tight spaces, the handy magnet strap lets you to stick the EZL500 printer to a vertical metallic surface to free your hands until you need to use it again.

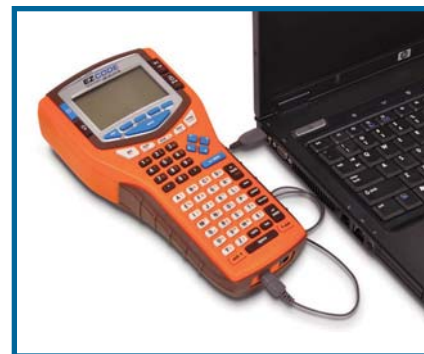

With the included PC connection software and built-in mini USB port, you can print directly from your computer and easily upgrade the software.

EZL500 Thermal Label Printer



EZL500 Thermal Label Printer

Cat. No.	Description	UPC Code
EZL500	Handheld Thermal Label Printer (includes EZL500 Thermal Label Printer, EZ-1030C-WN label cassette, six AA batteries, quick-start guide and user's manual)	78260991656
EZL500-KIT	Handheld Thermal Label Printer Kit with Accessories (includes EZL500 Thermal Label Printer, EZ-1030C-MP and EZ-1030C-WN label cassettes, PA-EZL500 power adapter, MS-EZL500 magnet strap, PCS-EZL500 PC software and USB cable, RB-EZL500 rechargeable battery, quick-start guide, user's manual and CC-EZL500 carrying case)	78260991657



PA-EZL500



MS-EZL500



PCS-EZL500



RB-EZL500



CC-EZL500

EZL500 Accessories

Cat. No.	Description	UPC Code
PA-EZL500	EZL500 Power Adapter	78260991682
MS-EZL500	Magnet Strap for EZL500	78260991683
PCS-EZL500	PC Software and USB Cable for EZL500	78260991685
CC-EZL500	Hard Carrying Case for EZL500	78260991686
RB-EZL500	EZL500 Rechargeable Battery	78260992262

Atlantic Region

Thomas & Betts Limited
106 Chain Lake Drive, Unit 2C
Halifax, Nova Scotia B3S 1A8
Tel.: (902) 450-1307
Toll Free: 1-877-862-4357
Fax: (902) 450-1309

Quebec Region

Thomas & Betts Limited
7900 Taschereau Boulevard
Building D, Suite 108
Brossard, Quebec J4X 1C2
Tel.: (450) 466-1102
Toll Free: 1-800-465-1399
Fax: (450) 466-1163

Ontario Region

Thomas & Betts Limited
2000 Argentia Road
Plaza 5, Suite 500
Mississauga, Ontario L5N 2R7
Tel.: (905) 858-1010
Toll Free: 1-877-291-7771
Fax: (905) 858-1080

Western Region

Thomas & Betts Limited
6531-148th Street, #1
Surrey, British Columbia
V3S 3C5
Tel.: (604) 598-9811
Toll Free: 1-866-540-8220
Fax: (604) 598-9840

Thomas & Betts Limited
4836 Eleniak Road
Edmonton, Alberta T6B 2S1
Tel.: (780) 424-7092
Toll Free: 1-888-664-5666
Fax: (780) 424-7093
Toll Free: 1-866-424-4082

EZL500 Thermal Label Printer Tapes

- Nylon** – Excellent for wire and cable wrapping on curved, textured and highly textured surfaces, these flexible labels feature EZ-Peel split backs and industrial-strength adhesive
- Polyester** – Perfect for general labeling on flat or textured surfaces, these labels also come with EZ-Peel split backs and industrial-strength adhesive
- Heat-Shrink** – Made of flame-retardant polyolefin with 3:1 shrink ratio for extra protection and insulation of wire and cable, these labels meet MIL-DTL-23053/5 classes 1 and 3 standards
- Vinyl** – Able to resist oil, dirt, grime and solvents on smooth, textured or curved surfaces, this flexible label features and EZ-Peel split back and industrial-strength adhesive; it's excellent for indoor/outdoor use.



EZ-1230C-WN



EZ-3430C-WP

EZL500 Label Printer Tapes

Cat. No.	Material	Color*	Width (in.)	UPC Number
EZ-3830C-WN	Nylon	White	3/8	78620991658
EZ-1230C-WN	Nylon	White	1/2	78620991659
EZ-3430C-WN	Nylon	White	3/4	78620991660
EZ-1030C-WN	Nylon	White	1	78620991661
EZ-3830C-WP	Polyester	White	3/8	78620991666
EZ-1230C-WP	Polyester	White	1/2	78620991667
EZ-3430C-WP	Polyester	White	3/4	78620991668
EZ-1030C-WP	Polyester	White	1	78620991670
EZ-3830C-MP	Polyester	Metallic	3/8	78620991671
EZ-1230C-MP	Polyester	Metallic	1/2	78620991672
EZ-3430C-MP	Polyester	Metallic	3/4	78620991673
EZ-1030C-MP	Polyester	Metallic	1	78620991674
EZ-1410C-WHS	Heat-Shrink	White	1/4	78620991675
EZ-3810C-WHS	Heat-Shrink	White	3/8	78620991676
EZ-1210C-WHS	Heat-Shrink	White	1/2	78620991677
EZ-1410C-YHS	Heat-Shrink	Yellow	1/4	78620991678
EZ-3810C-YHS	Heat-Shrink	Yellow	3/8	78620991679
EZ-1210C-YHS	Heat-Shrink	Yellow	1/2	78620991680
EZ-1030C-SL	Self-Laminating Vinyl	White/Clear	1	78620991681

* Other colors available. Contact your Regional Sales Office.