


Conduit Nipples – Die Cast Zinc 1" Long

Cat. No.	Conduit Size	A	B	Std. Ctn.
HA-211	½"	1"	1 ⁹ / ₁₆ "	1000
HA-212	¾"	1"	1 ³ / ₁₆ "	500
HA-213	1"	1"	1 ⁷ / ₁₆ "	250

U.L. File No. E-1275 ½" & ¾" only

E

Steel City®

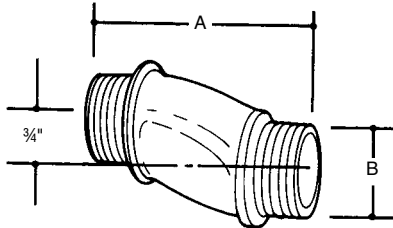


Offset Nipples – Die Cast Zinc

Cat. No.	Conduit Size	A	B	Std. Ctn.
HO-221	½"	2.60"	1.00"	100
HO-222	¾"	2.62"	1.32"	100
HO-223	1"	2.68"	1.51"	100
HO-224	1¼"	2.85"	1.85"	50
HO-225	1½"	2.88"	2.08"	50
HO-226	2"	3.19"	2.71"	20

¾ offset.


U.L. File No. E-1275

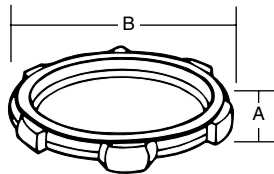

Locknuts – Steel/Zinc Plated

Cat. No.	Conduit Size	Dimensions (in.)		Std. Ctn.
		A (min.)	B (max.)	
LN-100-SC	¾"	–	–	1000
LN-101-SC	½"	0.125"	1.140"	1000
LN-102	¾"	0.140"	1.420"	1000
LN-103	1"	0.170"	1.770"	500
LN-104	1¼"	0.170"	2.281"	200
LN-105	1½"	0.170"	2.598"	100
LN-106	2"	0.187"	3.175"	50
LN-107	2½"	0.375"	3.562"	30
LN-108	3"	0.375"	4.250"	25
LN-109	3½"	0.438"	4.803"	25
LN-110	4"	0.438"	5.402"	25
LN-111	5"	0.500"	6.674"	10
LN-112	6"	0.561"	7.934"	10

U.L. File No. E-1275

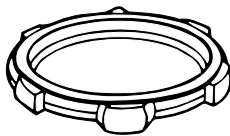

Thin Construction Locknuts–Steel/Zinc Plated

Cat. No.	Conduit Size	Unit Qty.	Std. Ctn.
SPLN-107	2½"	30	30
SPLN-108	3"	25	25
SPLN-109	3½"	25	25
SPLN-110	4"	25	25

*Not U.L. Listed