



LCS Series

Plastic Pictogram Exit Sign

Type: _____

Project/Location: _____

Contractor: _____

Prepared By: _____

Date: _____


Model No.: _____

FEATURES

- Energy efficient, long-life white LEDs consuming 4.2W at normal operation
- Dual voltage input capability 120/347VAC
- Selection of AC/DC, 6 to 24VDC or self-powered using a 3.6V Nickel-Cadmium battery
- Automatic, temperature compensated, pulse type charger
- Low voltage disconnect prevents over discharge of battery
- Automatic brownout protection
- Battery lock-out prevents discharge during installation
- Comes standard with three pictogram legends for direction selection
- Red LED charger monitor
- Injection-molded off-white thermoplastic ABS housing
- Fast and easy installation with snap-together design
- Ceiling, wall or end mount installation
- CSA C22.2 no.141-10 listed
- Comes standard with one (1) year warranty

DIMENSIONS

Dimensions are approximate and subject to change.

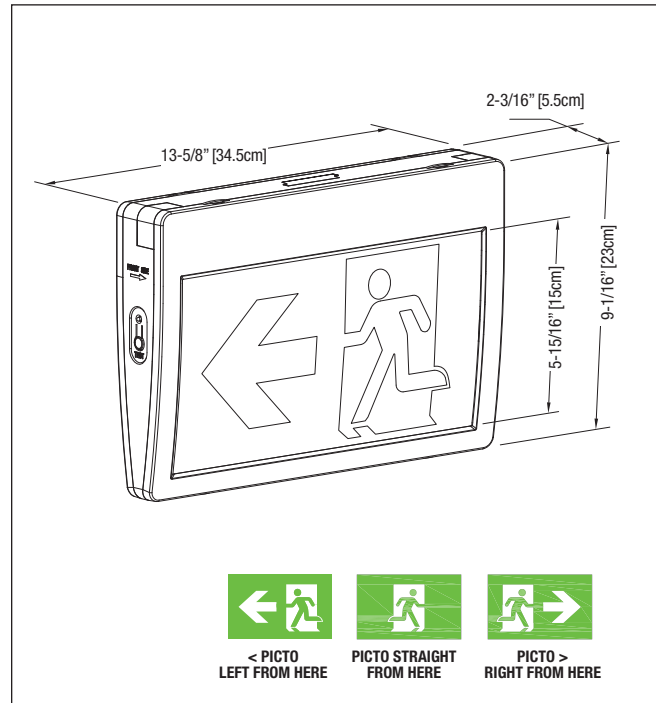

POWER CONSUMPTION AND UNIT RATING

MODEL	AC SPECS			DC SPECS	
AC/DC-remote	120/347VAC	0.5/0.4 A	4.2/3.6W	6 to 24VDC	Less than 1.5W
Self-powered				Ni-Cd battery	Min. 90 minutes

ORDERING INFORMATION

SERIES	VOLTAGE
LCS	-SP= 120/347VAC, Self-Powered (90 mins) -U= 120/347VAC, 6 to 24VDC

EXAMPLE: LCS-SP



All information and specifications contained in this catalogue sheet are subject to change due to engineer design, errors and omissions.
© 2014. Thomas & Betts Limited. All rights reserved.

